



Articulated foot with sheet metal base Ø80

Max load: 10,000N
Rubber sole in EPDM, blue

PTA80SS/EB

- **Articulated adjustable levelling feet**
- Axial articulation +/- 10°
- With non-slip sole in EPDM Blue
- Stainless steel in shiny finish
- **Materials:**
Base: shiny 304 stainless steel sheet
Thread: 304 stainless steel, supplied without nut
Sole: EPDM blue

Options


- Other thread dimensions on request
- 316 grade Stainless steel on request

Advantages

- Hygienic special sole for easy cleaning.
- Food processing, Pharmaceutical and Chemical Environment

Food industry

Sole in EPDM, blue

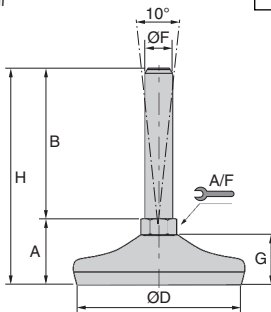

DISCOUNTS

Qty	1+	6+	10+	15+	20+
Disc.	Price -5%	-10%	-15%	On request	


References	ØD	ØF	B	A	A/F	G	H	Static load(N)	Price per unit 1 to 5
PTA80-12-100/SS/EB	80	M12	100	35	14	25	135	10000	29,62€
PTA80-12-150/SS/EB	80	M12	150	35	14	25	185	10000	31,76€
PTA80-16-100/SS/EB	80	M16	100	35	13	25	135	10000	31,76€
PTA80-16-150/SS/EB	80	M16	150	35	13	25	185	10000	33,84€
PTA80-20-100/SS/EB	80	M20	100	38	17	25	138	10000	35,47€
PTA80-20-150/SS/EB	80	M20	150	38	17	25	188	10000	38,07€
PTA80-20-200/SS/EB	80	M20	200	38	17	25	238	10000	42,04€

* Depending on availability - Dimensions in mm

Our other products



MEFC
Flanged sintered ferrous bush, Self-lubricating FP20 ferrous alloy M...

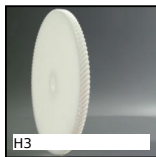

H3
Crossed helical gear crossed axis at 90°, Machined plastic (delrin)



SLBE
Indexing plunger - Spacer, Spacer for SLB and SLBS index bolts



SDG
Adjustable guide support bracket, Plastic



GARBAB
Lock pin for clamping, Ball lock pin



HLC24
Right angle spiro bevel gearbox, Up to 78Nm



RPCplss
Swivel castor with double brake, Stainless steel - Polyamide



VELM6
Screw-on base for hook-and-loop strip, Polyamide



PRF_PA
Angle plate for aluminium profile,



DOG319
Motor-gearbox 12V and 24V DC, from 4 to



KBS_UU
Stainless steel closed precision linear



ERT
Sliding nut, For T slot

Complementary products



PTA50ssEB
Articulated foot with sheet metal base
Ø50, Articulated foot



PTA100ssEB
Articulated foot with sheet metal base
Ø100, Articulated foot



PAMF80EB
Articulated foot with sheet metal base
Ø80, Articulated foot



PAMF100EB
Articulated foot with sheet metal base
Ø100, Articulated foot