



Articulated foot with sheet metal base Ø80

Max load: 10,000N
Rubber sole in EPDM, blue

PTA80SS/EB

- **Articulated adjustable levelling feet**
- Axial articulation +/- 10°
- With non-slip sole in EPDM Blue
- Stainless steel in shiny finish
- **Materials:**
Base: shiny 304 stainless steel sheet
Thread: 304 stainless steel, supplied without nut
Sole: EPDM blue

Options


- Other thread dimensions on request
- 316 grade Stainless steel on request

Advantages

- Hygienic special sole for easy cleaning.
- Food processing, Pharmaceutical and Chemical Environment

Food industry

Sole in EPDM, blue

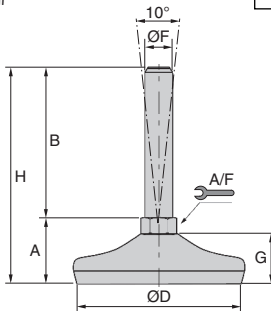

DISCOUNTS

| Qty | 1+ | 6+ | 10+ | 15+ | 20+ |
|-------|-------|-----|------|------|------------|
| Disc. | Price | -5% | -10% | -15% | On request |

| References | ØD | ØF | B | A | A/F | G | H | Static load(N) | Price per unit 1 to 5 |
|--------------------|----|-----|-----|----|-----|----|-----|----------------|-----------------------|
| PTA80-12-100/SS/EB | 80 | M12 | 100 | 35 | 14 | 25 | 135 | 10000 | 29,62€ |
| PTA80-12-150/SS/EB | 80 | M12 | 150 | 35 | 14 | 25 | 185 | 10000 | 31,76€ |
| PTA80-16-100/SS/EB | 80 | M16 | 100 | 35 | 13 | 25 | 135 | 10000 | 31,76€ |
| PTA80-16-150/SS/EB | 80 | M16 | 150 | 35 | 13 | 25 | 185 | 10000 | 33,84€ |
| PTA80-20-100/SS/EB | 80 | M20 | 100 | 38 | 17 | 25 | 138 | 10000 | 35,47€ |
| PTA80-20-150/SS/EB | 80 | M20 | 150 | 38 | 17 | 25 | 188 | 10000 | 38,07€ |
| PTA80-20-200/SS/EB | 80 | M20 | 200 | 38 | 17 | 25 | 238 | 10000 | 42,04€ |

* Depending on availability - Dimensions in mm

Our other products



RFK28C
Hypoid gearbox -
Stainless steel, up to
130 Nm



PTCR
Adjustable furniture
foot, square tube



M2
Worm and wheel set,
Unhardened steel



GLT3E-58
Telescopic drawer,



BPM_LOK
Long-Lok slotted
spring plunger with
ball tip, LONG-LOK -
Stainless ...



ACLLPP
Latch for aluminium
profile, Spring
operated latch



FBL4004_K32
Brush strip per metre,
Black striated
polypropylene (PP)



ACLALF
Adjustable foot for
aluminium profile,
Ideal for workstations



PW_PWG3
Wheel - precision
range, Bronze



ACL-FPA
Panel mounting block
for aluminium
structures, Support
block



AT5M_AT10M
AT type timing belt
per metre, AT10 Steel
cored polyurethane



FBL4004_K7
Brush strip per meter
PA6 fibres Ø0.3 to
Ø0.5, Black polyamide
6 ...

Complementary products



PTA50ssEB
Articulated foot with
sheet metal base
Ø50, Articulated foot



PTA100ssEB
Articulated foot with
sheet metal base
Ø100, Articulated foot



PAMF80EB
Articulated foot with
sheet metal base
Ø80, Articulated foot



PAMF100EB
Articulated foot with
sheet metal base
Ø100, Articulated foot