



Articulated foot with sheet metal base Ø80

Max load: 10,000N
Rubber sole in EPDM, blue

PTA80SS/EB

- **Articulated adjustable levelling feet**
- Axial articulation +/- 10°
- With non-slip sole in EPDM Blue
- Stainless steel in shiny finish
- **Materials:**
Base: shiny 304 stainless steel sheet
Thread: 304 stainless steel, supplied without nut
Sole: EPDM blue

Options


- Other thread dimensions on request
- 316 grade Stainless steel on request

Advantages

- Hygienic special sole for easy cleaning.
- Food processing, Pharmaceutical and Chemical Environment

Food industry

Sole in EPDM, blue

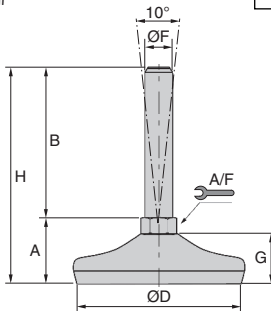

DISCOUNTS

Qty	1+	6+	10+	15+	20+
Disc.	Price	-5%	-10%	-15%	On request

References	ØD	ØF	B	A	A/F	G	H	Static load(N)	Price per unit 1 to 5
PTA80-12-100/SS/EB	80	M12	100	35	14	25	135	10000	29,62€
PTA80-12-150/SS/EB	80	M12	150	35	14	25	185	10000	31,76€
PTA80-16-100/SS/EB	80	M16	100	35	13	25	135	10000	31,76€
PTA80-16-150/SS/EB	80	M16	150	35	13	25	185	10000	33,84€
PTA80-20-100/SS/EB	80	M20	100	38	17	25	138	10000	35,47€
PTA80-20-150/SS/EB	80	M20	150	38	17	25	188	10000	38,07€
PTA80-20-200/SS/EB	80	M20	200	38	17	25	238	10000	42,04€

* Depending on availability - Dimensions in mm

Our other products



Sealed flange bearing unit for Food Industry, cover



Locking bolt, With grip - Steel



Spur gear - precision range, Stainless steel 316



Coupling bar for aluminium profile, Coupling bar



Dynamic washer DIN2093, Steel



Stainless steel bevel gear, 1:1



Ball transfer unit bolt fitting, Heavy



Nut for aluminium profile, Steel square nut with tab



V-rail guidance Simple Select® system, Rail with carriage



Machined plastic bevel gear, 2:1



Parallel axis helical gear, Machined plastic (delrin)



Tools Hygienic Usit® and Hygienic Design®, Protective inserts for ...

Complementary products



Articulated foot with sheet metal base Ø50, Articulated foot



Articulated foot with sheet metal base Ø100, Articulated foot



Articulated foot with sheet metal base Ø80, Articulated foot



Articulated foot with sheet metal base Ø100, Articulated foot