



# Articulated foot with sheet metal base Ø80

Max load: 10,000N  
Rubber sole in EPDM, blue

PTA80SS/EB

- **Articulated adjustable levelling feet**
- Axial articulation +/- 10°
- With non-slip sole in EPDM Blue
- Stainless steel in shiny finish
- **Materials:**  
Base: shiny 304 stainless steel sheet  
Thread: 304 stainless steel, supplied without nut  
Sole: EPDM blue

## Options


- Other thread dimensions on request
- 316 grade Stainless steel on request

## Advantages

- Hygienic special sole for easy cleaning.
- Food processing, Pharmaceutical and Chemical Environment

Food industry

Sole in EPDM, blue

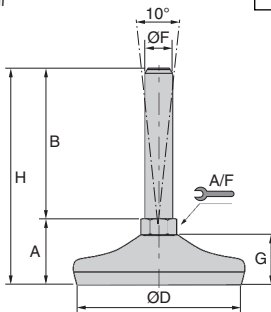

## DISCOUNTS

Qty	1+	6+	10+	15+	20+
Disc.	Price	-5%	-10%	-15%	On request

References	ØD	ØF	B	A	A/F	G	H	Static load(N)	Price per unit 1 to 5
PTA80-12-100/SS/EB	80	M12	100	35	14	25	135	10000	29,62€
PTA80-12-150/SS/EB	80	M12	150	35	14	25	185	10000	31,76€
PTA80-16-100/SS/EB	80	M16	100	35	13	25	135	10000	31,76€
PTA80-16-150/SS/EB	80	M16	150	35	13	25	185	10000	33,84€
PTA80-20-100/SS/EB	80	M20	100	38	17	25	138	10000	35,47€
PTA80-20-150/SS/EB	80	M20	150	38	17	25	188	10000	38,07€
PTA80-20-200/SS/EB	80	M20	200	38	17	25	238	10000	42,04€

\* Depending on availability - Dimensions in mm

## Our other products



RFK28C  
Hypoid gearbox -  
Stainless steel, up to  
130 Nm



PTCR  
Adjustable furniture  
foot, square tube



M2  
Worm and wheel set,  
Unhardened steel



GLT3E-58  
Telescopic drawer,



BPM\_LOK  
Long-Lok slotted  
spring plunger with  
ball tip, LONG-LOK -  
Stainless ...



ACLPP  
Latch for aluminium  
profile, Spring  
operated latch



FBL4004\_K32  
Brush strip per metre,  
Black striated  
polypropylene (PP)



ACLALF  
Adjustable foot for  
aluminium profile,  
Ideal for workstations



PW\_PWG3  
Wheel - precision  
range, Bronze



ACL-FPA  
Panel mounting block  
for aluminium  
structures, Support  
block



AT5M\_AT10M  
AT type timing belt  
per metre, AT10 Steel  
cored polyurethane



FBL4004\_K7  
Brush strip per meter  
PA6 fibres Ø0.3 to  
Ø0.5, Black polyamide  
6 ...

## Complementary products



PTA50ssEB  
Articulated foot with  
sheet metal base  
Ø50, Articulated foot



PTA100ssEB  
Articulated foot with  
sheet metal base  
Ø100, Articulated foot



PAMF80EB  
Articulated foot with  
sheet metal base  
Ø80, Articulated foot



PAMF100EB  
Articulated foot with  
sheet metal base  
Ø100, Articulated foot