

Articulated foot with solid base foot Ø40 **SteSta**

PTA40 PTA40ss

Accepts loads up to 3000N

- **Articulated foot**
- Up to +/- 5° from vertical
- **Materials:**


Steel version:

Base: Galvanised sheet steel C40
Shaft: Galvanised steel (nut not supplied)
Sole: Vulcanised NBR rubber, hardness 80° Shore

Stainless steel version:

Base: Sheet stainless steel 304
Shaft: Stainless steel 304 (nut not supplied)
Sole: Vulcanised NBR rubber, hardness 80° Shore

Stainless steel version, sanded finish

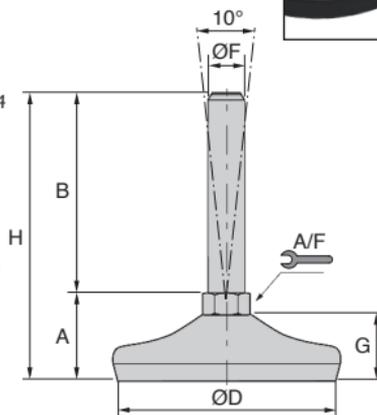

Option

- Other shaft size available upon request

DISCOUNTS

| | | | | | |
|-------|----------|------|------|------------|-----|
| Qty | 1+ | 15+ | 20+ | 25+ | 40+ |
| Disc. | List -5% | -10% | -15% | On request | |

| Part number | | ØD | ØF | B | A | A/F | G | H | Static load (N) | Price each 1 to 14 | |
|-----------------------------|--------------------|----|-----|-----|----|-----|----|-----|-----------------|--------------------|---------|
| bright | sanded finish | | | | | | | | | | |
| Steel foot | | | | | | | | | | | |
| PTA40-8-25 | - | 40 | M8 | 25 | 26 | 6 | 15 | 51 | 3000 | - | 11,02 € |
| PTA40-8-50 | - | 40 | M8 | 50 | 26 | 6 | 15 | 76 | 3000 | - | 11,44 € |
| PTA40-8-75 | - | 40 | M8 | 75 | 26 | 6 | 15 | 101 | 3000 | - | 11,91 € |
| PTA40-10-25 | - | 40 | M10 | 25 | 26 | 8 | 15 | 51 | 3000 | - | 11,44 € |
| PTA40-10-50 | - | 40 | M10 | 50 | 26 | 8 | 15 | 76 | 3000 | - | 11,91 € |
| PTA40-10-75 | - | 40 | M10 | 75 | 26 | 8 | 15 | 101 | 3000 | - | 12,33 € |
| PTA40-10-100 | - | 40 | M10 | 100 | 26 | 8 | 15 | 126 | 3000 | - | 12,64 € |
| PTA40-10-125 | - | 40 | M10 | 125 | 26 | 8 | 15 | 152 | 3000 | - | 12,80 € |
| Stainless steel foot | | | | | | | | | | | |
| PTA40-8-25/SS | PTA40-8-25/SS/SB | 40 | M8 | 25 | 26 | 6 | 15 | 51 | 3000 | - | 13,40 € |
| PTA40-8-50/SS | PTA40-8-50/SS/SB | 40 | M8 | 50 | 26 | 6 | 15 | 76 | 3000 | - | 13,81 € |
| PTA40-8-75/SS | PTA40-8-75/SS/SB | 40 | M8 | 75 | 26 | 6 | 15 | 101 | 3000 | - | 14,29 € |
| PTA40-10-25/SS | PTA40-10-25/SS/SB | 40 | M10 | 25 | 26 | 8 | 15 | 51 | 3000 | - | 14,59 € |
| PTA40-10-50/SS | PTA40-10-50/SS/SB | 40 | M10 | 50 | 26 | 8 | 15 | 76 | 3000 | - | 15,06 € |
| PTA40-10-75/SS | PTA40-10-75/SS/SB | 40 | M10 | 75 | 26 | 8 | 15 | 101 | 3000 | - | 15,51 € |
| PTA40-10-100/SS | PTA40-10-100/SS/SB | 40 | M10 | 100 | 26 | 8 | 15 | 126 | 3000 | - | 16,40 € |
| PTA40-10-125/SS | PTA40-10-125/SS/SB | 40 | M10 | 125 | 26 | 8 | 15 | 151 | 3000 | - | 17,05 € |

All dimensions in mm

StaSte Articulated levelling foot, pressed base Ø50

Accepts loads up to 4.000N

PTA50
PTA50ss

- **Tilting foot**
- Tilt up to +/- 5° from vertical
- The base of the stainless steel version is available with either a glossy or sandblasted finish
- Materials:


Steel version:

Base: Galvanised sheet steel C40
Spindle: Galvanised steel (nut not supplied)
Sole: Vulcanised NBR rubber, hardness 80° Shore

Stainless steel version:

Base: Sheet stainless steel 304
Spindle: Stainless steel 304 (nut not supplied)
Sole: Vulcanised NBR rubber, hardness 80° Shore

Stainless steel version, sanded finish

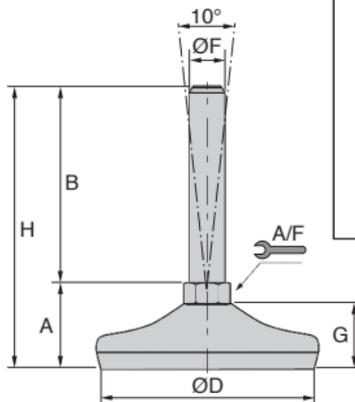

Option

- Other shaft dimensions are available on request

DISCOUNTS

| | | | | | |
|-------|------|-----|------|------|------------|
| Qty | 1+ | 15+ | 20+ | 25+ | 40+ |
| Disc. | List | -5% | -10% | -15% | On request |

| Part number | | ØD | ØF | B | A | A/F | G | H | Static load (N) | Stock* bright | Price each 1 to 14 |
|-----------------------------|--------------------|----|-----|-----|----|-----|----|-----|-----------------|---------------|--------------------|
| bright | sanded finish | | | | | | | | | | |
| Steel foot | | | | | | | | | | | |
| PTA50-10-100 | - | 50 | M10 | 100 | 29 | 14 | 19 | 129 | 4000 | ✓ | 18,07 € |
| PTA50-12-100 | - | 50 | M12 | 100 | 29 | 14 | 19 | 129 | 4000 | ✓ | 18,07 € |
| PTA50-12-150 | - | 50 | M12 | 150 | 29 | 14 | 19 | 179 | 4000 | - | 19,50 € |
| PTA50-16-75 | - | 50 | M16 | 75 | 29 | 16 | 19 | 104 | 4000 | ✓ | 18,55 € |
| PTA50-16-100 | - | 50 | M16 | 100 | 29 | 16 | 19 | 129 | 4000 | - | 19,82 € |
| PTA50-16-150 | - | 50 | M16 | 150 | 29 | 16 | 19 | 179 | 4000 | ✓ | 22,47 € |
| Stainless steel foot | | | | | | | | | | | |
| PTA50-10-75/SS | PTA50-10-75/SS/SB | 50 | M10 | 75 | 29 | 14 | 19 | 104 | 4000 | ✓ | 19,59 € |
| PTA50-10-125/SS | PTA50-10-125/SS/SB | 50 | M10 | 125 | 29 | 14 | 19 | 154 | 4000 | ✓ | 22,29 € |
| PTA50-12-75/SS | PTA50-12-75/SS/SB | 50 | M12 | 75 | 29 | 14 | 19 | 104 | 4000 | ✓ | 19,59 € |
| PTA50-12-125/SS | PTA50-12-125/SS/SB | 50 | M12 | 125 | 29 | 14 | 19 | 154 | 4000 | ✓ | 22,29 € |
| PTA50-16-75/SS | PTA50-16-75/SS/SB | 50 | M16 | 75 | 34 | 13 | 19 | 109 | 4000 | ✓ | 22,88 € |
| PTA50-16-100/SS | PTA50-16-100/SS/SB | 50 | M16 | 100 | 34 | 13 | 19 | 134 | 4000 | ✓ | 23,78 € |
| PTA50-16-150/SS | PTA50-16-150/SS/SB | 50 | M16 | 150 | 34 | 13 | 19 | 184 | 4000 | - | 26,16 € |

*Depending on availability - Dimensions in mm

Articulated levelling foot, pressed base Ø80 **Ste** **Sta**

PTA80

Accepts loads up to 10.000N

PTA80ss

- **Tilting foot**
- Tilt up to +/- 5° from vertical
- The base of the stainless steel version is available with either a glossy or sandblasted finish
- Materials:



Steel version:

Base: Galvanised sheet steel C40
 Spindle: Galvanised steel (nut not supplied)
 Sole: Vulcanised NBR rubber, hardness 80° Shore

Stainless steel version:

Base: Stainless steel sheet 304
 Spindle: Stainless steel 304 (nut not supplied)
 Sole: Vulcanised NBR rubber, hardness 80° Shore

Stainless steel version, sanded finish

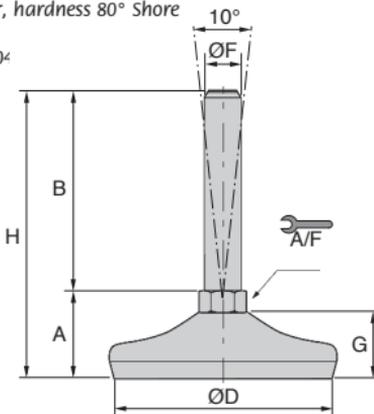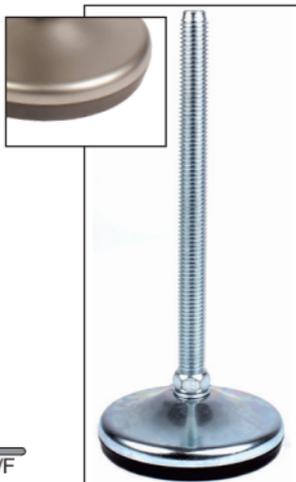

Option

- Other shaft dimensions are available on request

DISCOUNTS

| Qty | 1+ | 15+ | 20+ | 25+ | 40+ |
|-------|------|-----|------|------|------------|
| Disc. | List | -5% | -10% | -15% | On request |

| Part number | bright | sanded finish | ØD | ØF | B | A | A/F | G | H | Static load (N) | Stock* bright | Price each 1 to 14 |
|-----------------------------|--------------------|---------------|----|-----|-----|----|-----|----|-----|-----------------|---------------|--------------------|
| Steel foot | | | | | | | | | | | | |
| PTA80-12-100 | - | - | 80 | M12 | 100 | 35 | 14 | 25 | 135 | 10000 | ✓ | 25,69 € |
| PTA80-12-150 | - | - | 80 | M12 | 150 | 35 | 14 | 25 | 185 | 10000 | - | 28,59 € |
| PTA80-16-100 | - | - | 80 | M16 | 100 | 35 | 16 | 25 | 135 | 10000 | ✓ | 28,39 € |
| PTA80-16-150 | - | - | 80 | M16 | 150 | 35 | 16 | 25 | 185 | 10000 | - | 31,39 € |
| PTA80-20-100 | - | - | 80 | M20 | 100 | 36 | 20 | 25 | 136 | 10000 | - | 29,81 € |
| PTA80-20-150 | - | - | 80 | M20 | 150 | 36 | 20 | 25 | 186 | 10000 | - | 33,47 € |
| PTA80-20-200 | - | - | 80 | M20 | 200 | 36 | 20 | 25 | 236 | 10000 | ✓ | 36,54 € |
| Stainless steel foot | | | | | | | | | | | | |
| PTA80-12-100/SS | PTA80-12-100/SS/SB | | 80 | M12 | 100 | 35 | 14 | 25 | 135 | 10000 | ✓ | 39,22 € |
| PTA80-12-150/SS | PTA80-12-150/SS/SB | | 80 | M12 | 150 | 35 | 14 | 25 | 185 | 10000 | ✓ | 42,13 € |
| PTA80-16-100/SS | PTA80-16-100/SS/SB | | 80 | M16 | 100 | 35 | 13 | 25 | 135 | 10000 | - | 42,13 € |
| PTA80-16-150/SS | PTA80-16-150/SS/SB | | 80 | M16 | 150 | 35 | 13 | 25 | 185 | 10000 | ✓ | 45,07 € |
| PTA80-20-100/SS | PTA80-20-100/SS/SB | | 80 | M20 | 100 | 38 | 17 | 25 | 138 | 10000 | - | 47,26 € |
| PTA80-20-150/SS | PTA80-20-150/SS/SB | | 80 | M20 | 150 | 38 | 17 | 25 | 188 | 10000 | ↗ | 50,86 € |
| PTA80-20-200/SS | PTA80-20-200/SS/SB | | 80 | M20 | 200 | 38 | 17 | 25 | 238 | 10000 | ↗ | 56,36 € |

*Depending on availability - Dimensions in mm

Accepts loads up to 10.000N

PTAF80
PAMF80

- Tilting foot
- Tilt up to +/- 5° from vertical
- With non-slip sole
- Materials:

Steel version:

Base : Galvanised sheet steel C40
 Spindle: Galvanised steel (nut not supplied)
 Sole: Vulcanised NBR rubber, hardness 80° Shore


Stainless steel version:
 Base: Stainless steel sheet 304
 Spindle: Stainless steel 304 (nut not supplied)
 Sole: Vulcanised NBR rubber, 80° Shore

Advantages

- Easy to secure due to large distance between shaft and mounting hole

Option

- Other shaft dimensions are available on request

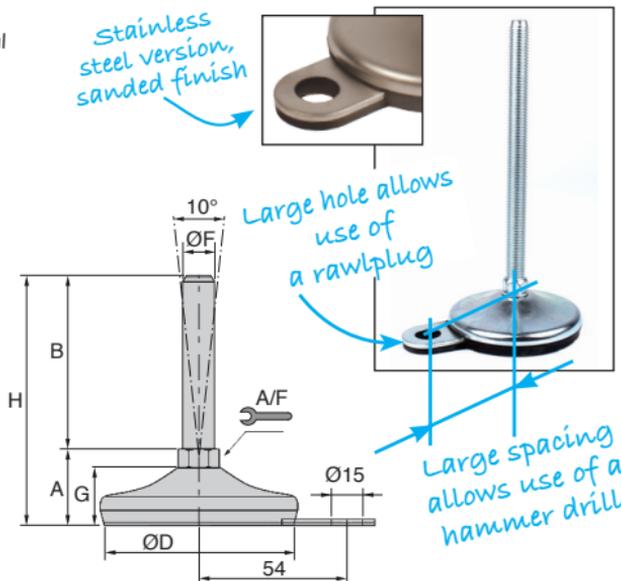**DISCOUNTS**

| Qty | 1+ | 6+ | 10+ | 15+ | 20+ |
|-------|------|-----|------|------|------------|
| Disc. | List | -5% | -10% | -15% | On request |

| Part number | Thread | Bright | | | | | | | Static load(N) | Price each | |
|-----------------------------|------------------|---------------|-----|-----|----|----|-----|-----|----------------|------------|---------|
| | | Sanded finish | ØD | ØF | B | A | A/F | G | | | H |
| Steel foot | | | | | | | | | | | |
| PTAF80-12-100 | - | 80 | M12 | 100 | 35 | 14 | 25 | 135 | 10000 | ✓ | 30,77 € |
| PTAF80-12-150 | - | 80 | M12 | 150 | 35 | 14 | 25 | 185 | 10000 | ✓ | 33,36 € |
| PTAF80-16-100 | - | 80 | M16 | 100 | 35 | 16 | 25 | 135 | 10000 | ✓ | 33,00 € |
| PTAF80-16-150 | - | 80 | M16 | 150 | 35 | 16 | 25 | 185 | 10000 | ✓ | 36,24 € |
| PTAF80-20-100 | - | 80 | M20 | 100 | 36 | 20 | 25 | 136 | 10000 | - | 34,74 € |
| PTAF80-20-150 | - | 80 | M20 | 150 | 36 | 20 | 25 | 186 | 10000 | - | 38,02 € |
| PTAF80-20-200 | - | 80 | M20 | 200 | 36 | 20 | 25 | 236 | 10000 | - | 41,38 € |
| Stainless steel foot | | | | | | | | | | | |
| PAMF80-12-100 | PAMF80-12-100/SB | 80 | M12 | 100 | 35 | 14 | 25 | 135 | 10000 | ✓ | 48,07 € |
| PAMF80-12-150 | PAMF80-12-150/SB | 80 | M12 | 150 | 35 | 14 | 25 | 185 | 10000 | ✓ | 50,94 € |
| PAMF80-16-75 | PAMF80-16-75/SB | 80 | M16 | 75 | 35 | 13 | 25 | 110 | 10000 | ✓ | 48,76 € |
| PAMF80-16-125 | PAMF80-16-125/SB | 80 | M16 | 125 | 35 | 13 | 25 | 160 | 10000 | ✓ | 52,44 € |
| PAMF80-16-175 | PAMF80-16-175/SB | 80 | M16 | 175 | 35 | 13 | 25 | 210 | 10000 | ✓ | 56,07 € |
| PAMF80-20-100 | PAMF80-20-100/SB | 80 | M20 | 100 | 38 | 17 | 25 | 138 | 10000 | - | 56,07 € |
| PAMF80-20-150 | PAMF80-20-150/SB | 80 | M20 | 150 | 38 | 17 | 25 | 188 | 10000 | - | 59,73 € |
| PAMF80-20-200 | PAMF80-20-200/SB | 80 | M20 | 200 | 38 | 17 | 25 | 238 | 10000 | - | 65,18 € |

*Depending on availability - Dimensions in mm

Articulated fixable foot, pressed bolt-down base Ø100 **Ste** **Sta**

PTAF100 PAMF100

Accepts loads up to 15.000N

- **Tilting foot**
- Tilt up to +/- 5° from vertical
- With non-slip sole
- Materials:


Steel version:

Base: Galvanised sheet steel C40
Spindle: Galvanised steel (nut not supplied)
Sole: Vulcanised NBR rubber, hardness 80° Shore

Stainless steel version:


Base: Stainless sheet steel 304
Spindle: Stainless steel plate 304 (nut not supplied)
Sole: Vulcanised NBR rubber, 80° Shore

Stainless steel version, sanded finish

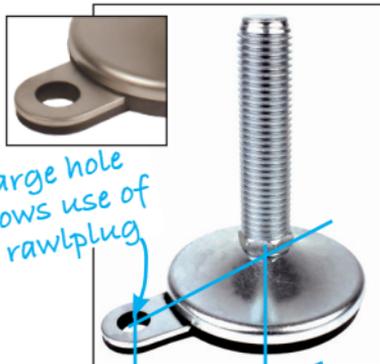

Large hole allows use of a rawlplug

Large spacing allows use of a hammer drill

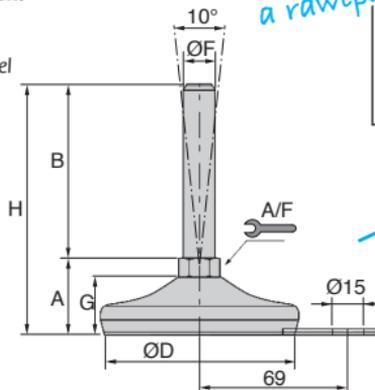

Advantages

- Easy to install due to large distance between shaft and mounting hole

Option

- Other shaft dimensions are available on request

DISCOUNTS

| Qty | 1+ | 6+ | 10+ | 15+ | 20+ |
|-------|------|-----|------|------|------------|
| Disc. | List | -5% | -10% | -15% | On request |

| Part number | Bright | Sanded finish | Thread | | | | | Static load (N) | Stock* Bright | Price each 1 to 5 | | |
|-----------------------------|-------------------|---------------|--------|-----|-----|------|-----|-----------------|------------------|----------------------|---|---------|
| | | | ØD | ØF | B | A | A/F | | | | | |
| Steel foot | | | | | | | | | | | | |
| PTAF100-16-100 | - | - | 100 | M16 | 100 | 38 | 16 | 28 | 137,5 | 15000 | ✓ | 38,65 € |
| PTAF100-16-150 | - | - | 100 | M16 | 150 | 38 | 16 | 28 | 187,5 | 15000 | ✓ | 41,69 € |
| PTAF100-16-200 | - | - | 100 | M16 | 200 | 38 | 16 | 28 | 237,5 | 15000 | ✓ | 42,87 € |
| PTAF100-20-100 | - | - | 100 | M20 | 100 | 39 | 20 | 28 | 138,5 | 15000 | - | 40,18 € |
| PTAF100-20-150 | - | - | 100 | M20 | 150 | 39 | 20 | 28 | 188,5 | 15000 | ✓ | 43,80 € |
| PTAF100-20-200 | - | - | 100 | M20 | 200 | 39 | 20 | 28 | 238,5 | 15000 | ✓ | 47,46 € |
| PTAF100-24-100 | - | - | 100 | M24 | 100 | 39 | 24 | 28 | 138,5 | 15000 | ✓ | 46,19 € |
| PTAF100-24-150 | - | - | 100 | M24 | 150 | 39 | 24 | 28 | 188,5 | 15000 | - | 50,12 € |
| Stainless steel foot | | | | | | | | | | | | |
| PAMF100-16-100 | PAMF100-16-100/SB | - | 100 | M16 | 100 | 39,5 | 13 | 30 | 139,5 | 15000 | ✓ | 69,93 € |
| PAMF100-16-150 | PAMF100-16-150/SB | - | 100 | M16 | 150 | 39,5 | 13 | 30 | 189,5 | 15000 | ✓ | 72,12 € |
| PAMF100-16-200 | PAMF100-16-200/SB | - | 100 | M16 | 200 | 39,5 | 13 | 30 | 239,5 | 15000 | - | 77,20 € |
| PAMF100-20-100 | PAMF100-20-100/SB | - | 100 | M20 | 100 | 43,0 | 17 | 30 | 143,0 | 15000 | - | 74,29 € |
| PAMF100-20-150 | PAMF100-20-150/SB | - | 100 | M20 | 150 | 43,0 | 17 | 30 | 193,0 | 15000 | - | 78,72 € |
| PAMF100-20-200 | PAMF100-20-200/SB | - | 100 | M20 | 200 | 43,0 | 17 | 30 | 243,0 | 15000 | - | 83,78 € |

*Depending on availability - Dimensions in mm

SteSta Articulated levelling foot, pressed base Ø100

Accepts loads up to 15.000N

PTA100
PTA100ss

- **Tilting foot**
- tilt up to +/- 5° from vertical
- The base of the stainless steel version is available with either a glossy or sandblasted finish
- Materials:


Steel version:

Base: Galvanised sheet steel C40
Spindle: Galvanised steel (nut not supplied)
Sole: Vulcanised NBR rubber, hardness 80° Shore

Stainless steel version:

Base: Stainless steel sheet 304
Spindle: Stainless steel plate 304 (nut not supplied)
Sole: Vulcanised NBR rubber, hardness 80° Shore

Stainless steel version, sanded finish

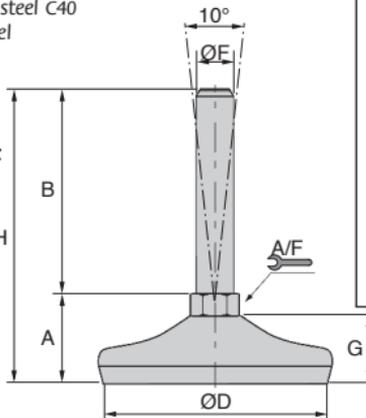

Option

- Other shaft dimensions are available on request

DISCOUNTS

| Qty | 1+ | 15+ | 20+ | 25+ | 40+ |
|-------|------|-----|------|------|------------|
| Disc. | List | -5% | -10% | -15% | On request |

| Part number | | ØD | ØF | B | A | A/F | G | H | Static load (N) | Stock* bright | Price each 1 to 14 |
|-----------------------------|---------------------|-----|-----|-----|------|-----|----|-------|-----------------|------------------|-----------------------|
| bright | sanded finish | | | | | | | | | | |
| Steel foot | | | | | | | | | | | |
| PTA100-16-100 | - | 100 | M16 | 100 | 38,0 | 16 | 28 | 137,5 | 15000 | ✓ | 31,39 € |
| PTA100-16-150 | - | 100 | M16 | 150 | 38,0 | 16 | 28 | 187,5 | 15000 | ✓ | 34,49 € |
| PTA100-16-200 | - | 100 | M16 | 200 | 38,0 | 16 | 28 | 237,5 | 15000 | - | 35,62 € |
| PTA100-20-100 | - | 100 | M20 | 100 | 39,0 | 20 | 28 | 138,5 | 15000 | ✓ | 32,90 € |
| PTA100-20-150 | - | 100 | M20 | 150 | 39,0 | 20 | 28 | 188,5 | 15000 | - | 36,54 € |
| PTA100-20-200 | - | 100 | M20 | 200 | 39,0 | 20 | 28 | 238,5 | 15000 | - | 40,18 € |
| PTA100-24-100 | - | 100 | M24 | 100 | 39,0 | 24 | 28 | 138,5 | 15000 | - | 38,90 € |
| PTA100-24-150 | - | 100 | M24 | 150 | 39,0 | 24 | 28 | 188,5 | 15000 | - | 42,67 € |
| Stainless steel foot | | | | | | | | | | | |
| PTA100-16-100/SS | PTA100-16-100/SS/SB | 100 | M16 | 100 | 39,5 | 13 | 30 | 139,5 | 15000 | ✓ | 61,08 € |
| PTA100-16-150/SS | PTA100-16-150/SS/SB | 100 | M16 | 150 | 39,5 | 13 | 30 | 189,5 | 15000 | - | 63,24 € |
| PTA100-16-200/SS | PTA100-16-200/SS/SB | 100 | M16 | 200 | 39,5 | 13 | 30 | 239,5 | 15000 | - | 68,36 € |
| PTA100-20-100/SS | PTA100-20-100/SS/SB | 100 | M20 | 100 | 43,0 | 17 | 30 | 143,0 | 15000 | - | 65,46 € |
| PTA100-20-150/SS | PTA100-20-150/SS/SB | 100 | M20 | 150 | 43,0 | 17 | 30 | 193,0 | 15000 | - | 69,78 € |
| PTA100-20-200/SS | PTA100-20-200/SS/SB | 100 | M20 | 200 | 43,0 | 17 | 30 | 243,0 | 15000 | - | 74,88 € |
| PTA100-24-100/SS | PTA100-24-100/SS/SB | 100 | M24 | 100 | 44,0 | 20 | 30 | 144,0 | 15000 | - | 70,52 € |
| PTA100-24-150/SS | PTA100-24-150/SS/SB | 100 | M24 | 150 | 44,0 | 20 | 30 | 194,0 | 15000 | - | 72,74 € |

*Depending on availability - Dimensions in mm

Pressed steel articulated foot Ø150 **SteSta**

PTA150 Accepts loads up to 40,000N PTA150ss

- Levelling foot
- Brilliant finish (Sand-blasted finish for base of the stainless steel version)
- Materials:

Steel version:

Base: Chromed steel sheet C40

Rod: Chromed steel (nut not supplied)

Sole: Vulcanised rubber NBR hardness

80° Shore


Stainless steel version:

Base: 304 stainless steel, brilliant or sand-blasted finish

Rod: 304 stainless steel (nut not supplied)

Sole: Vulcanised rubber NBR hardness 80° Shore

Sand-blasted stainless-steel version

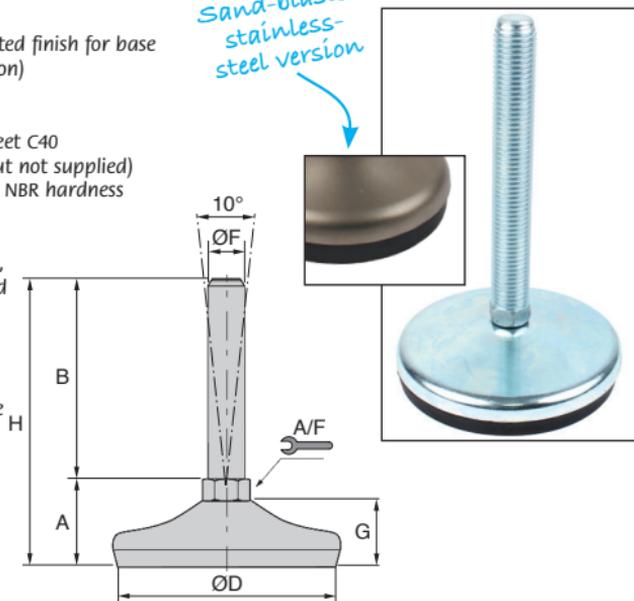

Options

- Other rod sizes are available

DISCOUNTS

| Qty | 1+ | 15+ | 20+ | 25+ | 40+ |
|-------|------|-----|------|------|------------|
| Disc. | List | -5% | -10% | -15% | On request |

| Part number | | ØD | ØF | B | A | A/F | G | H | Static load (N) | Price each 1 to 14 |
|-----------------------------|---------------------|-----|-----|-----|----|-----|----|-----|-----------------|--------------------|
| bright | sanded finish | | | | | | | | | |
| Steel foot | | | | | | | | | | |
| PTA150-24-100 | - | 150 | M24 | 100 | 44 | 24 | 35 | 144 | 40000 | 60,98 € |
| PTA150-24-150 | - | 150 | M24 | 150 | 44 | 24 | 35 | 194 | 40000 | 64,37 € |
| PTA150-24-200 | - | 150 | M24 | 200 | 44 | 24 | 35 | 244 | 40000 | 68,02 € |
| PTA150-24-250 | - | 150 | M24 | 250 | 44 | 24 | 35 | 294 | 40000 | 71,44 € |
| PTA150-30-100 | - | 150 | M30 | 100 | 44 | 30 | 35 | 145 | 40000 | 66,94 € |
| PTA150-30-150 | - | 150 | M30 | 150 | 44 | 30 | 35 | 195 | 40000 | 69,04 € |
| PTA150-30-200 | - | 150 | M30 | 200 | 44 | 30 | 35 | 245 | 40000 | 75,99 € |
| PTA150-30-250 | - | 150 | M30 | 250 | 44 | 30 | 35 | 295 | 40000 | 85,59 € |
| Stainless steel foot | | | | | | | | | | |
| PTA150-24-100/SS | PTA150-24-100/SS/SB | 150 | M24 | 100 | 49 | 20 | 35 | 149 | 40000 | 87,88 € |
| PTA150-24-150/SS | PTA150-24-150/SS/SB | 150 | M24 | 150 | 49 | 20 | 35 | 199 | 40000 | 92,71 € |
| PTA150-24-200/SS | PTA150-24-200/SS/SB | 150 | M24 | 200 | 49 | 20 | 35 | 249 | 40000 | 97,56 € |
| PTA150-24-250/SS | PTA150-24-250/SS/SB | 150 | M24 | 250 | 49 | 20 | 35 | 299 | 40000 | 102,39 € |
| PTA150-30-100/SS | PTA150-30-100/SS/SB | 150 | M30 | 100 | 50 | 26 | 35 | 150 | 40000 | 100,01 € |
| PTA150-30-150/SS | PTA150-30-150/SS/SB | 150 | M30 | 150 | 50 | 26 | 35 | 200 | 40000 | 107,08 € |
| PTA150-30-200/SS | PTA150-30-200/SS/SB | 150 | M30 | 200 | 50 | 26 | 35 | 250 | 40000 | 113,02 € |
| PTA150-30-250/SS | PTA150-30-250/SS/SB | 150 | M30 | 250 | 50 | 26 | 35 | 300 | 40000 | 118,93 € |

All dimensions in mm

Articulated foot with sheet metal base Ø50

Max load: 4000N
Rubber sole in **EPDM, blue**

PTA50SS/EB


- Articulated adjustable levelling feet
- Axial articulation +/- 10°
- With non-slip sole in EPDM Blue
- Stainless steel in shiny finish
- Materials:
 - Base: shiny 304 stainless steel sheet
 - Thread: 304 stainless steel, supplied without nut
 - Sole: EPDM blue

Options

- Other thread dimensions on request
- 316 grade Stainless steel on request

Advantages

- Hygienic special sole for easy cleaning.
- Food processing, Pharmaceutical and Chemical Environment

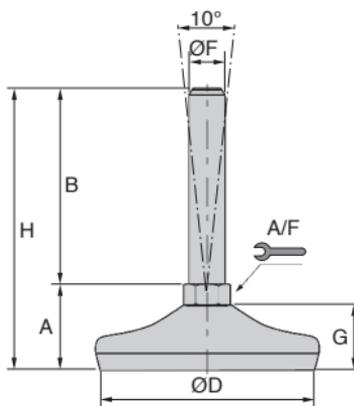

DISCOUNTS

| | | | | | |
|-------------|-----|------|------|------------|-----|
| Qty | 1+ | 6+ | 10+ | 15+ | 20+ |
| Disc. Price | -5% | -10% | -15% | On request | |

| Part number | ØD | ØF | B | A | A/F | G | H | Static load(N) | Price per unit 1 to 5 |
|--------------------|----|-----|-----|----|-----|----|-----|----------------|-----------------------|
| PTA50-10-75/SS/EB | 50 | M10 | 75 | 29 | 14 | 19 | 104 | 4,000 | 23,42 € |
| PTA50-10-125/SS/EB | 50 | M10 | 125 | 29 | 14 | 19 | 154 | 4,000 | 23,79 € |
| PTA50-12-75/SS/EB | 50 | M12 | 75 | 29 | 14 | 19 | 104 | 4,000 | 23,42 € |
| PTA50-12-125/SS/EB | 50 | M12 | 125 | 29 | 14 | 19 | 154 | 4,000 | 25,88 € |
| PTA50-16-75/SS/EB | 50 | M16 | 75 | 34 | 13 | 19 | 109 | 4,000 | 22,51 € |
| PTA50-16-100/SS/EB | 50 | M16 | 100 | 34 | 13 | 19 | 134 | 4,000 | 23,57 € |
| PTA50-16-150/SS/EB | 50 | M16 | 150 | 34 | 13 | 19 | 184 | 4,000 | 25,66 € |

* Depending on availability - Dimensions in mm



Articulated foot with sheet metal base Ø80

Max load: 10,000N

PTA80SS/EB

Rubber sole in **EPDM, blue**

- **Articulated adjustable levelling feet**
- Axial articulation +/- 10°
- With non-slip sole in EPDM Blue
- Stainless steel in shiny finish
- **Materials:**
 - Base: shiny 304 stainless steel sheet
 - Thread: 304 stainless steel, supplied without nut
 - Sole: EPDM blue

Options


- Other thread dimensions on request
- 316 grade Stainless steel on request

Advantages

- Hygienic special sole for easy cleaning.
- Food processing, Pharmaceutical and Chemical Environment

Food industry

Sole in EPDM, blue

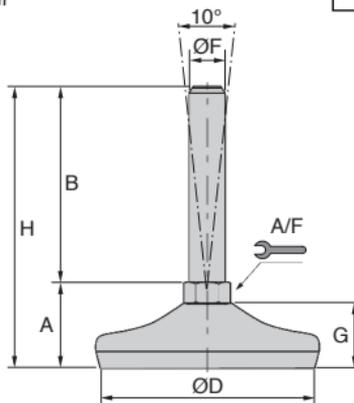

DISCOUNTS

| Qty | 1+ | 6+ | 10+ | 15+ | 20+ |
|-------|-------|-----|------|------|------------|
| Disc. | Price | -5% | -10% | -15% | On request |

| Part number | ØD | ØF | B | A | A/F | G | H | Static load(N) | Price per unit 1 to 5 |
|--------------------|----|-----|-----|----|-----|----|-----|----------------|-----------------------|
| PTA80-12-100/SS/EB | 80 | M12 | 100 | 35 | 14 | 25 | 135 | 10000 | 35,57 € |
| PTA80-12-150/SS/EB | 80 | M12 | 150 | 35 | 14 | 25 | 185 | 10000 | 38,15 € |
| PTA80-16-100/SS/EB | 80 | M16 | 100 | 35 | 13 | 25 | 135 | 10000 | 38,15 € |
| PTA80-16-150/SS/EB | 80 | M16 | 150 | 35 | 13 | 25 | 185 | 10000 | 40,63 € |
| PTA80-20-100/SS/EB | 80 | M20 | 100 | 38 | 17 | 25 | 138 | 10000 | 42,60 € |
| PTA80-20-150/SS/EB | 80 | M20 | 150 | 38 | 17 | 25 | 188 | 10000 | 45,72 € |
| PTA80-20-200/SS/EB | 80 | M20 | 200 | 38 | 17 | 25 | 238 | 10000 | 50,48 € |

* Depending on availability - Dimensions in mm

Articulated foot with sheet metal base Ø100

PTA100SS/EB

Max load: 15,000N
Rubber sole in **EPDM, blue**

- **Articulated adjustable levelling feet**
- Axial articulation +/- 10°
- With non-slip sole in EPDM Blue
- Stainless steel in shiny finish
- **Materials:**
 - Base: shiny 304 stainless steel sheet
 - Thread: 304 stainless steel, supplied without nut
 - Sole: EPDM blue

Options


- Other thread dimensions on request
- 316 grade Stainless steel on request

Advantages

- Hygienic special sole for easy cleaning.
- Food processing, Pharmaceutical and Chemical Environment

Food industry

Sole in EPDM, blue

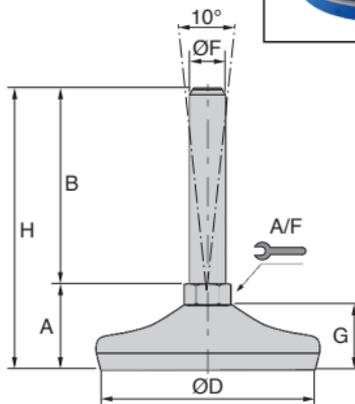

DISCOUNTS

| Qty | 1+ | 6+ | 10+ | 15+ | 20+ |
|-------------|----|-----|------|------|------------|
| Disc. Price | | -5% | -10% | -15% | On request |

| Part number | ØD | ØF | B | A | A/F | G | H | Static load(N) | Price per unit 1 to 5 |
|---------------------|-----|-----|-----|------|-----|----|-------|----------------|-----------------------|
| PTA100-16-100/SS/EB | 100 | M16 | 100 | 39.5 | 13 | 30 | 139.5 | 15000 | 54,84 € |
| PTA100-16-150/SS/EB | 100 | M16 | 150 | 39.5 | 13 | 30 | 189.5 | 15000 | 56,75 € |
| PTA100-16-200/SS/EB | 100 | M16 | 200 | 39.5 | 13 | 30 | 239.5 | 15000 | 61,21 € |
| PTA100-20-100/SS/EB | 100 | M20 | 100 | 43.0 | 17 | 30 | 143.0 | 15000 | 58,66 € |
| PTA100-20-150/SS/EB | 100 | M20 | 150 | 43.0 | 17 | 30 | 193.0 | 15000 | 62,42 € |
| PTA100-20-200/SS/EB | 100 | M20 | 200 | 43.0 | 17 | 30 | 243.0 | 15000 | 66,87 € |
| PTA100-24-100/SS/EB | 100 | M24 | 100 | 44.0 | 20 | 30 | 144.0 | 15000 | 63,08 € |
| PTA100-24-150/SS/EB | 100 | M24 | 150 | 44.0 | 20 | 30 | 194.0 | 15000 | 64,99 € |

* Depending on availability - Dimensions in mm



Articulated foot with sheet metal base Ø80

Max load: 10,000N

Rubber sole in **EPDM, blue**

PAMF80EB

- Articulated adjustable levelling feet
- Axial articulation +/- 10°
- With non-slip sole in EPDM Blue
- Stainless steel in shiny finish
- Materials:
 - Base: shiny 304 stainless steel sheet
 - Thread: 304 stainless steel, supplied without nut
 - Sole: EPDM blue

Options

- Other thread dimensions on request
- 316 grade Stainless steel on request

Advantages


- Hygienic special sole for easy cleaning
- Food processing, Pharmaceutical and Chemical Environment



Food industry

Hole for fixing bolt

Large spacing allows use of a hammer drill

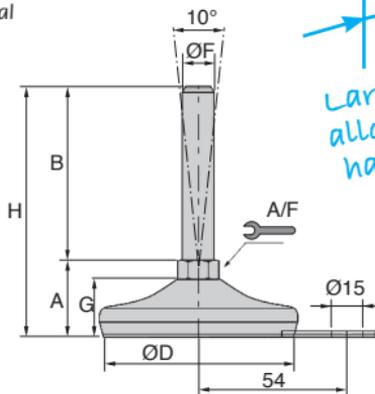

DISCOUNTS

| | | | | | |
|-------------|----|-----|------|------|------------|
| Qty | 1+ | 6+ | 10+ | 15+ | 20+ |
| Disc. Price | | -5% | -10% | -15% | On request |

| Part number | ØD | ØF | B | A | A/F | G | H | Static load(N) | Price per unit 1 to 5 |
|------------------|----|-----|-----|----|-----|----|-----|----------------|-----------------------|
| PAMF80-12-100/EB | 80 | M12 | 100 | 35 | 14 | 25 | 135 | 10000 | 39,71 € |
| PAMF80-12-150/EB | 80 | M12 | 150 | 35 | 14 | 25 | 185 | 10000 | 41,97 € |
| PAMF80-16-75/EB | 80 | M16 | 75 | 35 | 13 | 25 | 110 | 10000 | 40,25 € |
| PAMF80-16-125/EB | 80 | M16 | 125 | 35 | 13 | 25 | 160 | 10000 | 43,13 € |
| PAMF80-16-175/EB | 80 | M16 | 175 | 35 | 13 | 25 | 210 | 10000 | 45,97 € |
| PAMF80-20-100/EB | 80 | M20 | 100 | 38 | 17 | 25 | 138 | 10000 | 45,97 € |
| PAMF80-20-150/EB | 80 | M20 | 150 | 38 | 17 | 25 | 188 | 10000 | 48,81 € |
| PAMF80-20-200/EB | 80 | M20 | 200 | 38 | 17 | 25 | 238 | 10000 | 53,08 € |

*Within the limits of available stock - Dimensions in mm

Articulated foot with sheet metal base Ø100 Sta

PAMF100EB

Max load: 15,000N
Rubber sole in **EPDM, blue**



- Articulated adjustable levelling feet
- Axial articulation +/- 10°
- With non-slip sole in EPDM Blue
- Stainless steel in shiny finish
- Materials:
 - Base: shiny 304 stainless steel sheet
 - Thread: 304 stainless steel, supplied without nut
 - Sole: EPDM blue

Options

- Other thread dimensions on request
- 316 grade Stainless steel on request

Advantages

- Hygienic special pad for easy cleaning.
- Food processing, Pharmaceutical and Chemical Environment

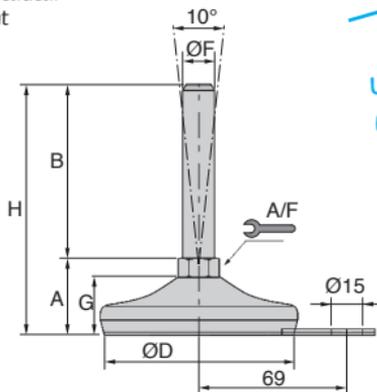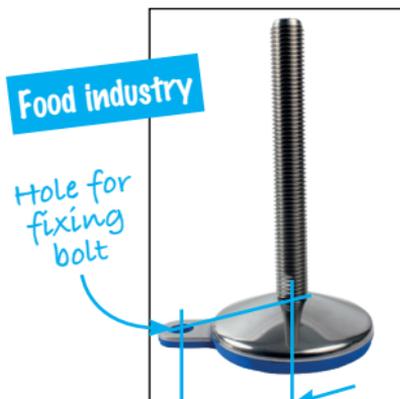

DISCOUNTS

| Qty | 1+ | 6+ | 10+ | 15+ | 20+ |
|-------------|-----|------|------|------------|-----|
| Disc. Price | -5% | -10% | -15% | On request | |

| Part number | Threading | | | B | A | A/F | G | H | Static load(N) | Price per unit 1 to 5 |
|-------------------|-----------|-----|-----|------|----|-----|-------|-------|----------------|-----------------------|
| | ØD | ØF | ØF | | | | | | | |
| PAMF100-16-100/EB | 100 | M16 | 100 | 39.5 | 13 | 30 | 139.5 | 15000 | 57,67 € | |
| PAMF100-16-150/EB | 100 | M16 | 150 | 39.5 | 13 | 30 | 189.5 | 15000 | 59,42 € | |
| PAMF100-16-200/EB | 100 | M16 | 200 | 39.5 | 13 | 30 | 239.5 | 15000 | 63,43 € | |
| PAMF100-20-100/EB | 100 | M20 | 100 | 43.0 | 17 | 30 | 143.0 | 15000 | 61,11 € | |
| PAMF100-20-150/EB | 100 | M20 | 150 | 43.0 | 17 | 30 | 193.0 | 15000 | 64,59 € | |
| PAMF100-20-200/EB | 100 | M20 | 200 | 43.0 | 17 | 30 | 243.0 | 15000 | 68,58 € | |

* Depending on availability - Dimensions in mm

Articulated fixable foot, pressed bolt-down base Ø120 **Sta**

PAMF120 Accepts loads up to 30 000N

Tilting foot


- Tilt up to +/- 5° from vertical
- With non-slip sole
- Materials:
 - Base: Stainless steel sheet 304
 - Spindle: Stainless steel 304 (nut not supplied)
 - Sole: Vulcanised NBR rubber, 80° Shore

Advantages

- Easy to secure due to large distance between shaft and mounting hole

Options

- Other shaft dimensions are available on request

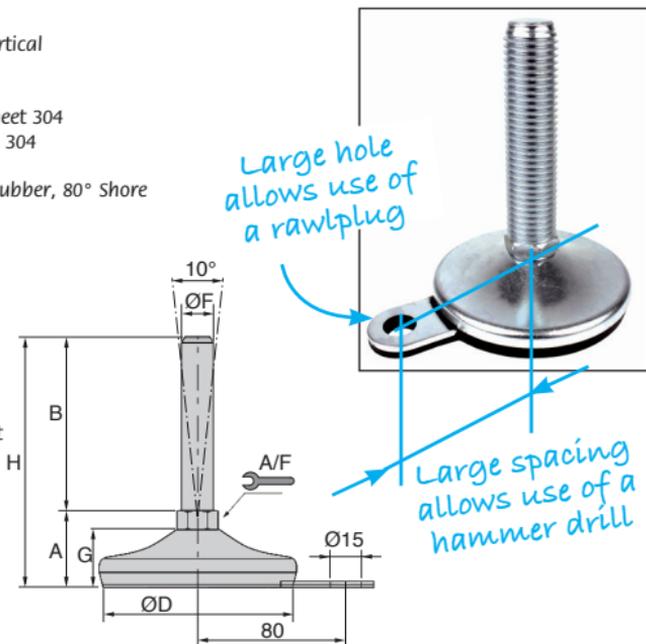

DISCOUNTS

| | | | | | |
|-------|------|-----|------|------|------------|
| Qty | 1+ | 6+ | 10+ | 15+ | 20+ |
| Disc. | List | -5% | -10% | -15% | On request |

| Part number | ØD | ØF | B | A | A/F | G | H | Static load (N) | Price each 1 to 5 |
|-------------------|-----|-----|-----|----|-----|----|-----|-----------------|-------------------|
| PAMF120-16-100/SS | 120 | M16 | 100 | 47 | 13 | 32 | 147 | 30000 | 75,62 € |
| PAMF120-16-150/SS | 120 | M16 | 150 | 47 | 13 | 32 | 197 | 30000 | 77,73 € |
| PAMF120-16-200/SS | 120 | M16 | 200 | 47 | 13 | 32 | 247 | 30000 | 81,44 € |
| PAMF120-20-100/SS | 120 | M20 | 100 | 47 | 17 | 32 | 147 | 30000 | 78,04 € |
| PAMF120-20-150/SS | 120 | M20 | 150 | 47 | 17 | 32 | 197 | 30000 | 81,10 € |
| PAMF120-20-200/SS | 120 | M20 | 200 | 47 | 17 | 32 | 247 | 30000 | 85,04 € |
| PAMF120-20-250/SS | 120 | M20 | 250 | 47 | 17 | 32 | 297 | 30000 | 89,94 € |
| PAMF120-24-150/SS | 120 | M24 | 150 | 49 | 20 | 32 | 199 | 30000 | 89,94 € |
| PAMF120-24-200/SS | 120 | M24 | 200 | 49 | 20 | 32 | 249 | 30000 | 94,51 € |
| PAMF120-24-250/SS | 120 | M24 | 250 | 49 | 20 | 32 | 299 | 30000 | 101,91 € |

Dimensions in mm