



Articulated foot with sheet metal base Ø80

Max load: 10,000N
Rubber sole in EPDM, blue

PTA80SS/EB

- Articulated adjustable levelling feet
- Axial articulation +/- 10°
- With non-slip sole in EPDM Blue
- Stainless steel in shiny finish
- Materials:
 - Base: shiny 304 stainless steel sheet
 - Thread: 304 stainless steel, supplied without nut
 - Sole: EPDM blue

Options


- Other thread dimensions on request
- 316 grade Stainless steel on request

Advantages

- Hygienic special sole for easy cleaning.
- Food processing, Pharmaceutical and Chemical Environment

Food industry

Sole in EPDM, blue

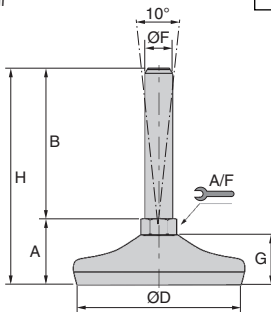

DISCOUNTS

| Qty | 1+ | 6+ | 10+ | 15+ | 20+ |
|-------|-------|-----|------|------|------------|
| Disc. | Price | -5% | -10% | -15% | On request |

| References | ØD | ØF | B | A | A/F | G | H | Static load(N) | Price per unit 1 to 5 |
|--------------------|----|-----|-----|----|-----|----|-----|----------------|-----------------------|
| PTA80-12-100/SS/EB | 80 | M12 | 100 | 35 | 14 | 25 | 135 | 10000 | 29,62€ |
| PTA80-12-150/SS/EB | 80 | M12 | 150 | 35 | 14 | 25 | 185 | 10000 | 31,76€ |
| PTA80-16-100/SS/EB | 80 | M16 | 100 | 35 | 13 | 25 | 135 | 10000 | 31,76€ |
| PTA80-16-150/SS/EB | 80 | M16 | 150 | 35 | 13 | 25 | 185 | 10000 | 33,84€ |
| PTA80-20-100/SS/EB | 80 | M20 | 100 | 38 | 17 | 25 | 138 | 10000 | 35,47€ |
| PTA80-20-150/SS/EB | 80 | M20 | 150 | 38 | 17 | 25 | 188 | 10000 | 38,07€ |
| PTA80-20-200/SS/EB | 80 | M20 | 200 | 38 | 17 | 25 | 238 | 10000 | 42,04€ |

* Depending on availability - Dimensions in mm

Our other products



ZG0

Plastic spur gear,
Machined plastic
(delrin)



PRF-P

Aluminium profile feet
support, For feet or
casters



LRM

Trapezoidal bronze
nut, Bronze - 1 thread



RJUM05

Dyrilin R® linear
bearing housing,
Closed - Long



AHEX

Hexagonal shaft,
Hexagonal shaft



VB

Small 6 lobe threaded
handle - female,
Duroplast - Stainless
steel



LVT

Miniature motorised
actuator 1A, 1 amper



BOX-TOR-D

Box set of Nitrile O-
rings in nitrile, 18.00 x
2.00mm to 50.00 x
5.00



RAGFLOW

Floway2® roller track,
Roller track



HTD14M_55

HTD Heavy duty
timing pulley, HTD14
Steel



HK

Manual locking clamp,
Manual locking clamp
LRX



MBF

Threaded blocking
clamp, Threaded
locking clamp

Complementary products



PTA50ssEB

Articulated foot with
sheet metal base
Ø50, Articulated foot



PTA100ssEB

Articulated foot with
sheet metal base
Ø100, Articulated foot



PAMF80EB

Articulated foot with
sheet metal base
Ø80, Articulated foot



PAMF100EB

Articulated foot with
sheet metal base
Ø100, Articulated foot