

# Articulated fixable foot, pressed bolt-down base Ø80 **SteSta**

## PTAF80 PAMF80

Accepts loads up to 10.000N

- **Tilting foot**
- Tilt up to +/- 5° from vertical
- With non-slip sole
- Materials:

### Steel version:

Base : Galvanised sheet steel C40

Spindle: Galvanised steel (nut not supplied)

Sole: Vulcanised NBR rubber, hardness 80° Shore


### Stainless steel version:

Base: Stainless steel sheet 304

Spindle: Stainless steel 304 (nut not supplied)

Sole: Vulcanised NBR rubber, 80° Shore

Stainless steel version, sanded finish

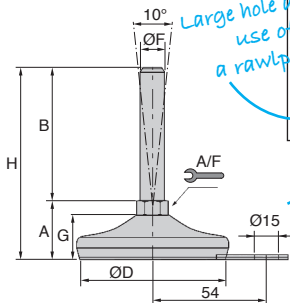

### Advantages

- Easy to secure due to large distance between shaft and mounting hole

### Option

- Other shaft dimensions are available on request

### DISCOUNTS

Qty	1+	6+	10+	15+	20+
Disc.	List	-5%	-10%	-15%	On request

Références		Thread		ØD	B	A	A/F	G	H	Static load(N)	Price each 1 to 5
Bright	Sanded finish	ØF									
<b>Steel foot</b>											
PTAF80-12-100	-	80	M12	100	35	14	25	135	10000	✓	26,59 €
PTAF80-12-150	-	80	M12	150	35	14	25	185	10000	✓	28,83 €
PTAF80-16-100	-	80	M16	100	35	16	25	135	10000	✓	28,51 €
PTAF80-16-150	-	80	M16	150	35	16	25	185	10000	✓	31,31 €
PTAF80-20-100	-	80	M20	100	36	20	25	136	10000	✓	30,01 €
PTAF80-20-150	-	80	M20	150	36	20	25	186	10000	-	32,85 €
PTAF80-20-200	-	80	M20	200	36	20	25	236	10000	-	35,75 €
<b>Stainless steel foot</b>											
PAMF80-12-100	PAMF80-12-100/SB	80	M12	100	35	14	25	135	10000	✓	41,53 €
PAMF80-12-150	PAMF80-12-150/SB	80	M12	150	35	14	25	185	10000	-	44,02 €
PAMF80-16-75	PAMF80-16-75/SB	80	M16	75	35	13	25	110	10000	✓	42,13 €
PAMF80-16-125	PAMF80-16-125/SB	80	M16	125	35	13	25	160	10000	✓	45,31 €
PAMF80-16-175	PAMF80-16-175/SB	80	M16	175	35	13	25	210	10000	✓	48,45 €
PAMF80-20-100	PAMF80-20-100/SB	80	M20	100	38	17	25	138	10000	-	48,45 €
PAMF80-20-150	PAMF80-20-150/SB	80	M20	150	38	17	25	188	10000	✓	51,61 €
PAMF80-20-200	PAMF80-20-200/SB	80	M20	200	38	17	25	238	10000	✓	56,31 €

\*Depending on availability - Dimensions in mm

## Our other products



T5-10ECO

T type timing pulley,  
Economy range - T5  
aluminium




GLB

Small 6 lobe threaded  
handle - female,  
Technopolymer -  
Stainless steel



PW\_PWG15

Wheel - precision  
range, Bronze

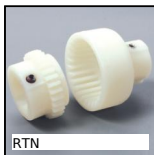

RTN

BoWex® curved tooth  
gear coupling, Nylon



ACLEPP

Right angled bracket  
for aluminium profile,  
2 holes



BABS

630 Stainless steel  
compact ball pin,  
Hardened stainless  
steel




BEAB

Knob star grip  
antibacterial, Star,  
anti-bacterial



NT61

 Spur gear coaxial  
gearbox, from 5 to 14  
Nm - In-line



LFM

Steel leadscrew,  
Medium carbon steel -  
1 thread



DOG111

Motor-gearbox 12V  
and 24V DC, from 1.5  
to 6 Nm



CHAR5050\_Z

Spring hinge, screwed



CHAEpac

Square decorative  
screwed hinges,  
carbon fibre  
reinforced

## Complementary products



PAMF120

Articulated fixable  
foot, pressed bolt-  
down base Ø 120, Ø  
120



PTKFss

Fixable foot for the  
food industry,  
Stainless steel - 3-A  
standard