

Stack Threaded eye hook stainless steel

Diameter M6 to M12

 
PTBss

Eye bolt

- Material : Stainless steel 316
- Product carries no certification marking

Utilisation

The breaking strength is obtained by multiplying the SWL by a factor of safety of 4



INCREASED STOCK


DISCOUNTS

Qty	1+	20+	40+	60+	80+	100+
Disc.	List	-5%	-10%	-15%	-20%	On request

Part number	ØM	L	ØA	ØB	CMU (kg)	Weight (kg)	Stock*	Price each 1 to 19
PTB6-40/SS	M6	40	12	22	120	0,020	✓	5,03 €
PTB6-60/SS	M6	60	12	22	120	0,030	✓	5,39 €
PTB6-80/SS	M6	80	12	22	120	0,030	✓	5,79 €
PTB8-60/SS	M8	60	14	26	225	0,050	✓	7,03 €
PTB8-80/SS	M8	80	14	26	225	0,055	-	7,70 €
PTB8-100/SS	M8	100	14	26	225	0,060	✓	8,52 €
PTB10-100/SS	M10	100	16	30	375	0,105	✓	13,16 €
PTB12-120/SS	M12	120	16	35	600	0,165	✓	20,71 €

Dimensions in mm

Our other products

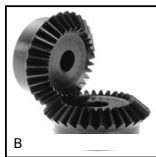

B
Steel bevel gear, 1:1



PCC50K
Chain sprocket with
hardened teeth,
12.7mm (DIN08B-1)



SH1
Parallel axis helical
gear, Machined plastic
(delrin)



AC
Strike for toggle latch,
12mm



PLA
Flat magnet, Flat
magnet



GCH
Linear ball slide Eco
Range, economy
range



DOMI30
Accessories, Turntable



COA-COG
Surface mounting
plate, Surface
mounting plate for
clevis



HLU
Spoked handwheel
without handle,
Aluminium



SNG
Stainless/Polymer
pillow block bearing,
Cast iron - Split pillow



DOMI50
Domino 50 adjustable
slide, Slide DOMILINE
50 with counter and



PSG25
Spur gear - precision
range, Pre-hardened
Steel 35NCD6

 
Complementary products




TAC_SS
Stainless steel rigging
screw (hook/eye),
Stainless steel



TCC
Rigging screw
(hook/hook), Steel



 CAB
Stainless steel cable,
Stainless steel



CAB
Galvanised steel
cable, Galvanised
steel