

Threaded eye hook **stainless steel** **Sta Stock**

PTBss


Diameter from M6 to M12

Eye bolt

- Material : Stainless steel 316
- Product carries no certification marking

Utilisation

The breaking strength is obtained by multiplying the SWL by a factor of safety of 4

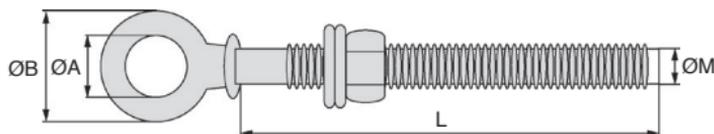

DISCOUNTS

Qty	1+	5+	10+	20+	30+	50+
Disc. Prix		-5%	-10%	-15%	-20%	On request

Part number	ØM	L	ØA	ØB	SWL (kg)	Weight (kg)	Stock*	Price each 1 to 4
PTB6-40/SS	M6	40	12	22	120	0,020	✓	5,26 €
PTB6-60/SS	M6	60	12	22	120	0,030	✓	5,63 €
PTB6-80/SS	M6	80	12	22	120	0,030	✓	6,05 €
PTB8-60/SS	M8	60	14	26	225	0,050	✓	7,36 €
PTB8-80/SS	M8	80	14	26	225	0,055	✓	8,06 €
PTB8-100/SS	M8	100	14	26	225	0,060	✓	8,91 €
PTB10-100/SS	M10	100	16	30	375	0,105	✓	13,79 €
PTB12-120/SS	M12	120	16	35	600	0,165	✓	21,69 €

*Depending on availability - Dimensions in mm