

Tensioner pulley



PTGP

For flat belts

- Idler pulley

- Material:

PA6 reinforced with 30% fibreglass


Steel bearing

- Max speed 5,000 RPM

(Except for PTGP30 + PTGP32 = 9,000 RPM)



INCREASED STOCK

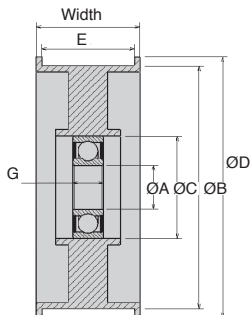

DISCOUNTS

Qty	1+	10+	25+	50+
Disc.	List	-5%	-10%	On request


Part number	ØD	Width		ØB	Bearing	ØC	ØA	E	G	For shaft	Stock*	Price each 1 to 9
		L	L									
PTGP30-9-8	40	13,2	30	608	2ZZ	20	8	9,2	7	AXTR-M8	✓	12,72 €
PTGP32-13-8	42	17,2	32	608	2ZZ	22	8	13,2	7	AXTR-M8	-	12,92 €
PTGP50-18-17	62	22,5	50	6203	2RS	38	17	18,3	12	AXTR-M12	✓	14,16 €
PTGP50-20-17	62	26	50	6203	2RS	38	17	20,3	12	AXTR-M12	✓	14,16 €
PTGP75-25-17	87	29,5	75	6203	2RS	38	17	25,3	12	AXTR-M12	✓	16,84 €
PTGP75-31-17	87	35,5	75	6203	2RS	38	17	31,3	12	AXTR-M12	-	19,77 €
PTGP75-31-17D	87	35,5	75	6203	2RS	38	17	31,3	24	AXTR-M12	-	25,57 €
PTGP90-18-17	102	22,5	90	6203	2RS	38	17	18,3	12	AXTR-M12	-	28,50 €
PTGP90-31-17	102	35,5	90	6203	2RS	38	17	31,3	12	AXTR-M12	-	28,75 €
PTGP90-31-17D	102	35,5	90	6203	2RS	38	17	31,3	24	AXTR-M12	-	29,25 €
PTGP90-36-17D	102	40,5	90	6203	2RS	38	17	36,3	24	AXTR-M12	-	29,52 €
PTGP115-36-17	127	30,5	115	6203	2RS	38	17	26,6	12	AXTR-M12	-	34,60 €

Dimensions in mm

Our other products



 CDPC
Flanged drill bushing,
Steel



QN
Single row cylindrical
roller bearing, Free
outer ring



LVT
Miniature motorised
actuator 4A, 4 amperes



MRAeco
Low cost quick link,
Steel



gt64
Rotating bent lever,
Common applications



HTD14M_85
HTD Heavy duty
timing pulley, HTD14
Steel



CHAupa
Front hinge, 270°



VTAP
Magnetic head screw,
With rubber coating
With rubber coating



BS3
Panamech, Multi-
Beam stainless steel,
Stainless steel - with



PSG05HC
Skive hobbled spur
gears - precision
range, Case hardened




BFD
Locking pin for bush,
+180°C



PTA150
Articulated levelling
foot, pressed base
Ø150, Ø150

 Complementary products



AXTR
Axle for tensioner
pulley, Shaft



PTGR
Tensioner pulley, For
round belts



PTGT
Tensioner pulley, For
V belts