

Tensioner pulley



PTGP

For flat belts

- Idler pulley

- Material:

PA6 reinforced with 30% fibreglass


Steel bearing

- Max speed 5,000 RPM

(Except for PTGP30 + PTGP32 = 9,000 RPM)



INCREASED STOCK

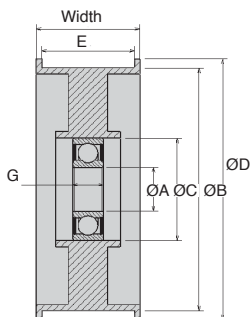

DISCOUNTS

Qty	1+	10+	25+	50+
Disc.	List	-5%	-10%	On request

Part number	ØD	Width		ØB	Bearing	ØC	ØA	E	G	For shaft	Stock*	Price each 1 to 9
		L	L									
PTGP30-9-8	40	13,2	30	608	2ZZ	20	8	9,2	7	AXTR-M8	✓	12,72 €
PTGP32-13-8	42	17,2	32	608	2ZZ	22	8	13,2	7	AXTR-M8	-	12,92 €
PTGP50-18-17	62	22,5	50	6203	2RS	38	17	18,3	12	AXTR-M12	✓	14,16 €
PTGP50-20-17	62	26	50	6203	2RS	38	17	20,3	12	AXTR-M12	✓	14,16 €
PTGP75-25-17	87	29,5	75	6203	2RS	38	17	25,3	12	AXTR-M12	✓	16,84 €
PTGP75-31-17	87	35,5	75	6203	2RS	38	17	31,3	12	AXTR-M12	-	19,77 €
PTGP75-31-17D	87	35,5	75	6203	2RS	38	17	31,3	24	AXTR-M12	-	25,57 €
PTGP90-18-17	102	22,5	90	6203	2RS	38	17	18,3	12	AXTR-M12	-	28,50 €
PTGP90-31-17	102	35,5	90	6203	2RS	38	17	31,3	12	AXTR-M12	-	28,75 €
PTGP90-31-17D	102	35,5	90	6203	2RS	38	17	31,3	24	AXTR-M12	-	29,25 €
PTGP90-36-17D	102	40,5	90	6203	2RS	38	17	36,3	24	AXTR-M12	-	29,52 €
PTGP115-36-17	127	30,5	115	6203	2RS	38	17	26,6	12	AXTR-M12	-	34,60 €

Dimensions in mm

Our other products



NK40

Drylin®N miniature guiding system, Width 40 mm



S2B

Short linear bearing housing, Closed - Slim



RDE-N

Sealing washer Hygienic Usit®, Stainless steel - Black EPDM



M0

Worm and wheel set, Hardened steel



SH1

Parallel axis helical gear, Steel 20NCD2



TSM T10M

T type timing belt per metre, T5 Steel cored polyurethane




PM3

Worm and wheel set, Hardened steel




YG1

 HEAVY DUTY spur gear, Steel 35NCD6



RPP5

 RPP heavy duty timing belt, RPP5



PF45

Worm and wheel gear reducer, up to 40 Nm



H1


Crossed helical gear, crossed axis at 90°



CHAR7530


Spring hinge, welded

Complementary products

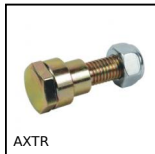

AXTR

Axle for tensioner pulley, Shaft

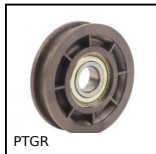

PTGR

Tensioner pulley, For round belts



PTGT

Tensioner pulley, For V belts