


- **Idler pulley**
- **Materials:**
  - PA6 reinforced with 30% fibreglass
  - Steel bearing
- Max speed 5,000 RPM

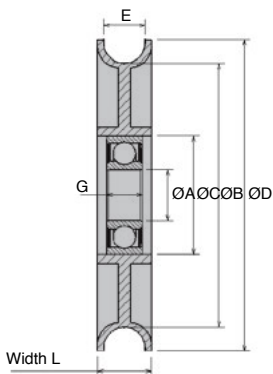

### DISCOUNTS

Qty	1+	10+	25+	50+
Disc. List	-5%	-10%	On request	

Part number	For round belt	ØD	Width L	ØB	Bearing	C	ØA	E	G	For shaft	Price each 1 to 9
PTGR62-10-17	Ø10	76	18	62	6203 2RS	38	17	10,3	12	AXTR-M12	17,24 €
PTGR89-14-17	Ø14	105	18	89	6203 2RS	38	17	14,3	12	AXTR-M12	21,52 €
PTGR95-11-17	Ø11	114	20	95	6203 2RS	38	17	11,3	12	AXTR-M12	25,77 €

Dimensions in mm

## Our other products



SH1

Parallel axis helical gear, Steel 20NCD2



GCH

Linear ball slide Eco Range, economy range



CAP805

Slat top chain stainless steel, Large range 805



SDG

Adjustable guide support bracket, Plastic




SLBW

Indexing plunger, weldable, Steel



PGM86-M5

 Pull handle, Thermoplastic



GMC

Flat profile - Round guide, Flat profile - round guide



H1

Crossed helical gear crossed axis at 90°, Steel 20NCD2



CHA135

Screwed hinge, 135 degrees



RJA00\_02

Sealing strip, Clipping



AK

Bellows coupling Gerwah®, from 36 to 800Nm



FF30

Offset spur gear reducer, from 21.50 to 83 Nm

## Complementary products



AXTR

Axle for tensioner pulley, Shaft



PTGP

Tensioner pulley, For flat belts



PTGT

Tensioner pulley, For V belts