


- **Idler pulley**
- **Materials:**
  - PA6 reinforced with 30% fibreglass
  - Steel bearing
- **Max speed 5,000 RPM**

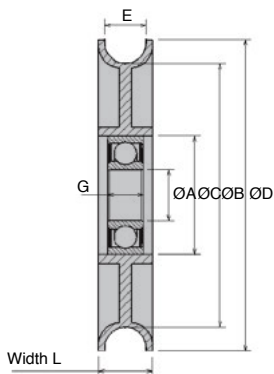

### DISCOUNTS

<b>Qty</b>	1+	10+	25+	50+
<b>Disc. List</b>	-5%	-10%	On request	

Part number	For round belt	ØD	Width L	ØB	Bearing	C	ØA	E	G	For shaft	Price each 1 to 9
PTGR62-10-17	Ø10	76	18	62	6203 2RS	38	17	10,3	12	AXTR-M12	17,24 €
PTGR89-14-17	Ø14	105	18	89	6203 2RS	38	17	14,3	12	AXTR-M12	21,52 €
PTGR95-11-17	Ø11	114	20	95	6203 2RS	38	17	11,3	12	AXTR-M12	25,77 €

Dimensions in mm

## Our other products



J64  
Spur gear coaxial gearbox, from 0.57 to 2.25 Nm - Inline



GTC  
Belt tensioner, For standard applications



GSA\_A  
Adjustable gas spring, Steel



VHTM  
Hexagonal headed screw Hygienic Design®, Stainless steel



MAC  
Carabiner DIN5299 steel, Steel



ERF  
Quick fitting threaded cable terminal, Cable terminal with threaded ...



RBG  
Wheel, Grey rubber - Polypropylene rim



HCV  
V-rail guidance Simple Select® system, on rail



TIFss  
Threaded stud - DIN976A, Stainless steel



T5M\_T10M  
T type timing belt per metre, T5 Steel cored polyurethane

 


WS10  
Drylin® W rail, Rail



PV1R  
Adjustable suction-cup support, Standard grip

## Complementary products



AXTR  
Axle for tensioner pulley, Shaft



PTGP  
Tensioner pulley, For flat belts



PTGT  
Tensioner pulley, For V belts