

Tensioner pulley

Stock

PTGR

For **round belts**

- Idler pulley

- Materials:


PA6 reinforced with 30% fibreglass

Steel bearing

- Max speed 5,000 RPM

Accessories

- AXTR shaft (tome 4 p.149)

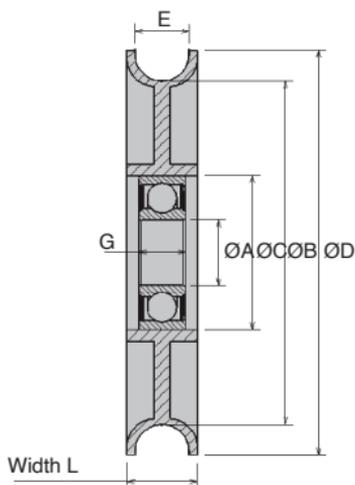

DISCOUNTS

| | | | | |
|-------|------|-----|------|------------|
| Qty | 1+ | 10+ | 25+ | 50+ |
| Disc. | List | -5% | -10% | On request |


| Part number | For round belt | ØD | Width L | ØB | Bearing | C | ØA | E | G | For shaft | Stock* | Price each 1 to 9 |
|--------------|----------------|-----|---------|----|----------|----|----|------|----|-----------|--------|-------------------|
| PTGR62-10-17 | Ø10 | 76 | 18 | 62 | 6203 2ZZ | 38 | 17 | 10,3 | 12 | AXTR-M12 | ✓ | 15,87 € |
| PTGR89-14-17 | Ø14 | 105 | 18 | 89 | 6203 2RS | 38 | 17 | 14,3 | 12 | AXTR-M12 | ✓ | 18,20 € |
| PTGR95-11-17 | Ø11 | 114 | 20 | 95 | 6203 2RS | 38 | 17 | 11,3 | 12 | AXTR-M12 | ✓ | 21,85 € |

*Depending on availability - Dimensions in mm

- **Idler pulley**
- Material:
PA6 reinforced with 30% fibreglass
steel bearing
- Max speed 5,000 RPM

Accessories

- AXTR shaft (tome 4 p.149)

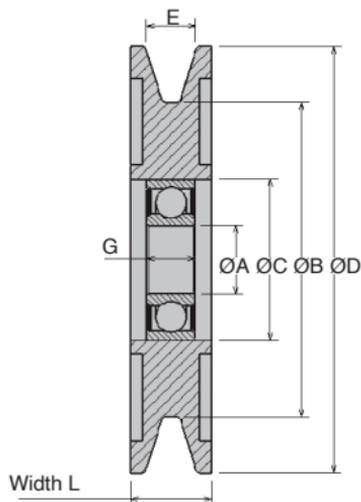

DISCOUNTS

| | | | | |
|-------|------|-----|------|------------|
| Qty | 1+ | 10+ | 25+ | 50+ |
| Disc. | List | -5% | -10% | On request |

| Part number | For V belt | Width ØD L | ØB | Bearing | C | ØA | E | G | For shaft | Stock* | Price each 1 to 9 |
|--------------|------------|---------------|----|----------|----|----|------|----|-----------|--------|----------------------|
| PTGT49-13-17 | A | 76 17 | 49 | 6203 2RS | 38 | 17 | 13,3 | 12 | AXTR-M12 | ✓ | 13,98 € |
| PTGT75-13-17 | SPA | 102 17 | 75 | 6203 2RS | 38 | 17 | 12,8 | 12 | AXTR-M12 | ✓ | 15,62 € |
| PTGT96-15-17 | XPB | 127 20,5 | 96 | 6203 2RS | 38 | 17 | 15,8 | 12 | AXTR-M12 | ✓ | 20,96 € |

*Depending on availability - Dimensions en mm

Tensioner pulley

Stock

PTGP

For flat belts

- Idler pulley

- Material:

PA6 reinforced with 30% fibreglass


Steel bearing

- Max speed 5,000 RPM

(Except for PTGP30 and PTGP32/9,000 RPM)

Accessories

- AXTR shaft (tome 4 p.149)

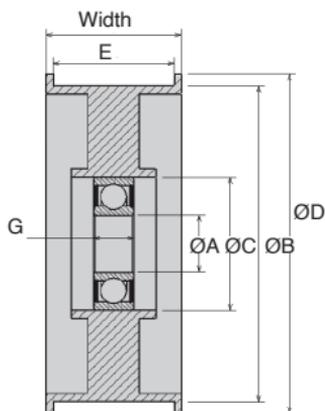

DISCOUNTS

| | | | | |
|-------|------|------|------|------------|
| Qty | 1+ | 10+ | 25+ | 50+ |
| Disc. | List | -20% | -30% | On request |

| Part number | ØD | Width | | ØB | Bearing | ØC | ØA | E | G | For shaft | Stock* | Price each |
|---------------|----|-------|--|----|----------|----|----|------|----|-----------|--------|------------|
| | | L | | | | | | | | | | 1 to 9 |
| PTGP30-9-8 | 40 | 15 | | 30 | 608 ZZ | 20 | 8 | 9,2 | 7 | AXTR-M8 | ✓ | 11,71 € |
| PTGP32-13-8 | 42 | 19 | | 32 | 608 ZZ | 22 | 8 | 13,2 | 7 | AXTR-M8 | ✓ | 11,84 € |
| PTGP50-18-17 | 62 | 24 | | 50 | 6203 2RS | 38 | 17 | 18,3 | 12 | AXTR-M12 | ✓ | 12,79 € |
| PTGP50-20-17 | 62 | 26 | | 50 | 6203 2RS | 38 | 17 | 20,3 | 12 | AXTR-M12 | ✓ | 15,78 € |
| PTGP75-25-17 | 87 | 30,5 | | 75 | 6203 2RS | 38 | 17 | 25,3 | 12 | AXTR-M12 | ✓ | 16,95 € |
| PTGP75-31-17 | 87 | 36,5 | | 75 | 6203 2RS | 38 | 17 | 31,3 | 12 | AXTR-M12 | ✓ | 16,12 € |
| PTGP75-31-17D | 87 | 36,5 | | 75 | 6203 2RS | 38 | 17 | 31,3 | 24 | AXTR-M12 | ✓ | 20,90 € |

*Depending on availability - Dimensions in mm


- Shaft for idler pulley

- Material:

Zinc plated C45 steel

Accessories

- Compatible with PTGP, PTGT and PTGR tensioner pulleys (tome 4 p.146, p.147, p.148)

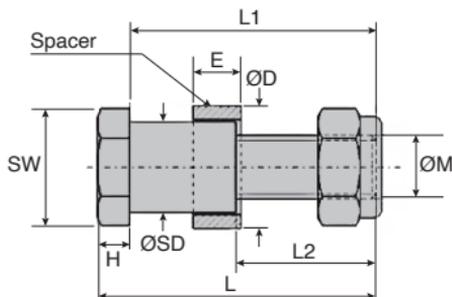

DISCOUNTS

| | | | | |
|-------|------|------|------|------------|
| Qty | 1+ | 10+ | 25+ | 50+ |
| Disc. | List | -20% | -30% | On request |

| Part number | ØM | ØSD | ØD | L | L1 | L2 | E | Across faces | | | Stock* | Price each 1 to 9 |
|-------------|-----|-----|----|----|----|------|---|--------------|---|--|--------|----------------------|
| | | | | | | | | SW | H | | | |
| AXTR-M8 | M8 | 8 | 12 | 30 | 25 | 14,5 | 4 | 13 | 5 | | ✓ | 7,92 € |
| AXTR-M12 | M12 | 17 | 23 | 53 | 47 | 26,5 | 9 | 22 | 6 | | ✓ | 7,59 € |

*Depending on availability - Dimensions in mm