

Tensioner pulley

New

PTGR

For round belts


- **Idler pulley**

- **Materials:**

PA6 reinforced with 30% fibreglass

Steel bearing

- Max speed 5,000 RPM

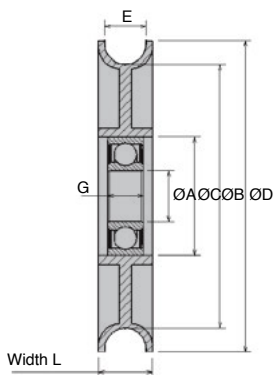

DISCOUNTS

Qty	1+	10+	25+	50+
Disc. List	-5%	-10%	On request	

Part number	For round belt	ØD	Width L	ØB	Bearing	C	ØA	E	G	For shaft	Price each 1 to 9
PTGR62-10-17	Ø10	76	18	62	6203 2RS	38	17	10,3	12	AXTR-M12	17,24 €
PTGR89-14-17	Ø14	105	18	89	6203 2RS	38	17	14,3	12	AXTR-M12	21,52 €
PTGR95-11-17	Ø11	114	20	95	6203 2RS	38	17	11,3	12	AXTR-M12	25,77 €

Dimensions in mm

Our other products



PRF_JL2
Lip seal for panel,
Door seal - Ø 2mm



FBL6000_K13
Brush strip per meter
PP fibres Ø0.2, Black
striated polypropylene



UTKswcr
Utilitrak® 3 wheels
carriage, Steel roller
carriage



CLB_T
Die cast zinc clamping
lever - male, Zamak



CHB
Double output shaft,
For CHB gearbox



APB_F
Adjusting rod for
clamp - Male,
Threaded



RTT
Locking Assembly,
Medium/high torque



LVT
Miniature motorised
actuator 1A, 1 ampere



WJUM20
Drylin® W bearing
block, Slide



SBF
Sealed flange bearing
unit for Food Industry,



PR40
Articulated foot Ø50,
Ø 50



STRIP1000
Sealing brush strip,
1m length

Complementary products



AXTR
Axle for tensioner
pulley, Shaft



PTGP
Tensioner pulley, For
flat belts



PTGT
Tensioner pulley, For
V belts