


- **Idler pulley**
- **Materials:**
  - PA6 reinforced with 30% fibreglass
  - Steel bearing
- Max speed 5,000 RPM

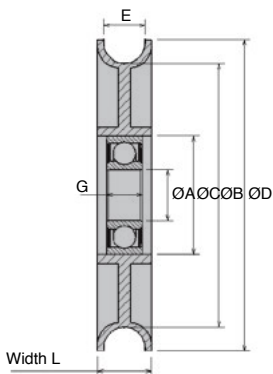

### DISCOUNTS

Qty	1+	10+	25+	50+
Disc.	List	-5%	-10%	On request

Part number	For round belt	ØD	Width L	ØB	Bearing	C	ØA	E	G	For shaft	Price each 1 to 9
PTGR62-10-17	Ø10	76	18	62	6203 2RS	38	17	10,3	12	AXTR-M12	17,24 €
PTGR89-14-17	Ø14	105	18	89	6203 2RS	38	17	14,3	12	AXTR-M12	21,52 €
PTGR95-11-17	Ø11	114	20	95	6203 2RS	38	17	11,3	12	AXTR-M12	25,77 €

Dimensions in mm

## Our other products




PSG25

Spur gear - precision range, Case hardened steel 20NCD2



SLB

 Indexing plunger, stainless steel



M2

Worm and wheel set, Bronze



HTD5M\_09

HTD Heavy duty timing pulley, HTD5 Steel



NT121

Spur gear coaxial gearbox, from 20 to 68 Nm - Inline



CHA38\_SS

Stainless steel face frame hinge, Surface mount




OP6

Mechanical digital position indicator, 5 numbers



M2

 Worm and wheel set, Unhardened steel



BMF

Knurled knob - female, Knurled - through threaded



EHD08-9

Internal epicyclic servo reducers, from 35 to 50 Nm



FF30

Offset spur gear reducer, from 21.50 to 83 Nm



MBEX

Hexagonal ended handle, Hexagonal ended handle

## Complementary products



AXTR

Axle for tensioner pulley, Shaft



PTGP

Tensioner pulley, For flat belts



PTGT

Tensioner pulley, For V belts