


- **Idler pulley**
- **Material:**  
PA6 reinforced with 30% fibreglass  
steel bearing
- Max speed 5,000 RPM

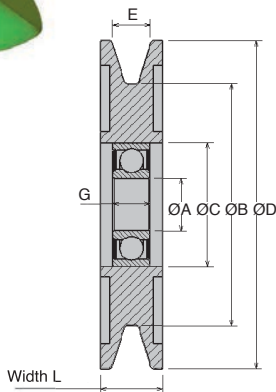

**INCREASED STOCK**

**DISCOUNTS**

Qty	1+	10+	25+	50+
Disc.	List	-5%	-10%	On request

Part number	FOR round belt	ØD	Width L	ØB	Bearing C	ØA	E	G	For shaft	Stock*	Price each 1 to 9
PTGR62-10-17	Ø10	76	18	62	6203 2ZZ	38	17	10,3	12	AXTR-M12	✓ 17,50 €
PTGR89-14-17	Ø14	105	18	89	6203 2RS	38	17	14,3	12	AXTR-M12	✓ 21,83 €
PTGR95-11-17	Ø11	114	20	95	6203 2RS	38	17	11,3	12	AXTR-M12	- 26,16 €

Dimensions en mm

## Our other products



Weld-on hinge with flat end, Steel



Stainless steel worm and wheel gearbox, up to 80 Nm



Clevis components, short version, Steel - Short range



Spur gear - precision range, Stainless steel 316




Miniature motorised actuator 2A, 2 amperes



Domino 80 adjustable slide, Slide DOMILINE 80



Cam follower without axial guide, Without interior ring

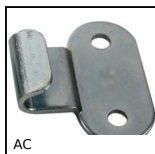

Strike for toggle latch, 20mm



Lock for aluminium profile, Lock for



Automatic chain tensioner, With steel



Machined plastic bevel gear, 1:1



Worm and wheel set, Non hardened steel

## Complementary products



Axle for tensioner pulley, Shaft



Tensioner pulley, For flat belts



Tensioner pulley, For round belts