


- **Idler pulley**
- Material:
 - PA6 reinforced with 30% fibreglass
 - steel bearing
- Max speed 5,000 RPM

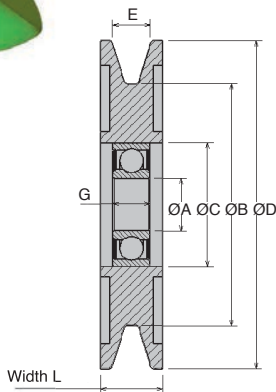

INCREASED STOCK

DISCOUNTS

Qty	1+	10+	25+	50+
Disc.	List	-5%	-10%	On request

Part number	FOR round belt	ØD	Width L	ØB	Bearing C	ØA	E	G	For shaft	Stock*	Price each 1 to 9
PTGR62-10-17	Ø10	76	18	62	6203 2ZZ	38	17	10,3	12	AXTR-M12	✓ 17,50 €
PTGR89-14-17	Ø14	105	18	89	6203 2RS	38	17	14,3	12	AXTR-M12	✓ 21,83 €
PTGR95-11-17	Ø11	114	20	95	6203 2RS	38	17	11,3	12	AXTR-M12	- 26,16 €

Dimensions en mm

Our other products



MAX26
Motor-gearbox 12V
and 24V DC, from
0,075 to 0,6Nm



HS
Hexagonal spacer,
Stainless steel 303




BCA
Steel splined collar,
Steel



DER90
Stainless steel AC
asynchronous motor
1.1 - 1.5kW, 1.1 to
1.5kW



BAG0
Locking rings in steel,
Steel

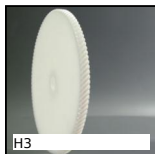

H3
Crossed helical gear
crossed axis at 90°,
Machined plastic
(delrin)



H2
Crossed helical gear
crossed axis at 90°,
Steel 20NCD2



SH0
Parallel axis helical
gear, Steel 20NCD2



PRF_BV
Screw block, Panel
addition and fastening



EHD08-3
Internal epicyclic
servo reducers, from
20 to 50 Nm



PAT123
Pressed stainless
steel articulating foot
Ø123, Ø 123



PP50
Worm and wheel gear
reducer, from 6.50 to
12.80 Nm

Complementary products



AXTR
Axle for tensioner
pulley, Shaft



PTGP
Tensioner pulley, For
flat belts



PTGR
Tensioner pulley, For
round belts