


- **Idler pulley**
- **Material:**
PA6 reinforced with 30% fibreglass
steel bearing
- Max speed 5,000 RPM

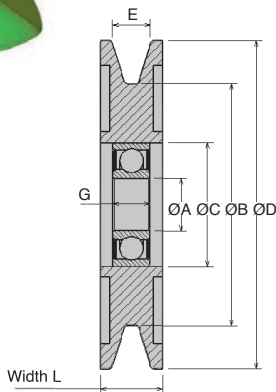

INCREASED STOCK

DISCOUNTS

Qty	1+	10+	25+	50+
Disc.	List	-5%	-10%	On request

Part number	FOR round belt	ØD	Width L	ØB	Bearing C	ØA	E	G	For shaft	Stock*	Price each 1 to 9
PTGR62-10-17	Ø10	76	18	62	6203 2ZZ	38	17	10,3	12	AXTR-M12	✓ 17,50 €
PTGR89-14-17	Ø14	105	18	89	6203 2RS	38	17	14,3	12	AXTR-M12	✓ 21,83 €
PTGR95-11-17	Ø11	114	20	95	6203 2RS	38	17	11,3	12	AXTR-M12	- 26,16 €

Dimensions en mm

Our other products



AC
Strike for toggle latch,
15mm



SDG
Adjustable guide
support bracket,
Plastic



BLHT30
Right angled gearbox,
from 1.65 to 4.40 Nm



UGH32
H Type Guide units,
For Ø32 actuators




BIM
Indexing plunger mini,
miniature



NKXR
Combined bearing
without inner ring,
Needle and cylindrical
rollers



VELM4
Screw-on base for
hook-and-loop strip,
Polyamide

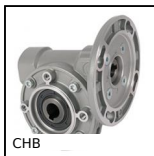

CHB
Worm and wheel gear
reducer, up to 22 Nm



CPAS
Stay with safety
catch, Opens upward



SSG2_304L
Stainless steel spur
gear, Stainless steel
304L




PTA40ssEB
Articulated foot with
sheet metal base
Ø40, 3000N



MSP23
Masterplate®
glueable insert Ø23,
Cylindrical Ø23 with
threaded s...


Complementary products

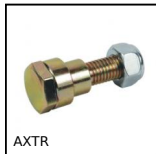

AXTR
Axle for tensioner
pulley, Shaft



PTGP
Tensioner pulley, For
flat belts

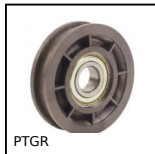

PTGR
Tensioner pulley, For
round belts