



Stainless steel swivelling foot, bolt-down

Max load 25,000N



PTKFss

- "Teknohygienic" swivelling foot
- Materials:
 - Base: stainless steel 304
 - Stem: stainless steel 304
 - Blind nut: stainless steel 304
- Sole: NBR rubber Shore hardness 90°


For the food industry

Advantages

- The 3-A standard designates products that are designed for the dairy, food and pharmaceutical industries where strict hygiene rules apply.
- Smooth finished foot with a wiper seal between the stem and the nut and around the swivel to prevent accumulation of dirt or retention of water
- Suitable for cleaning with water or chemicals
- USDA approved

Avoids water retention

stainless steel

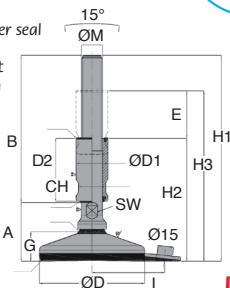

Blind M12 nut

Info.

- Do not forget to order the PTKF-M12/SS 3-A approved blind nut

DISCOUNTS

Qty	1+	6+	10+
Disc.	List	-5%	On request

Part number	Adjustable range	ØM	E	A	B	ØD	SW	ØD1	D2	CH	H2	H3	H1	I	Static load (N)	Price each 1 to 5
PTKF80-16-140/SS	M16	45	53	140	80	13	24	60	20	114	159	193	54	20000	102,12 €	
PTKF80-16-190/SS	M16	70	53	190	80	13	24	85	20	139	209	243	54	20000	105,01 €	
PTKF80-20-140/SS	M20	45	53	140	80	17	30	60	26	114	159	193	54	20000	92,37 €	
PTKF80-20-142/SS	M20	55	53	142	80	17	30	70	26	123	178	195	54	20000	95,30 €	
PTKF80-20-190/SS	M20	70	53	190	80	17	30	85	26	139	209	243	54	20000	105,91 €	
PTKF80-24-140/SS	M24	45	53	140	80	20	35	60	30	114	159	193	54	20000	95,92 €	
PTKF80-24-190/SS	M24	70	53	190	80	20	35	85	30	139	209	243	54	20000	112,90 €	
PTKF100-16-140/SS	M16	45	56	140	100	13	24	60	20	117	162	196	69	25000	93,26 €	
PTKF100-16-190/SS	M16	70	56	190	100	13	24	85	20	142	212	246	69	25000	110,14 €	
PTKF100-20-140/SS	M20	45	56	140	100	17	30	60	26	117	162	196	69	25000	97,49 €	
PTKF100-20-190/SS	M20	70	56	190	100	17	30	85	26	142	212	246	69	25000	111,05 €	
PTKF100-24-140/SS	M24	45	56	140	100	20	35	60	30	117	162	196	69	25000	105,20 €	
PTKF100-24-190/SS	M24	70	56	190	100	20	35	85	30	142	212	246	69	25000	118,02 €	
PTKF100-30-135/SS	M30	40	56	135	100	26	42	60	36	117	157	191	69	25000	115,08 €	
PTKF100-30-185/SS	M30	65	56	185	100	26	42	85	36	142	207	241	69	25000	125,34 €	

Blind M12 nut

PTKF-M12/SS	M12															13,82 €
-------------	-----	--	--	--	--	--	--	--	--	--	--	--	--	--	--	---------

Dimensions in mm

Our other products



MDB_MTB
Moulded plastic bevel gear (nylon), 2:1



CDPC
Flanged drill bushing, Steel



SH2
Parallel axis helical gear, Machined plastic (delrin)



FBL6000_K19
Brush strip per meter horsehair fibres Ø0.2, Black horsehair



M2
Worm and wheel set, Unhardened steel



PDD
Spring plunger, With sensor adaptor



EHD08-3
Internal epicyclic servo reducers, from 20 to 50 Nm



STC
Shock Absorber - stop collar, Universal flange



WS20
Drylin® W rail, Rail



H0
Crossed helical gear, crossed axis at 90°, Steel 20NCD2



AT5M AT10M
AT type timing belt per metre, AT10 Steel cored polyurethane



RBGpl
Swivel castor with double brake, Steel - grey rubber

Complementary products



PTKFss
Fixable foot for the food industry, Stainless steel - 3-A standard