



# Stainless steel swivelling foot, bolt-down

## Max load 25,000N



## PTKFss

- "Teknohygienic" swivelling foot
- Materials:
  - Base: stainless steel 304
  - Stem: stainless steel 304
  - Blind nut: stainless steel 304
- Sole: NBR rubber Shore hardness 90°

For the food industry

Avoids water retention


stainless steel

### Advantages

- The 3-A standard designates products that are designed for the dairy, food and pharmaceutical industries where strict hygiene rules apply.
- Smooth finished foot with a wiper seal between the stem and the nut and around the swivel to prevent accumulation of dirt or retention of water
- Suitable for cleaning with water or chemicals
- USDA approved

### Info.

- Do not forget to order the PTKF-M12/SS 3-A approved blind nut

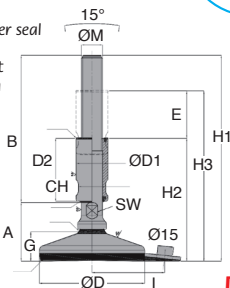

Blind M12 nut

### DISCOUNTS

Qty	1+	6+	10+
Disc.	List	-5%	On request

Part number	Adjustable range	ØM	E	A	B	ØD	SW	ØD1	D2	CH	H2	H3	H1	I	Static load (N)	Price each 1 to 5
PTKF80-16-140/SS	M16	45	53	140	80	13	24	60	20	114	159	193	54	20000	102,12 €	
PTKF80-16-190/SS	M16	70	53	190	80	13	24	85	20	139	209	243	54	20000	105,01 €	
PTKF80-20-140/SS	M20	45	53	140	80	17	30	60	26	114	159	193	54	20000	92,37 €	
PTKF80-20-142/SS	M20	55	53	142	80	17	30	70	26	123	178	195	54	20000	95,30 €	
PTKF80-20-190/SS	M20	70	53	190	80	17	30	85	26	139	209	243	54	20000	105,91 €	
PTKF80-24-140/SS	M24	45	53	140	80	20	35	60	30	114	159	193	54	20000	95,92 €	
PTKF80-24-190/SS	M24	70	53	190	80	20	35	85	30	139	209	243	54	20000	112,90 €	
PTKF100-16-140/SS	M16	45	56	140	100	13	24	60	20	117	162	196	69	25000	93,26 €	
PTKF100-16-190/SS	M16	70	56	190	100	13	24	85	20	142	212	246	69	25000	110,14 €	
PTKF100-20-140/SS	M20	45	56	140	100	17	30	60	26	117	162	196	69	25000	97,49 €	
PTKF100-20-190/SS	M20	70	56	190	100	17	30	85	26	142	212	246	69	25000	111,05 €	
PTKF100-24-140/SS	M24	45	56	140	100	20	35	60	30	117	162	196	69	25000	105,20 €	
PTKF100-24-190/SS	M24	70	56	190	100	20	35	85	30	142	212	246	69	25000	118,02 €	
PTKF100-30-135/SS	M30	40	56	135	100	26	42	60	36	117	157	191	69	25000	115,08 €	
PTKF100-30-185/SS	M30	65	56	185	100	26	42	85	36	142	207	241	69	25000	125,34 €	

### Blind M12 nut

PTKF-M12/SS	M12															17	13,82 €
-------------	-----	--	--	--	--	--	--	--	--	--	--	--	--	--	--	----	---------


Dimensions in mm

## Our other products



BL15

Right angled gearbox,  
from 1.10 to 6 Nm

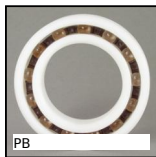

PB

Plastic deep groove  
ball bearing, Plastic -  
glass balls material



YG3

HEAVY DUTY spur  
gear, Steel 35NCD6




PSG08HC

Skive hobbed spur  
gears - precision  
range, Case hardened  
steel 20NCD2



PR820

 Idler sprocket for slat  
top chain, Rangs 820  
and 815



T2

T type timing belt,  
T2.5 Steel cored  
polyurethane



LF

Precision locknut,  
Precision locknut



CAP815

Slim slat top chain  
stainless steel,  
Narrow range 815



DOMI120

Domino 120  
adjustable slide, Slide  
DOMILINE 120



SSE

Stainless steel  
spherical bearing,  
Stainless steel / PTFE



PSG125HC

Skive hobbed spur  
gears - precision  
range, Case hardened



PARF110

Pressed steel base  
rigid foot, Swivelling  
Ø110

## Complementary products



PTKFss

Cap nut for foot for  
the food industry,  
Stainless steel blind  
nut - ...



PTKss

Foot for the food  
industry, Stainless  
steel - 3-A standard



PTAF80-PAMF80

Articulated fixable  
foot with pressed  
base Ø80, Ø 80



PTAF80-PAMF80

Articulated fixable  
foot with pressed  
base Ø80, Ø 80