



# Stainless steel swivelling foot, bolt-down

Max load 25,000N



PTKFss

- "Teknohygienic" swivelling foot
- Materials:
  - Base: stainless steel 304
  - Stem: stainless steel 304
  - Blind nut: stainless steel 304
- Sole: NBR rubber Shore hardness 90°


For the food industry

## Advantages

- The 3-A standard designates products that are designed for the dairy, food and pharmaceutical industries where strict hygiene rules apply.
- Smooth finished foot with a wiper seal between the stem and the nut and around the swivel to prevent accumulation of dirt or retention of water
- Suitable for cleaning with water or chemicals
- USDA approved

Avoids water retention

stainless steel

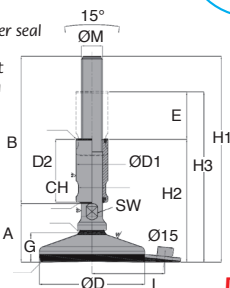

Blind M12 nut

## Info.

- Do not forget to order the PTKF-M12/SS 3-A approved blind nut

## DISCOUNTS

Qty	1+	6+	10+
Disc.	List	-5%	On request

Part number	Adjustable range	ØM	E	A	B	ØD	SW	ØD1	D2	CH	H2	H3	H1	I	Static load (N)	Price each 1 to 5
PTKF80-16-140/SS	M16	45	53	140	80	13	24	60	20	114	159	193	54	20000	102,12 €	
PTKF80-16-190/SS	M16	70	53	190	80	13	24	85	20	139	209	243	54	20000	105,01 €	
PTKF80-20-140/SS	M20	45	53	140	80	17	30	60	26	114	159	193	54	20000	92,37 €	
PTKF80-20-142/SS	M20	55	53	142	80	17	30	70	26	123	178	195	54	20000	95,30 €	
PTKF80-20-190/SS	M20	70	53	190	80	17	30	85	26	139	209	243	54	20000	105,91 €	
PTKF80-24-140/SS	M24	45	53	140	80	20	35	60	30	114	159	193	54	20000	95,92 €	
PTKF80-24-190/SS	M24	70	53	190	80	20	35	85	30	139	209	243	54	20000	112,90 €	
PTKF100-16-140/SS	M16	45	56	140	100	13	24	60	20	117	162	196	69	25000	93,26 €	
PTKF100-16-190/SS	M16	70	56	190	100	13	24	85	20	142	212	246	69	25000	110,14 €	
PTKF100-20-140/SS	M20	45	56	140	100	17	30	60	26	117	162	196	69	25000	97,49 €	
PTKF100-20-190/SS	M20	70	56	190	100	17	30	85	26	142	212	246	69	25000	111,05 €	
PTKF100-24-140/SS	M24	45	56	140	100	20	35	60	30	117	162	196	69	25000	105,20 €	
PTKF100-24-190/SS	M24	70	56	190	100	20	35	85	30	142	212	246	69	25000	118,02 €	
PTKF100-30-135/SS	M30	40	56	135	100	26	42	60	36	117	157	191	69	25000	115,08 €	
PTKF100-30-185/SS	M30	65	56	185	100	26	42	85	36	142	207	241	69	25000	125,34 €	

### Blind M12 nut

 
PTKF-M12/SS	M12	17	13,82 €
-------------	-----	----	---------

Dimensions in mm

## Our other products



TBbutee  
Axial thrust bearing,  
Steel balls



CFC  
Spring loaded position  
switch, Electric  
contact



ACL-FPA  
Panel mounting block  
for aluminium  
structures, Angular  
connector



DOMI80  
Domino 80 adjustable  
slide, Slide DOMILINE  
80 with counter and  
handw...



PPRss  
Pad eye on mounting  
plate round, Stainless  
steel



PLC\_PLT  
Magnetic stud with  
threaded hole, With  
threaded hole



NK40  
Drylin®N miniature  
guiding system, With  
40 mm




TBD  
Manual leadscrew  
table with opposing  
threads, 2kg



GG3  
Ground spur gear,  
Heat treated steel



 PRES7HR  
Manual workbench  
press, Force up to  
700 N



PRF4545r90  
Standard aluminium  
profile, 45 x 45 mm -  
r90



WW16  
Drylin® W slide, slide  
assembly

## Complementary products



PTKFss  
Fixable foot for the  
food industry,  
Stainless steel - 3-A  
standard