



Stainless steel swivelling foot, bolt-down

Max load 25,000N



PTKFss

- "Teknohygienic" swivelling foot
- Materials:
 - Base: stainless steel 304
 - Stem: stainless steel 304
 - Blind nut: stainless steel 304
- Sole: NBR rubber Shore hardness 90°


For the food industry

Advantages

- The 3-A standard designates products that are designed for the dairy, food and pharmaceutical industries where strict hygiene rules apply.
- Smooth finished foot with a wiper seal between the stem and the nut and around the swivel to prevent accumulation of dirt or retention of water
- Suitable for cleaning with water or chemicals
- USDA approved

Info.

- Do not forget to order the PTKF-M12/SS 3-A approved blind nut

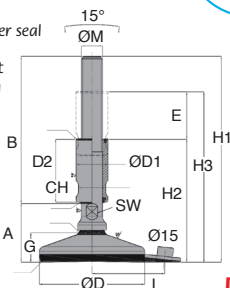

Avoids water retention

stainless steel



Blind M12 nut

DISCOUNTS

Qty	1+	6+	10+
Disc.	List	-5%	On request

Part number	Adjustable range	ØM	E	A	B	ØD	SW	ØD1	D2	CH	H2	H3	H1	I	Static load (N)	Price each 1 to 5
PTKF80-16-140/SS	M16	45	53	140	80	13	24	60	20	114	159	193	54	20000	102,12 €	
PTKF80-16-190/SS	M16	70	53	190	80	13	24	85	20	139	209	243	54	20000	105,01 €	
PTKF80-20-140/SS	M20	45	53	140	80	17	30	60	26	114	159	193	54	20000	92,37 €	
PTKF80-20-142/SS	M20	55	53	142	80	17	30	70	26	123	178	195	54	20000	95,30 €	
PTKF80-20-190/SS	M20	70	53	190	80	17	30	85	26	139	209	243	54	20000	105,91 €	
PTKF80-24-140/SS	M24	45	53	140	80	20	35	60	30	114	159	193	54	20000	95,92 €	
PTKF80-24-190/SS	M24	70	53	190	80	20	35	85	30	139	209	243	54	20000	112,90 €	
PTKF100-16-140/SS	M16	45	56	140	100	13	24	60	20	117	162	196	69	25000	93,26 €	
PTKF100-16-190/SS	M16	70	56	190	100	13	24	85	20	142	212	246	69	25000	110,14 €	
PTKF100-20-140/SS	M20	45	56	140	100	17	30	60	26	117	162	196	69	25000	97,49 €	
PTKF100-20-190/SS	M20	70	56	190	100	17	30	85	26	142	212	246	69	25000	111,05 €	
PTKF100-24-140/SS	M24	45	56	140	100	20	35	60	30	117	162	196	69	25000	105,20 €	
PTKF100-24-190/SS	M24	70	56	190	100	20	35	85	30	142	212	246	69	25000	118,02 €	
PTKF100-30-135/SS	M30	40	56	135	100	26	42	60	36	117	157	191	69	25000	115,08 €	
PTKF100-30-185/SS	M30	65	56	185	100	26	42	85	36	142	207	241	69	25000	125,34 €	

Blind M12 nut

PTKF-M12/SS	M12	17	13,82 €
-------------	-----	----	---------

Dimensions in mm

Our other products



M2

Worm and wheel set,
Hardened steel



NIN

Self-locking nut, Steel



VTLM

3 lobed handle,
Polyamide - Steel



PTA80

Articulated levelling
foot, pressed base
Ø80, Ø 80



TCLar

Automatic chain
tensioner, With wide
guide



GAL_25

Ø25 conveyor roller,
Without ball bearing



UGPC

Actuator guide kit,
Short bearing



AZY_SS

Stainless steel
cylindrical elasto
mount, Stainless steel



DER80

Stainless steel AC
asynchronous motor



BPVM

Miniature ball transfer
unit, Miniature to



PPD

Indexing plunger for
sheets, For sheet



DFG

Flat suction cup,
silicon

Complementary products



PTKfss

Cap nut for foot for
the food industry,
Stainless steel blind
nut - ...



PTKss

Foot for the food
industry, Stainless
steel - 3-A standard



PTAF80-PAMF80

Articulated fixable
foot with pressed
base Ø80, Ø 80



PTAF80-PAMF80

Articulated fixable
foot with pressed
base Ø80, Ø 80