

# Adjustable furniture foot

For square tube

PTCR

## Furniture foot with simple height adjustment

- For square tubes 20x20mm to 50x50mm
- Turn to adjust height
- Working T° -30°C to +80°C
- Material:

Thermoplastic PA12 black

## Advantages

- Easy height adjustment
- Easy to install in the tube by pressure mounting



## Info

- Not sold individually, please contact us for details

**NEW!**



## Example of use

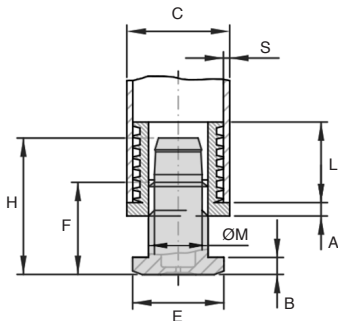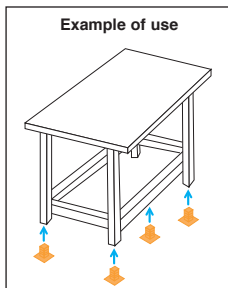

## DISCOUNT

Qty	1+	60+	100+	200+
Disc.	List	-5%	-10%	On request

Part number	C	E	A	B	ØM	F	L	H	S	Stock*	Price each 1 à 59
PTCR20-M10	20	20	5	4	M10	24	16,7	-	1,5 - 2	-	1,88 €
PTCR25-M16	25	24	5	5	M16	22	20	34,5	1,5 - 2	-	2,08 €
PTCR30-M22	30	28	5	5	M22	20	19,5	45,5	1,5 - 2	-	1,96 €
PTCR35-M22	35	28	5	5	M22	21,5	29,3	34,5	1,5 - 2	-	3,04 €
PTCR40-M22	40	28	5	5	M22	21,5	29,3	34,5	1,5 - 2	-	3,48 €
PTCR50-M30	50	41	5	5	M30	28	29,3	45,5	1,5 - 2	-	4,72 €

\*Depending on availability - Dimensions in mm

# Stainless steel telescopic furniture foot

With threaded stud

PTMR

## Furniture foot with simple height adjustment


- Turn to adjust height
- Materials:
  - Stainless steel foot 304
  - Glass fibre reinforced nylon internal thread
  - Anti-slip pad in black PVC

## Advantages



- Easy height adjustment
- When washing, the water flows over the outer part of the foot



**NEW!**

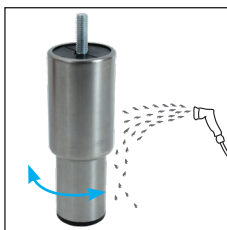

## Example of use: metal cabinet

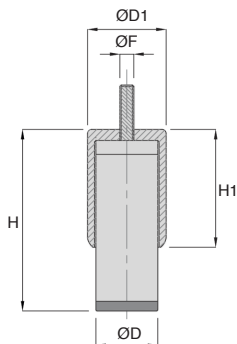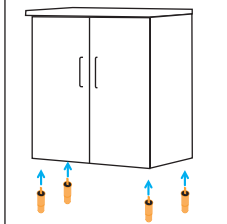

## DISCOUNT

Qty	1+	6+	10+	15+	20+
Disc.	List	-5%	-10%	-15%	On request

Part number	ØD	ØD1	H	H1	ØF	Static load (N)	Stock*	Price each 1 à 5
PTMR30-40-M10	30	40	80/110	67	M10x15	3000	-	21,39 €
PTMR44-56-M10	44,5	56,5	130/180	85	M10x30	5000	-	26,58 €
PTMR56-64-M10	56,5	64	130/180	85	M10x30	8000	-	29,25 €

\*Depending on availability - Dimensions in mm

# Stainless steel telescopic furniture foot

With square plate


PTMC

## Furniture foot with simple height adjustment



- Turn to adjust height
- Materials:
  - Stainless steel foot 304
  - Glass fibre reinforced nylon internal thread
  - Anti-slip pad in black PVC

## Advantages

- Easy height adjustment
- When washing, the water flows over the outer part of the foot

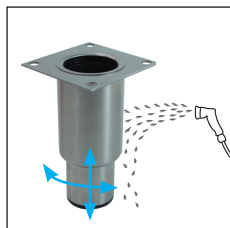

Example of use:  
metal cabinet

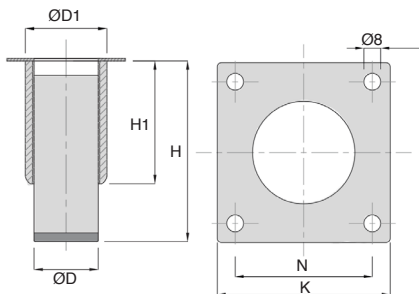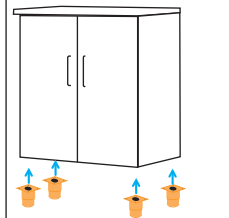

## DISCOUNT

Qty	1+	6+	10+	15+	20+
Disc.	List -5%	-10%	-15%	-	On request

Part number	ØD	ØD1	H	H1	K	N	Static load (N)	Stock*	Price each 1 to 5
PTMC44-56-82	44,5	56,5	130/180	85	82	65	5000	-	31,23 €
PTMC56-64-82	56,6	64	130/180	85	82	65	8000	-	33,81 €

\*Depending on availability - Dimensions in mm

## Our other products



SMLS  
Linear table, For small lengths



PTGT  
Tensioner pulley, For V belts



 
PTA40ssEB  
Articulated foot with sheet metal base  
Ø40, Ø 40



BSM\_LOK  
Long-Lok spring plunger with internal hexagonal socket,  
LONG-LOK - s...



CLR  
Straight clevis,  
Straight clevis for use with a male clevis



CAB  
Stainless steel cable,  
Stainless steel



PM2  
Worm and wheel set,  
Machined plastic (delrin)



TBD  
Manual leadscrew table with opposing threads, 5kg



SLB  
Indexing plunger,  
steel class 5.8



NT62  
Spur gear coaxial gearbox, from 6 to 18



VTSM  
Ball head screws  
Hygienic Design®,



CHB  
Feet, For CHB gearbox

## Complementary products



PTCR  
Adjustable furniture foot, square tube



PTMR  
Telescopic furniture foot, threaded stud