

Adjustable furniture foot

For square tube

PTCR

Furniture foot with simple height adjustment

- For square tubes 20x20mm to 50x50mm
- Turn to adjust height
- Working T° -30°C to +80°C
- Material:

Thermoplastic PA12 black

Advantages



- Easy height adjustment
- Easy to install in the tube by pressure mounting

Info

- Not sold individually, please contact us for details



Example of use

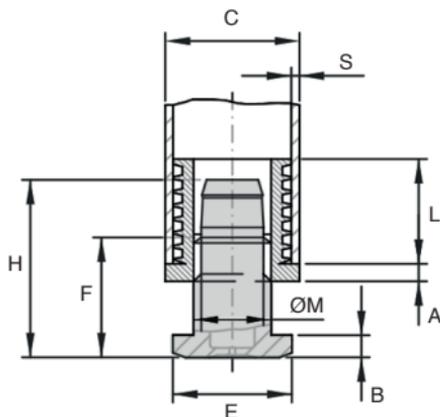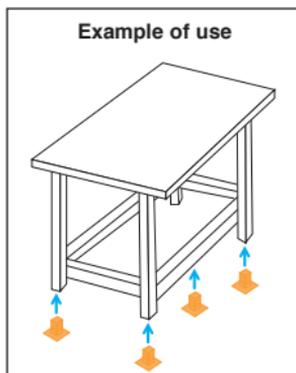

DISCOUNTS

| | | | | |
|-------|------|-----|------|------------|
| Qty | 1+ | 60+ | 100+ | 200+ |
| Disc. | List | -5% | -10% | On request |

| Part number | C | E | A | B | ØM | F | L | H | S | Price each 1 to 59 |
|-------------|----|----|---|---|-----|------|------|------|---------|-----------------------|
| PTCR20-M10 | 20 | 20 | 5 | 4 | M10 | 24 | 16,7 | - | 1,5 - 2 | 1,92 € |
| PTCR25-M16 | 25 | 24 | 5 | 5 | M16 | 22 | 20 | 34,5 | 1,5 - 2 | 2,12 € |
| PTCR30-M22 | 30 | 28 | 5 | 5 | M22 | 20 | 19,5 | 45,5 | 1,5 - 2 | 2,00 € |
| PTCR35-M22 | 35 | 28 | 5 | 5 | M22 | 21,5 | 29,3 | 34,5 | 1,5 - 2 | 3,10 € |
| PTCR40-M22 | 40 | 28 | 5 | 5 | M22 | 21,5 | 29,3 | 34,5 | 1,5 - 2 | 3,55 € |
| PTCR50-M30 | 50 | 41 | 5 | 5 | M30 | 28 | 29,3 | 45,5 | 1,5 - 2 | 4,82 € |

Dimensions in mm

Stainless steel telescopic furniture foot **Sta**

PTMR


With threaded stud

Furniture foot with simple height adjustment



- Turn to adjust height
- Materials:
 - Stainless steel foot 304
 - Glass fibre reinforced nylon internal thread
 - Anti-slip pad in black PVC

Advantages

- Easy height adjustment
- When washing, the water flows over the outer part of the foot

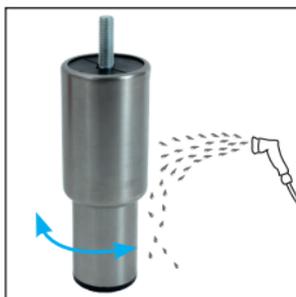

Example of use: metal cabinet

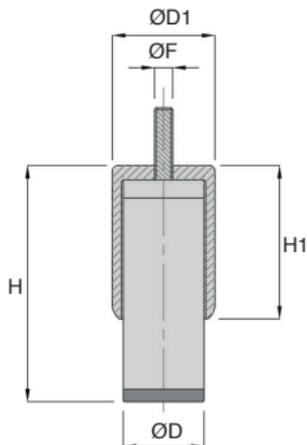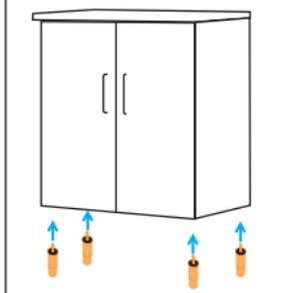

DISCOUNTS

| | | | | | |
|-------|------|-----|------|------|------------|
| Qty | 1+ | 6+ | 10+ | 15+ | 20+ |
| Disc. | List | -5% | -10% | -15% | On request |

| Part number | ØD | ØD1 | H | H1 | ØF | Static load (N) | Stock* | Price each 1 to 5 |
|---------------|------|------|---------|----|--------|-----------------|--------|-------------------|
| PTMR30-40-M10 | 30 | 40 | 80/110 | 67 | M10x15 | 3000 | | 21,82 € |
| PTMR44-56-M10 | 44,5 | 56,5 | 130/180 | 85 | M10x30 | 5000 | | 27,12 € |
| PTMR56-64-M10 | 56,5 | 64 | 130/180 | 85 | M10x30 | 8000 | | 29,84 € |

Dimensions in mm

Stainless steel telescopic furniture foot

With square plate


PTMC

Furniture foot with simple height adjustment



- Turn to adjust height
- Materials:
 - Stainless steel foot 304
 - Glass fibre reinforced nylon internal thread
 - Anti-slip pad in black PVC

Advantages

- Easy height adjustment
- When washing, the water flows over the outer part of the foot

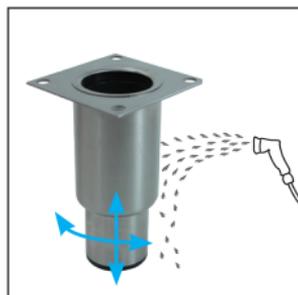

Example of use:
metal cabinet

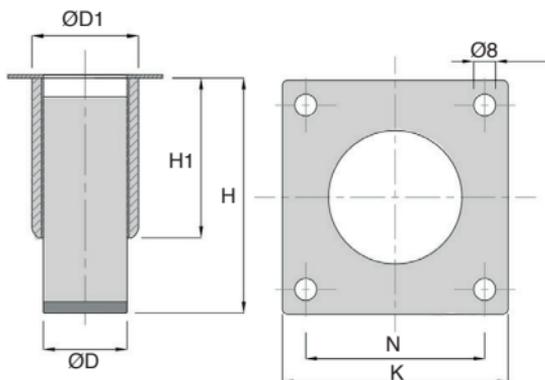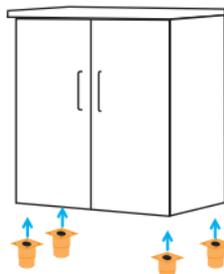

DISCOUNTS

| Qty | 1+ | 6+ | 10+ | 15+ | 20+ |
|-------|----------|------|------|------------|-----|
| Disc. | List -5% | -10% | -15% | On request | |

| Part number | ØD | ØD1 | H | H1 | K | N | Static load (N) | Price each |
|--------------|------|------|---------|----|----|----|-----------------|------------|
| | | | | | | | | Stock* |
| PTMC44-56-82 | 44,5 | 56,5 | 130/180 | 85 | 82 | 65 | 5000 | 31,86 € |
| PTMC56-64-82 | 56,6 | 64 | 130/180 | 85 | 82 | 65 | 8000 | 34,49 € |

Dimensions in mm