

# Adjustable furniture foot

For square tube

PTCR

## Furniture foot with simple height adjustment

- For square tubes 20x20mm to 50x50mm
- Turn to adjust height
- Working T° -30°C to +80°C
- Material:

Thermoplastic PA12 black

## Advantages



- Easy height adjustment
- Easy to install in the tube by pressure mounting

## Info

- Not sold individually, please contact us for details



## Example of use

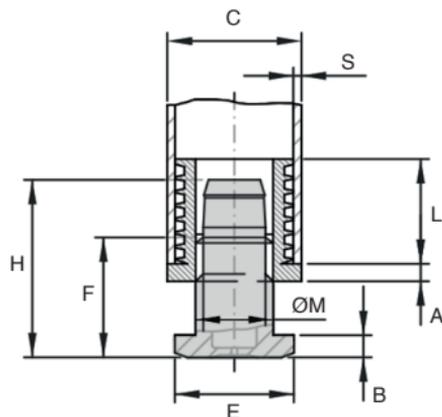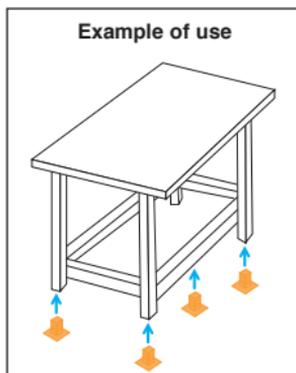

## DISCOUNTS

Qty	1+	60+	100+	200+
Disc.	List	-5%	-10%	On request

Part number	C	E	A	B	ØM	F	L	H	S	Price each 1 to 59
PTCR20-M10	20	20	5	4	M10	24	16,7	-	1,5 - 2	1,92 €
PTCR25-M16	25	24	5	5	M16	22	20	34,5	1,5 - 2	2,12 €
PTCR30-M22	30	28	5	5	M22	20	19,5	45,5	1,5 - 2	2,00 €
PTCR35-M22	35	28	5	5	M22	21,5	29,3	34,5	1,5 - 2	3,10 €
PTCR40-M22	40	28	5	5	M22	21,5	29,3	34,5	1,5 - 2	3,55 €
PTCR50-M30	50	41	5	5	M30	28	29,3	45,5	1,5 - 2	4,82 €

Dimensions in mm

# Stainless steel telescopic furniture foot **Sta**

## PTMR


## With threaded stud

### Furniture foot with simple height adjustment



- Turn to adjust height
- Materials:
  - Stainless steel foot 304
  - Glass fibre reinforced nylon internal thread
  - Anti-slip pad in black PVC

### Advantages

- Easy height adjustment
- When washing, the water flows over the outer part of the foot

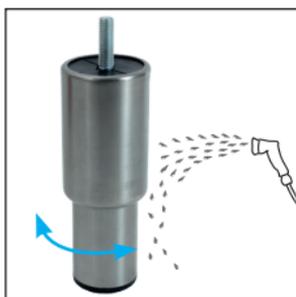

### Example of use: metal cabinet

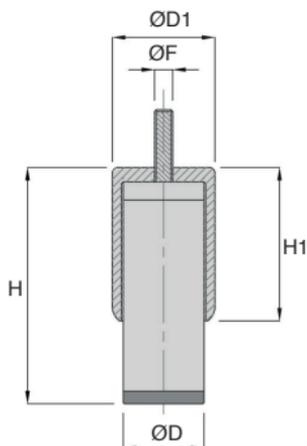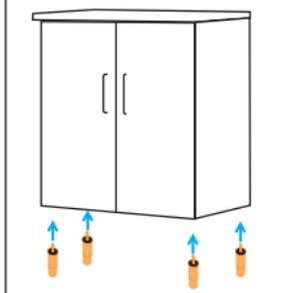

### DISCOUNTS

Qty	1+	6+	10+	15+	20+
Disc.	List	-5%	-10%	-15%	On request

Part number	ØD	ØD1	H	H1	ØF	Static load (N)	Stock*	Price each 1 to 5
PTMR30-40-M10	30	40	80/110	67	M10x15	3000		21,82 €
PTMR44-56-M10	44,5	56,5	130/180	85	M10x30	5000		27,12 €
PTMR56-64-M10	56,5	64	130/180	85	M10x30	8000		29,84 €

Dimensions in mm

# Stainless steel telescopic furniture foot

With square plate


PTMC

## Furniture foot with simple height adjustment



- Turn to adjust height
- Materials:
  - Stainless steel foot 304
  - Glass fibre reinforced nylon internal thread
  - Anti-slip pad in black PVC

## Advantages

- Easy height adjustment
- When washing, the water flows over the outer part of the foot

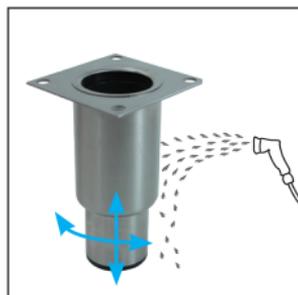

Example of use:  
metal cabinet

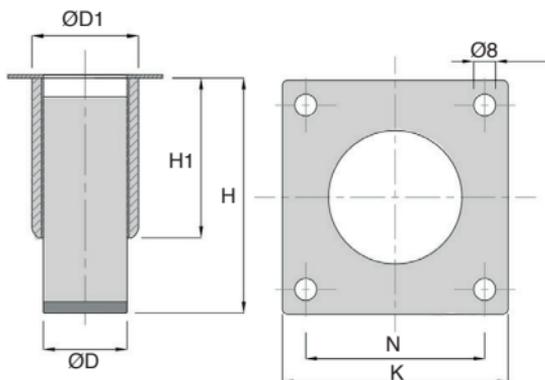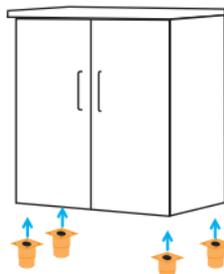

## DISCOUNTS

Qty	1+	6+	10+	15+	20+
Disc.	List -5%	-10%	-15%	On request	

Part number	ØD	ØD1	H	H1	K	N	Static load (N)	Stock*	Price each 1 to 5
PTMC44-56-82	44,5	56,5	130/180	85	82	65	5000		31,86 €
PTMC56-64-82	56,6	64	130/180	85	82	65	8000		34,49 €

Dimensions in mm