

# Adjustable furniture foot

For square tube

PTCR

## Furniture foot with simple height adjustment

- For square tubes 20x20mm to 50x50mm
- Turn to adjust height
- Working T° -30°C to +80°C
- Material:

Thermoplastic PA12 black

## Advantages

- Easy height adjustment
- Easy to install in the tube by pressure mounting



## Info

- Not sold individually, please contact us for details

**NEW!**



## Example of use

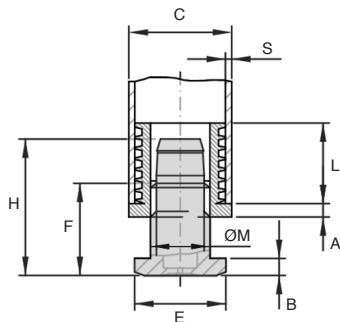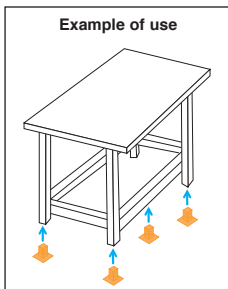

## DISCOUNT

|       |      |     |      |            |
|-------|------|-----|------|------------|
| Qty   | 1+   | 60+ | 100+ | 200+       |
| Disc. | List | -5% | -10% | On request |

| Part number | C  | E  | A | B | ØM  | F    | L    | H    | S       | Stock* | Price each<br>1 à 59 |
|-------------|----|----|---|---|-----|------|------|------|---------|--------|----------------------|
| PTCR20-M10  | 20 | 20 | 5 | 4 | M10 | 24   | 16,7 | -    | 1,5 - 2 | -      | 1,88 €               |
| PTCR25-M16  | 25 | 24 | 5 | 5 | M16 | 22   | 20   | 34,5 | 1,5 - 2 | -      | 2,08 €               |
| PTCR30-M22  | 30 | 28 | 5 | 5 | M22 | 20   | 19,5 | 45,5 | 1,5 - 2 | -      | 1,96 €               |
| PTCR35-M22  | 35 | 28 | 5 | 5 | M22 | 21,5 | 29,3 | 34,5 | 1,5 - 2 | -      | 3,04 €               |
| PTCR40-M22  | 40 | 28 | 5 | 5 | M22 | 21,5 | 29,3 | 34,5 | 1,5 - 2 | -      | 3,48 €               |
| PTCR50-M30  | 50 | 41 | 5 | 5 | M30 | 28   | 29,3 | 45,5 | 1,5 - 2 | -      | 4,72 €               |

\*Depending on availability - Dimensions in mm

# Stainless steel telescopic furniture foot

With threaded stud

PTMR

## Furniture foot with simple height adjustment


- Turn to adjust height
- Materials:
  - Stainless steel foot 304
  - Glass fibre reinforced nylon internal thread
  - Anti-slip pad in black PVC

## Advantages



- Easy height adjustment
- When washing, the water flows over the outer part of the foot



**NEW!**

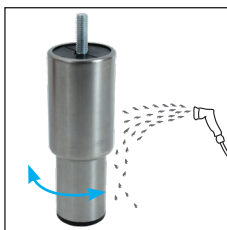

## Example of use: metal cabinet

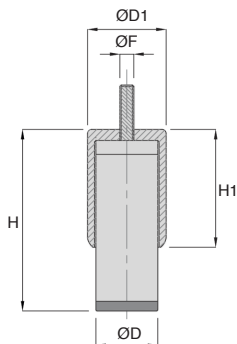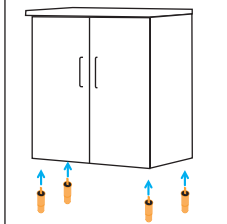

## DISCOUNT

|       |      |     |      |      |            |
|-------|------|-----|------|------|------------|
| Qty   | 1+   | 6+  | 10+  | 15+  | 20+        |
| Disc. | List | -5% | -10% | -15% | On request |

| Part number   | ØD   | ØD1  | H       | H1 | ØF     | Static load (N) | Stock* | Price each<br>1 à 5 |
|---------------|------|------|---------|----|--------|-----------------|--------|---------------------|
| PTMR30-40-M10 | 30   | 40   | 80/110  | 67 | M10x15 | 3000            | -      | 21,39 €             |
| PTMR44-56-M10 | 44,5 | 56,5 | 130/180 | 85 | M10x30 | 5000            | -      | 26,58 €             |
| PTMR56-64-M10 | 56,5 | 64   | 130/180 | 85 | M10x30 | 8000            | -      | 29,25 €             |

\*Depending on availability - Dimensions in mm

# Stainless steel telescopic furniture foot

With square plate


PTMC

## Furniture foot with simple height adjustment



- Turn to adjust height
- Materials:
  - Stainless steel foot 304
  - Glass fibre reinforced nylon internal thread
  - Anti-slip pad in black PVC

## Advantages

- Easy height adjustment
- When washing, the water flows over the outer part of the foot

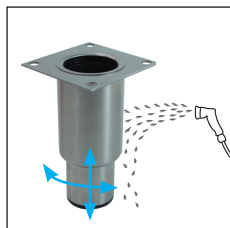

Example of use:  
metal cabinet

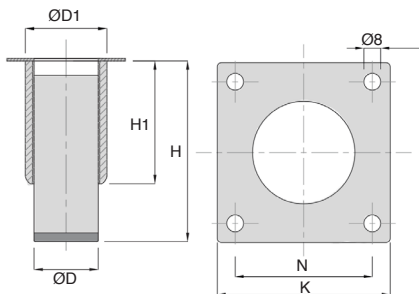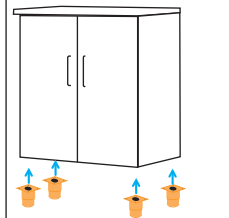

## DISCOUNT

|       |          |      |      |     |            |
|-------|----------|------|------|-----|------------|
| Qty   | 1+       | 6+   | 10+  | 15+ | 20+        |
| Disc. | List -5% | -10% | -15% | -   | On request |

| Part number  | ØD   | ØD1  | H       | H1 | K  | N  | Static load (N) | Stock* | Price each 1 to 5 |
|--------------|------|------|---------|----|----|----|-----------------|--------|-------------------|
| PTMC44-56-82 | 44,5 | 56,5 | 130/180 | 85 | 82 | 65 | 5000            | -      | 31,23 €           |
| PTMC56-64-82 | 56,6 | 64   | 130/180 | 85 | 82 | 65 | 8000            | -      | 33,81 €           |

\*Depending on availability - Dimensions in mm

## Our other products




PP35

Worm and wheel gear reducer, from 2.20 to 4.10 Nm



GG2

 Ground spur gear, Heat treated steel



CF

Cam follower, Standard - steel



BWU

Compact precision slide, from 1510 N to 10500 N



 
E40

Right angle helical reducers, from 2.30 to 20 Nm



GLP

Small 6 lobe threaded handle - male, Technopolymer - Steel



RDERSS

Stainless steel manual rigging screw, Stainless steel - manual



CHM40

Worm and wheel gear reducer, up to 57 Nm



SRG

Adjustable latch clamp with strike



OPFL\_OPPI

Numerical counter accessories,



G0

Steel spur gear, Steel 20NCD2



DPAK\_DKON

Conical elasto buffer, Steel

## Complementary products



PTCR

Adjustable furniture foot, square tube



PTMC

Telescopic furniture foot, square plate