

# Idler chain sprocket



## PTR

## For standard applications


- Chain sprocket for use with the BTE universal tension arm
- With ball bearings
- Greased for life
- Material: nut, screw, and sprocket in bichromate steel
- Max speed: 70 rpm
- t° of use: -30°C to + 80°C

**Good price/  
quality/ratio**



### Accessory

- BTE tension arm

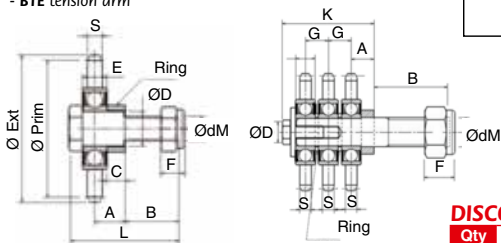

### DISCOUNTS

Qty	1+	4+	10+
Disc.	List -10%	On request	

Part number	Pitch	No. of teeth			ØdM	ØD	A	B	C	E	F	L	Arm size	Stock*	Price each 1 to 3
		Z	S	S											
<b>Single chain</b>															
PTR-04B1	6,000	15	2,6	M6	6	7	15	4	6	6	28	BTE2	✓	27,01 €	
PTR-05B1	8,000	14	2,8	M8	8	7,5	16	4	7	8	30	BTE2	-	24,62 €	
PTR-06B1	9,525	17	5,3	M10	12	12	22	7	10	10	44	BTE3	✓	17,16 €	
PTR-08B1	12,700	17	7,2	M12	17	15	26	9	12	12	53	BTE4/BTE5	✓	18,95 €	
PTR-10B1	15,800	16	9,1	M12	17	15	26	9	12	12	53	BTE4/BTE5	✓	24,60 €	
PTR-12B1	19,050	14	11,1	M12	17	15	26	9	12	12	53	BTE4/BTE5	✓	28,27 €	

Part number	Pitch	No. of teeth			ØdM	ØD	A	B	G	F	L	Arm size	Stock*	Price each 1 to 3
		Z	S	S										
<b>Double chain</b>														
PTR-06B2	9,525	17	M12	12	12	35	10,24	12	35	BTE4	-	41,77 €		
PTR-08B2	12,700	17	M18	17	15	45	13,92	18,5	44	BTE5	-	49,13 €		
PTR-10B2	15,800	16	M20	17	15	45	16,59	20	46	BTE6	-	71,28 €		
PTR-12B2	19,050	14	M20	17	15	45	19,46	20	49	BTE6	-	81,09 €		
<b>Triple chain</b>														
PTR-06B3	9,525	17	M12	12	12	35	10,24	12	45	BTE4	-	56,53 €		
PTR-08B3	12,700	17	M18	17	15	45	13,92	18,5	58	BTE5	-	73,74 €		
PTR-10B3	15,800	16	M20	17	15	45	16,59	20	64	BTE6	-	105,70 €		
PTR-12B3	19,050	14	M20	17	15	45	19,46	20	64	BTE6	-	110,64 €		

\*Depending on availability - Dimensions in mm

## Our other products



HCV

V- rail guidance  
Simple Select®  
system, on rail



BAC105

Storage bin, 8mm



BPHclip

Clip for ball transfer  
unit, Insert clip -  
Installing from above



 
SME

Male rod ends ,  
Stainless steel / PTFE



PRF\_PL\_9090

Joining plate for  
aluminium profile,  
joint plate - 90x90  
mm



R\_RR

Narrow spur rack,  
Steel



APB\_BOU

Protective cap, Safety  
cap



PPG

Indexing plunger with  
flange, With  
horizontal mounting  
flange



VRC2

Retaining clamp, dual  
sided, Dual sided



PITAss

Locking bolt, with T  
handle



VAP

Magnetic stud with  
central hole, With  
central hole



CHINV

Invisible hinge,  
Invisible - Opening up  
to 90°

## Complementary products



 
BTE

Universal tension arm,  
For standard  
applications




TMR

Rigid manual  
tensioner, Adjustable



TC1rp

 Automatic chain  
tensioner, With 180°  
guide



RLR

Roll-Ring® chain  
tensioner, Roll-Ring®  
Self-adjusting