

Idler chain sprocket



PTR

For standard applications


- Chain sprocket for use with the BTE universal tension arm
- With ball bearings
- Greased for life
- Material: nut, screw, and sprocket in bichromate steel
- Max speed: 70 rpm
- t° of use: -30°C to + 80°C

**Good price/
quality/ratio**



Accessory

- BTE tension arm

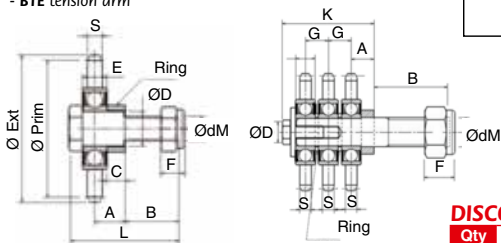

DISCOUNTS

Qty	1+	4+	10+
Disc.	List -10%	On request	

Part number	Pitch	No. of teeth			ØDm	ØD	A	B	C	E	F	L	Arm size	Stock*	Price each 1 to 3
		Z	S												
Single chain															
PTR-04B1	6,000	15	2,6	M6	6	7	15	4	6	6	28	BTE2	✓		27,01 €
PTR-05B1	8,000	14	2,8	M8	8	7,5	16	4	7	8	30	BTE2	-		24,62 €
PTR-06B1	9,525	17	5,3	M10	12	12	22	7	10	10	44	BTE3	✓		17,16 €
PTR-08B1	12,700	17	7,2	M12	17	15	26	9	12	12	53	BTE4/BTE5	✓		18,95 €
PTR-10B1	15,800	16	9,1	M12	17	15	26	9	12	12	53	BTE4/BTE5	✓		24,60 €
PTR-12B1	19,050	14	11,1	M12	17	15	26	9	12	12	53	BTE4/BTE5	✓		28,27 €

Part number	Pitch	No. of teeth			ØDm	ØD	A	B	G	F	L	Arm size	Stock*	Price each 1 to 3
		Z	S											
Double chain														
PTR-06B2	9,525	17	M12	12	12	35	10,24	12	35	BTE4	-		41,77 €	
PTR-08B2	12,700	17	M18	17	15	45	13,92	18,5	44	BTE5	-		49,13 €	
PTR-10B2	15,800	16	M20	17	15	45	16,59	20	46	BTE6	-		71,28 €	
PTR-12B2	19,050	14	M20	17	15	45	19,46	20	49	BTE6	-		81,09 €	
Triple chain														
PTR-06B3	9,525	17	M12	12	12	35	10,24	12	45	BTE4	-		56,53 €	
PTR-08B3	12,700	17	M18	17	15	45	13,92	18,5	58	BTE5	-		73,74 €	
PTR-10B3	15,800	16	M20	17	15	45	16,59	20	64	BTE6	-		105,70 €	
PTR-12B3	19,050	14	M20	17	15	45	19,46	20	64	BTE6	-		110,64 €	

*Depending on availability - Dimensions in mm

Our other products



SRG

Adjustable latch clamp with strike plate, Stroke from 77,3mm to 83mm



SDG

Adjustable guide support bracket, Plastic



ZG2

Plastic spur gear, Machined plastic (delrin)



BLH70

Right angled gearbox, from 26 to 128 Nm



PRF_JL6

Lip seal for panel, Door seal - Ø 6mm



COA-COG

Surface mounting plate, Surface mounting plate for clevis



MDB_MTB

Moulded plastic bevel gear (nylon), 2:1



LR

Precision locknut, Precision locknut



CHA_GC_14SS

Stainless steel garnet hinge, To screw



ESCON

Speed controller 5A, 5 A



RFV63

Stainless steel worm and wheel gearbox, up to 152 Nm



PRS80

Stainless steel articulated foot Ø80, Ø 80

Complementary products



 
BTE

Universal tension arm, For standard applications




TMR

Rigid manual tensioner, Adjustable



TC1rp

 Automatic chain tensioner, With 180° guide



RLR

Roll-Ring® chain tensioner, Roll-Ring® Self-adjusting