


- **Idler chain sprocket for use with BTE/SS universal tension arm**
- Fitted with sealed stainless steel bearings
- Max working temperature: 100°C
- Max speed : 70 rpm
- Material :Axle and gear :
Stainless steel 304L
Nuts : Stainless steel A2

Accessory

- **BTE/SS tension arm**

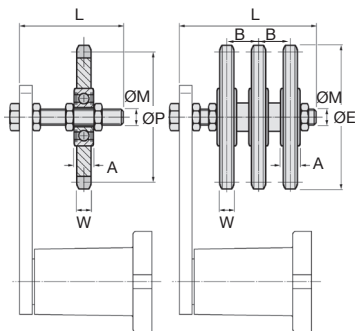

DISCOUNTS

Qty	1+	3+	5+
Disc.	List	-10%	On request

Part number	Pitch	N° of teeth Z	W	ØM	A	B	L	ØP	ØE	Size of arm	Price each 1 to 2
Simple											
PTR-06B1/SS	9,525	15	5,3	M10	9	-	55	45,81	49,3	BTE3/BTE4	41,51 €
PTR-08B1/SS	12,700	15	7,2	M10	9	-	55	61,09	65,5	BTE4	51,10 €
PTR-10B1/SS	15,800	15	9,1	M12	12	-	80	76,36	83,0	BTE5	65,63 €
PTR-12B1/SS	19,050	15	11,1	M12	12	-	80	91,63	99,8	BTE5	97,61 €
Double											
PTR-06B2/SS	9,525	15	5,3	M10	9	10,24	55	45,81	49,3	BTE4	76,40 €
PTR-08B2/SS	12,700	15	7,2	M10	9	13,92	60	61,09	65,5	BTE4	95,57 €
PTR-10B2/SS	15,800	15	9,1	M12	12	16,59	80	76,36	83,0	BTE5	123,48 €
PTR-12B2/SS	19,050	15	11,1	M12	12	19,46	80	91,63	99,8	BTE5	187,99 €
Triple											
PTR-06B3/SS	9,525	15	5,3	M10	9	10,24	60	45,81	49,3	BTE4	92,79 €
PTR-08B3/SS	12,700	15	7,2	M12	9	13,92	80	61,09	65,5	BTE5	133,21 €
PTR-10B3/SS	15,800	15	9,1	M12	12	16,59	80	76,36	83,0	BTE5	169,09 €
PTR-12B3/SS	19,050	15	11,1	M20	15	19,46	120	91,63	99,8	BTE6	222,30 €

Dimensions in mm

Our other products



PRF_JL5
Lip seal for panel,
Door seal - Ø 5mm



ZG0
Plastic spur gear,
Machined plastic
(delrin)



PTA100ssEB
Articulated foot with
sheet metal base
Ø100, Articulated foot




RCC_RCX
Spherical tilt washer -
DIN6319, convex



DOMI80
Domino 80 adjustable
slide, Slide DOMILINE
80



 GARDLL
Mounting sleeve for
lock pin, Nickel-plated
steel or Stainless steel



UCF_PBT
Stainless
steel/Polymer flanged
bearing, Polymer and
stainless steel



ATZY
Diabolo shaped elasto
mount, Steel



YG1
HEAVY DUTY spur
gear, Steel 35NCD6



PGT
Sliding profile, Sliding
panel support



SF_ZZ
Deep groove ball
bearing, Stainless



KH
Linear bearing, Light

Complementary products



TFR
Rigid manual
tensioner, Fixed



BTESS
Universal stainless
steel arm for
tensioner, For use in
hostile envi...