

Adjustable suction-cup support



PV1R

Standard grip

- Allows vacuum suction cups to be integrated into a handling system

- Materials :



Aluminium

Screws : steel

Advantages

- Infinitely variable angle of adjustment

- Easy, flexible mounting

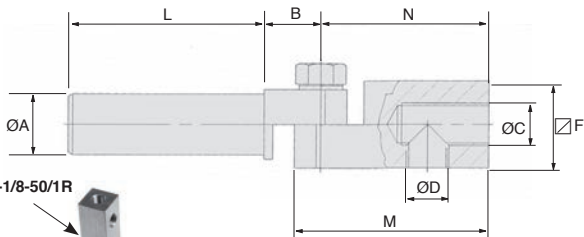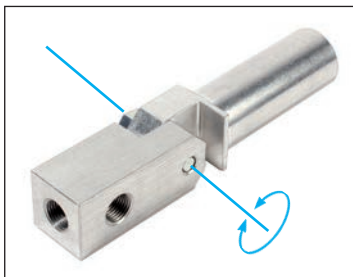

PV20-1/8-50/1R

BAN20/U

Typical application

DISCOUNTS

Qty	1+	10+	30+
Disc.	List	-5%	On request

Part number	ØA	B	ØC	ØD	L	M	∇ F	N	Weight (g)	Price each 1 to 9
PV20-1/8-50/1R	20	15	G1/8"	G1/8"	50	47	20	41	72	51,16 €
PV20-1/8-100/1R	20	15	G1/8"	G1/8"	100	47	20	41	87	53,36 €
PV20-1/8-150/1R	20	15	G1/8"	G1/8"	150	47	20	41	103	55,55 €
PV20-1/4-50/1R	20	15	G1/4"	G1/4"	50	49	25	43	93	52,27 €
PV20-1/4-100/1R	20	15	G1/4"	G1/4"	100	49	25	43	106	54,46 €
PV20-1/4-150/1R	20	15	G1/4"	G1/4"	150	49	25	43	123	56,64 €

Dimensions in mm

Our other products



GMK17_BR

Clamp for guiding profile, Rounded only - double



ACL-APB

Closing system for aluminium profile, Magnetic door stop



GAL48_OMNI

Omni-directional roller, Omni-directional



SR

Narrow spur rack, Stainless steel



CMAss

Eye bolt stainless steel, Stainless steel



RJA10_03

Sealing strip, Clipping



F7-SN

Multifunction display, Articulated support



 
ARTE

Flexible bush, For multi-directional loads



DB

Steel bevel gear, 2:1




NANO

Speed controller 3A, 3 A



TS01_TW01

 Drylin® T linear slide, up to 7000 N



BH01

Single housed bearing, Bearing fitted with adhesive

Complementary products



PV2R

Adjustable suction-cup support, Increased grip