

Adjustable suction-cup support



PV1R

Standard grip

- Allows vacuum suction cups to be integrated into a handling system

- Materials :



Aluminium

Screws : steel

Advantages

- Infinitely variable angle of adjustment

- Easy, flexible mounting

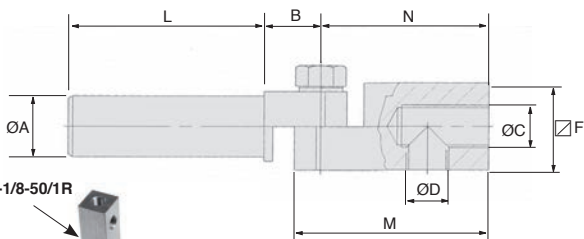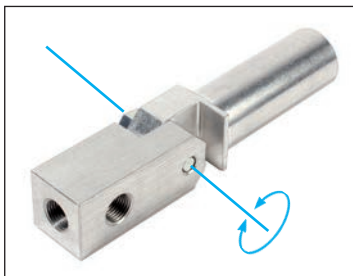

PV20-1/8-50/1R

BAN20/U

Typical application

DISCOUNTS

Qty	1+	10+	30+
Disc.	List	-5%	On request

Part number	ØA	B	ØC	ØD	L	M	∇ F	N	Weight (g)	Price each 1 to 9
PV20-1/8-50/1R	20	15	G1/8"	G1/8"	50	47	20	41	72	51,16 €
PV20-1/8-100/1R	20	15	G1/8"	G1/8"	100	47	20	41	87	53,36 €
PV20-1/8-150/1R	20	15	G1/8"	G1/8"	150	47	20	41	103	55,55 €
PV20-1/4-50/1R	20	15	G1/4"	G1/4"	50	49	25	43	93	52,27 €
PV20-1/4-100/1R	20	15	G1/4"	G1/4"	100	49	25	43	106	54,46 €
PV20-1/4-150/1R	20	15	G1/4"	G1/4"	150	49	25	43	123	56,64 €

Dimensions in mm

Our other products



RTN

BoWex® curved tooth gear coupling, Nylon



LVT

Miniature motorised actuator 2A, 2 amperes



PSG25

Spur gear - precision range, Stainless steel 316



SVT_CH

Screwjack - pivot mounting, Pivoting bracket



PR820

Idler sprocket for slat top chain, Rangs 820 and 815



ZDB

Machined plastic bevel gear, 2:1



CTZYSS

Stainless steel diabolo shaped elasto mount, Stainless steel



CHN_CHNSS

Straight long link chain, Galvanised steel



UCFL_PBT

Stainless steel/Polymer flanged bearing, Polymer and



PCS_PA6

Plastic sprocket, 9.525mm (DIN 06B-1)



BEAS

Knob star grip antistatic, Star, antistatic



OPFL_OPPM

Numerical counter accessories, Locking clamp

Complementary products



PV2R

Adjustable suction-cup support, Increased grip