

Adjustable suction-cup support



PV1R

Standard grip

- Allows vacuum suction cups to be integrated into a handling system

- Materials :



Aluminium

Screws : steel

Advantages

- Infinitely variable angle of adjustment

- Easy, flexible mounting

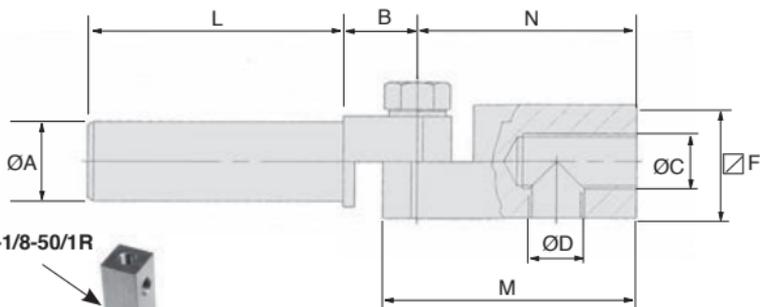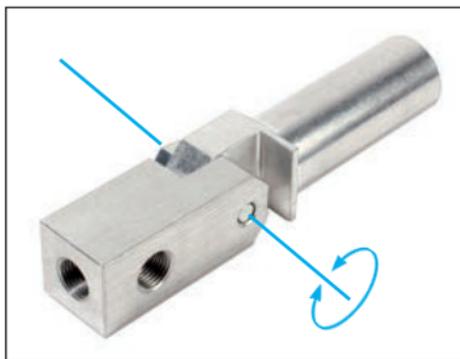

PV20-1/8-50/1R

BAN20/U

Typical application

DISCOUNTS

Qty	1+	10+	30+
Disc.	List	-5%	On request

Part number	ØA	B	ØC	ØD	L	M	∇ F	N	Weight (g)	Price each 1 to 9
PV20-1/8-50/1R	20	15	G1/8"	G1/8"	50	47	20	41	72	51,16 €
PV20-1/8-100/1R	20	15	G1/8"	G1/8"	100	47	20	41	87	53,36 €
PV20-1/8-150/1R	20	15	G1/8"	G1/8"	150	47	20	41	103	55,55 €
PV20-1/4-50/1R	20	15	G1/4"	G1/4"	50	49	25	43	93	52,27 €
PV20-1/4-100/1R	20	15	G1/4"	G1/4"	100	49	25	43	106	54,46 €
PV20-1/4-150/1R	20	15	G1/4"	G1/4"	150	49	25	43	123	56,64 €

Dimensions in mm

Our other products



RBNtc

Swivel castor with central hole, Steel - rubber - with double brake




AT5-25ECO

AT type timing pulley, Economy range - AT5 aluminium



Q6

Deep groove ball bearing, Steel

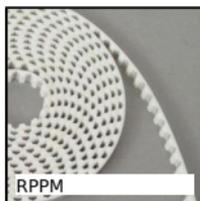

RPPM

RPP type belt per metre, RPP8 Steel cored polyurethane



SDC_{ss}

Positioning sleeve for indexing pin, For pin Ø4 to Ø12



RAM35

Manual bevel gearbox, Bevel



VRSS_{ss}

Male swivelling lifting rings stainless steel, Male swivelling - s...



CAB_{ma}

Swaging sleeve for fitting cable, To crimp a wire rope




VTLB

Three-lobed knob, Thermoplastic / Brass or stainless steel insert



HTD8M_30

HTD Heavy duty timing pulley, HTD8 Steel

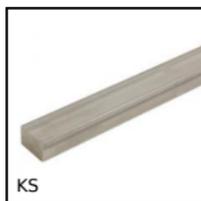

KS

Keysteel, Stainless steel - Keystock



MET

Cylindrical sintered bronze bush, Self-lubricating sintered bronze

Complementary products



PV2R

Adjustable suction-cup support, Increased grip