



Adjustable suction-cup support

Increased grip



PV2R

- Allows vacuum suction cups to be integrated into a handling system

- Materials :
Aluminium
Screws : steel

Advantages

- Infinitely variable angle of adjustment
- No circlips required

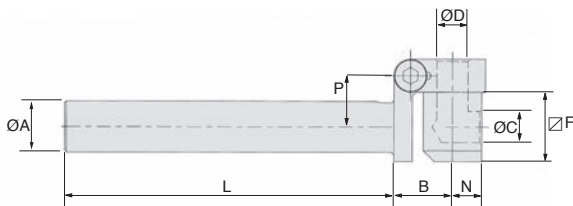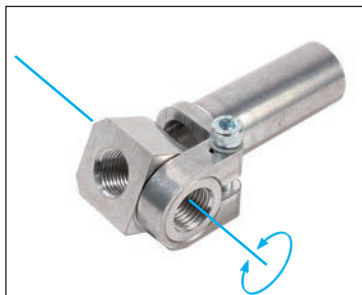

Exploded view



DISCOUNTS

Qty	1+	10+	30+
Disc. List	-5%	On request	

Part number	ØA	B	ØC	ØD	L	∇F	N	P	Weight (g)	Price each 1 to 9
PV20-1/4-50/2R	20	19	G1/4"	G1/4"	50	24	12	16,5	57	70,81 €
PV20-1/4-100/2R	20	19	G1/4"	G1/4"	100	24	12	16,5	71	73,65 €
PV20-1/4-150/2R	20	19	G1/4"	G1/4"	150	24	12	16,5	86	77,92 €

Dimensions in mm

Our other products



BPLF

Ball transfer unit light duty, Light



UGCG

Actuator guide kit, Long housing



G01

Single universal joint, Normal duty



SER69K-CLE

Quarter turn latch for the food industry, Stainless steel key



SCA_SS

Stainless steel flat cable clamp, Stainless steel



DTR

Chain idler sprocket, Chain idler sprocket - Plastic



 
TB_ECO

Eco. range steel bevel gear, gear, 3:1




PFM

Fixed levelling foot, Flanged plate



NK80

 Drylin®N miniature guiding system, Width 80mm



RPP

Connecting plate for RPP type timing belts, RRP5



PP50

Worm and wheel gear reducer, from 6.50 to 12.80 Nm



BPFLss

Pressed stainless steel flange bearing, Stainless steel

Complementary products