



# Adjustable suction-cup support

Increased grip



PV2R

- Allows vacuum suction cups to be integrated into a handling system

- Materials :  
Aluminium  
Screws : steel

## Advantages

- Infinitely variable angle of adjustment
- No circlips required

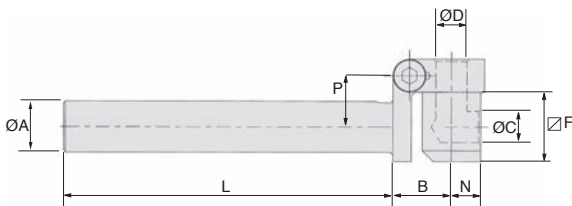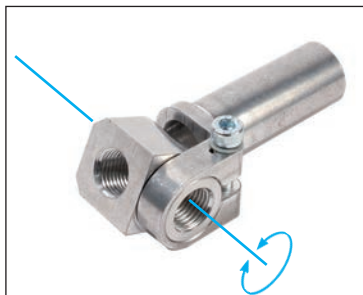

Exploded view




## DISCOUNTS

 Qty	1+	10+	30+
Disc.	List	-5%	On request


Part number	ØA	B	ØC	ØD	L	∇F	N	P	Weight (g)	Price each 1 to 9
PV20-1/4-50/2R	20	19	G1/4"	G1/4"	50	24	12	16,5	57	70,81 €
PV20-1/4-100/2R	20	19	G1/4"	G1/4"	100	24	12	16,5	71	73,65 €
PV20-1/4-150/2R	20	19	G1/4"	G1/4"	150	24	12	16,5	86	77,92 €

Dimensions in mm

## Our other products



Manual lifting tables,  
12kg

 

Manually operated  
gearbox, Bevel



Castor for aluminium  
profile, No brake



T type timing pulley,  
T5 aluminium



Spherical bushing,  
Hard chromium / PTFE



Deep groove ball  
bearing, Steel



Cam follower without  
axial guide, Without  
interior ring



Idler sprocket for slat  
top chain, Ranges 821  
and 805



Right angled gearbox,  
bored shafts, up to  
4.47 Nm



Stainless steel  
hexagonal headed  
thumb nut, Lobed



Low cost stainless  
steel quick link,  
Stainless steel



Modular cylindrical  
brush, Tampico  
bristles

Complementary products