



Adjustable suction-cup support



Increased grip

PV2R

- Allows vacuum suction cups to be integrated into a handling system
- Materials :
Aluminium
Screws : steel

Advantages

- Infinitely variable angle of adjustment
- No circlips required

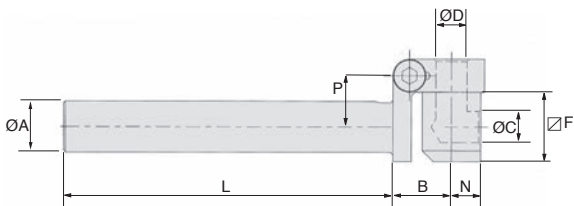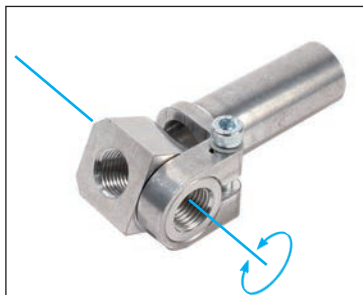

Exploded view



DISCOUNTS

Qty	1+	10+	30+
Disc. List		-5%	On request

Part number	ØA	B	ØC	ØD	L	∇F	N	P	Weight (g)	Price each 1 to 9
PV20-1/4-50/2R	20	19	G1/4"	G1/4"	50	24	12	16,5	57	70,81 €
PV20-1/4-100/2R	20	19	G1/4"	G1/4"	100	24	12	16,5	71	73,65 €
PV20-1/4-150/2R	20	19	G1/4"	G1/4"	150	24	12	16,5	86	77,92 €

Dimensions in mm

Our other products



RBN
Wheel, Rubber tyre -
Polypropylene rim



SBF
Sealed flange bearing
unit for Food Industry,
cover



BL8
Right angled gearbox,
from 0.20 to 2 Nm



HTD3M_09
HTD Heavy duty
timing pulley, HTD3
Aluminium



AT5M AT10M
AT type timing belt
per metre, AT5 Steel
cored polyurethane



GE
Toggle latches,
Standard



LSAG
Sleeve for splined ball
shaft, Chariot - from
514 N to 15386 N



SVG
Adjustable latch
clamp with strike
plate, Stroke from
82mm to 92mm



PM4
Worm and wheel set,
Machined plastic



WS16
Drylin® W rail, Rail



BIMSS
Indexing plunger mini,
miniature - Stainless



AFA
Locking pin, with ring

Complementary products