



Adjustable suction-cup support

Increased grip



PV2R

- Allows vacuum suction cups to be integrated into a handling system

- Materials :
Aluminium
Screws : steel

Advantages

- Infinitely variable angle of adjustment
- No circlips required

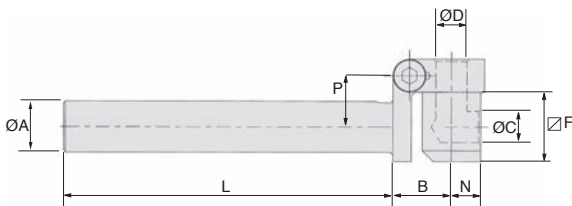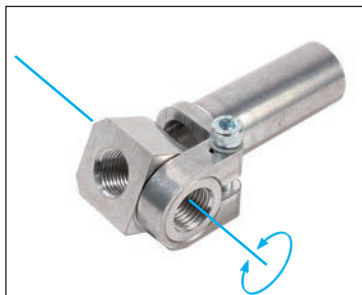

Exploded view



DISCOUNTS

Qty	1+	10+	30+
Disc.	List	-5%	On request

Part number	ØA	B	ØC	ØD	L	∇F	N	P	Weight (g)	Price each 1 to 9
PV20-1/4-50/2R	20	19	G1/4"	G1/4"	50	24	12	16,5	57	70,81 €
PV20-1/4-100/2R	20	19	G1/4"	G1/4"	100	24	12	16,5	71	73,65 €
PV20-1/4-150/2R	20	19	G1/4"	G1/4"	150	24	12	16,5	86	77,92 €

Dimensions in mm

Our other products



SBS_L
Chain link, Stainless steel



LVT
Miniature motorised actuator 1A, 1 amper



T10_21N1F
T type timing pulley, Economy range - T10 moulded plastic (nylon)




COA-COG
Surface mounting plate, Surface mounting plate for clevis



H0
Crossed helical gear crossed axis at 90°, Steel 20NCD2



 CHM50
Worm and wheel gear reducer, up to 107 Nm



SCA
Flat cable clamp, Steel



LVT
Miniature motorised actuator 4A, 4 amper



SSB
Stainless steel bevel gear, 1:1



CDPC
Flanged drill bushing, Steel



BAN
Angular clamp, Standard



GP
Spring loaded toggle latch, With padlock-holder

Complementary products