

 


Small lobed handle

PVL

With square bore

- **Handling element**
- Max working temperature: 100°C
- Material:
Polyamide
- Not sold individually,
please contact-us for details

Square
bore

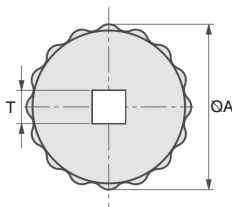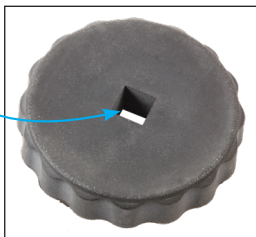

DISCOUNTS

Qty	1+	10+	20+	50+	100+	200+
Disc	Net	-5%	-10%	-15%	-20%	On request

Part N°	ØA	ØB	C	T	F	G	Weight (g)	Stock*	Price each 1 to 9
PVL40-6/SQ	40	20	9	6x6	1	8	10	✓	2,35 €
PVL40-8/SQ	40	20	9	8x8	1	8	10	✓	2,35 €

All dimensions in mm

HPC

WEB
04/2021

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

Our other products



BIMSS

Indexing plunger mini,
miniature - Stainless
steel



CRM

Moulded nylon rack,
Nylon



GFX

Curved tooth
coupling, economy
range, Steel and
polyamide



SLV

Vertical toggle clamp,
Vertical Lever Clamp -
steel



PML

Solid foot mount for
heavy loads, Ø 100,
120 or 150



SDB

Locking bolt support
bracket, Mounting
holes at 90° to
locating bolt



SH0

Parallel axis helical
gear, Machined plastic
(delrin)



BLHB40

Right angled gearbox,
bored shafts, up to
10.3 Nm



 
CHCSS

Socket headed screw,
Stainless steel - A2



CHAE4060PA

Decorative
asymmetric screwed



TBV

Manual lifting tables,
3kg



SHA

Handwheel without
handle, Polyamide

Complementary products



BMF

Knurled knob -
female, Knurled -
blind



GLB

Small 6 lobe threaded
handle - female,
Technopolymer -
Brass



GGB

Female wing knob,
Fully threaded