




Small lobed handle

PVL

With square bore

- **Handling element**
- Max working temperature: 100°C
- Material:
Polyamide
- Not sold individually,
please contact-us for details

Square
bore

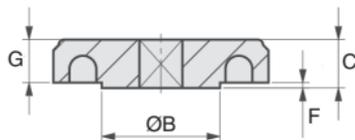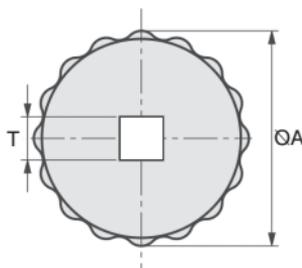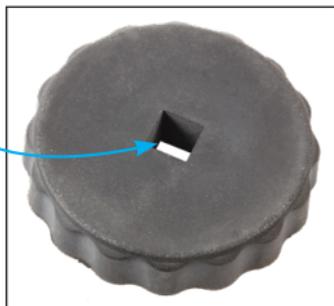

DISCOUNTS

Qty	1+	10+	20+	50+	100+	200+
Disc	Net	-5%	-10%	-15%	-20%	On request

Part N°	ØA	ØB	C	T	F	G	Weight (g)	Stock*	Price each 1 to 9
PVL40-6/SQ	40	20	9	6x6	1	8	10	✓	2,35 €
PVL40-8/SQ	40	20	9	8x8	1	8	10	✓	2,35 €

All dimensions in mm

HPC

WEB
04/2021

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

Our other products



PTR
 Idler chain sprocket,
 For standard
 applications



BSPM
 Miniature ballscrew,
 Nut+rolled ballscrew



EHD16
 Internal epicyclic
 servo reducers, from
 210 to 380 Nm



PRES2HR
 Manual workbench
 press, Force up to
 200kg



RPCtc
 Swivel castor with
 central hole, Steel -
 Polyamide - with
 double brake



PTCR
 Adjustable furniture
 foot, square tube



QNUP
 Single row cylindrical
 roller bearing, 1 fixed
 inner flange and 1 fr...



DEP
 Tools Hygienic Usit®
 and Hygienic
 Design®, Protective
 insert for s...



BEAS
 Knob star grip
 antistatic, Star, anti-



ZHG5
 Plastic spur gear,
 Machined plastic



ADL_M
 Male eye bolt
 conforms to DIN580,



DH
 Dowel pin, Solid DIN
 6325

Complementary products



BMF
 Knurled knob -
 female, Knurled -
 blind



GLB
 Small 6 lobe threaded
 handle - female,
 Technopolymer -
 Brass



GGB
 Female wing knob,
 Fully threaded