

 


# Small lobed handle

## PVL

## With square bore

- **Handling element**
- Max working temperature: 100°C
- Material:  
Polyamide
- Not sold individually,  
please contact-us for details

Square bore

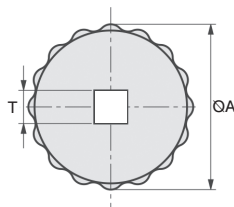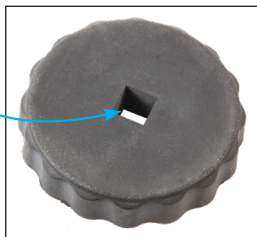

### DISCOUNTS

Qty	1+	10+	20+	50+	100+	200+
Disc	Net	-5%	-10%	-15%	-20%	On request

Part N°	ØA	ØB	C	T	F	G	Weight (g)	Stock*	Price each 1 to 9
PVL40-6/SQ	40	20	9	6x6	1	8	10	✓	2,35 €
PVL40-8/SQ	40	20	9	8x8	1	8	10	✓	2,35 €

All dimensions in mm

**HPC**

WEB  
04/2021

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

## Our other products



PLA

Flat magnet, Flat magnet with thread



BFM

Flanged bronze nut, Bronze - 1 thread



MDB\_MTB

Moulded plastic bevel gear (nylon), 3:1



TBEBASE

Base plate for economic mini-table, Allows X-Y cross tables



HRV

V-rail guidance Simple Select® system, Rail with carriage



BSM\_LOK

Long-Lok spring plunger with internal hexagonal socket, LONG-LOK - s...



RTE

Rotex®, jaw coupling, steel



CQA20

Adjustment slide-system miniature, 20



SHNbr

Hexagonal nut DIN934, Brass



HLC19

Right angle spirol bevel gearbox, Up to



AFA

Locking pin, with ring



P45

Worm and wheel gear reducer, up to 40 Nm

## Complementary products



BMF

Knurled knob - female, Knurled - blind



GLB

Small 6 lobe threaded handle - female, Technopolymer - Brass



GGB

Female wing knob, Fully threaded