

 


Small lobed handle

PVL

With square bore

- **Handling element**
- Max working temperature: 100°C
- Material:
Polyamide
- Not sold individually,
please contact-us for details

Square
bore

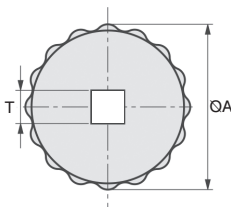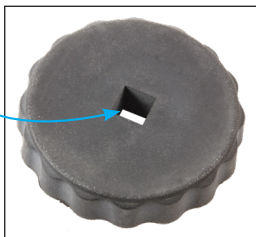

DISCOUNTS

Qty	1+	10+	20+	50+	100+	200+
Disc	Net	-5%	-10%	-15%	-20%	On request

Part N°	ØA	ØB	C	T	F	G	Weight (g)	Stock*	Price each 1 to 9
PVL40-6/SQ	40	20	9	6x6	1	8	10	✓	2,35 €
PVL40-8/SQ	40	20	9	8x8	1	8	10	✓	2,35 €

All dimensions in mm

HPC

WEB
04/2021

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

Our other products



CHMX_CHMDX

Shaft for worm and wheel reducer CHMR and CHM, CHMR and CHM gearbox...



NCT

Square tube connector, Fixed angle



AC

Strike for toggle latch, 15mm



PR40

Articulated foot Ø50, Ø 50



RURp

Fixed castor with plate, Polyurethane - Aluminium rim (Free running)



PITAss

Locking bolt, with T handle



GEC

Rubber latch clamp with strike plate, Lockable



ERC

Quick fitting cable terminal, Eye version



INS_SS

Self tapping stainless steel insert, 316



PSPT

Flexible tube handle, PVC



LFM

Steel leadscrew, Medium carbon steel -



P45

Worm and wheel gear reducer, up to 40 Nm

Complementary products



BMF

Knurled knob - female, Knurled - blind



GLB

Small 6 lobe threaded handle - female, Technopolymer - Brass



GGB

Female wing knob, Fully threaded