

 


Small lobed handle

PVL

With square bore

- **Handling element**
- Max working temperature: 100°C
- Material:
Polyamide
- Not sold individually,
please contact-us for details

Square bore

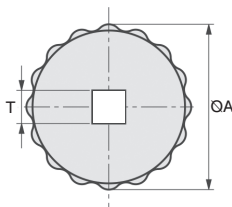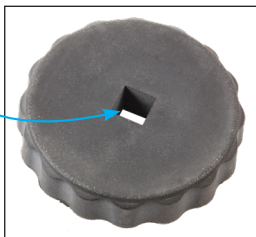

DISCOUNTS

Qty	1+	10+	20+	50+	100+	200+
Disc	Net	-5%	-10%	-15%	-20%	On request

Part N°	ØA	ØB	C	T	F	G	Weight (g)	Stock*	Price each 1 to 9
PVL40-6/SQ	40	20	9	6x6	1	8	10	✓	2,35 €
PVL40-8/SQ	40	20	9	8x8	1	8	10	✓	2,35 €

All dimensions in mm


HPC

WEB
04/2021


www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel


Our other products

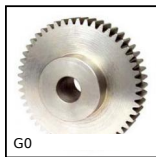

G0
Steel spur gear, Steel
20NCD2

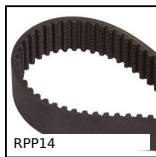

RPP14
RPP heavy duty
timing belt, RPP14

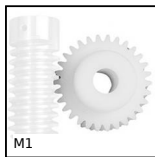

M1
Wormwheel ,
Machined plastic
(delrin)



DER63
Stainless steel AC
asynchronous motor
0.18 kW, 0.18kW



MRASeco
Low cost stainless
steel quick link,
Stainless steel



PLN
Cylindrical spacer,
Thermoplastic



ERC
Quick fitting cable
terminal, Eye version




PSG125S
Spur gear - precision
range, Stainless steel
316



DCA
Suction cup, 1.5
bellows, silicon



RFK48C
Hypoid gearbox -
Stainless steel, up to
2000W

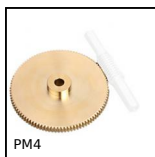

PM4
Wormwheel, Bronze



T5P_T10P
Connecting plate for T
type timing belts, T5

Complementary products



BMF
Knurled knob -
female, Knurled -
blind



GLB
Small 6 lobe threaded
handle - female,
Technopolymer -
Brass



GGB
Female wing knob,
Fully threaded