

PW PSW Worm and wheel set

Worm available in pre-treated or **stainless steel**

Module 3,0



- Quality grade 7e25 DIN 3974
- Pressure angle: 20°
- Material:
 - Pre-treated steel 35NCD6, 28HRC
 - Stainless steel 303
- Tooth thickness conforms to DIN 3967



Info.

- Torque figures are for 100 rpm and are given as a guide only.

Quality grade 7e25

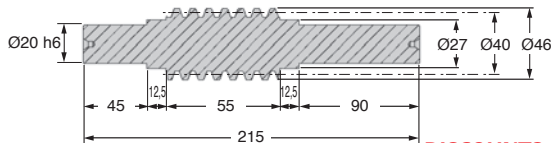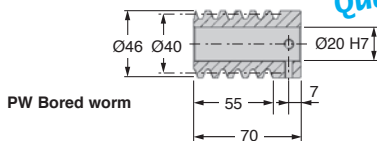

DISCOUNTS

Qty	1+	6+	19+	50+
Disc.	List	-5%	-10%	On request

Part number		No of starts	Price each 1 to 5	
Steel	Stainless steel		Steel	Stainless steel
Bored worm				
PW3.0-1	PW3.0-1S	1	180,83 €	244,18 €
PW3.0-2	PW3.0-2S	2	180,83 €	244,18 €
PW3.0-3	PW3.0-3S	3	180,83 €	244,18 €
PW3.0-4	PW3.0-4S	4	180,83 €	244,18 €
Shaft worm				
PSW3.0-1	PSW3.0-1S	1	258,76 €	349,38 €
PSW3.0-2	PSW3.0-2S	2	258,76 €	349,38 €
PSW3.0-3	PSW3.0-3S	3	258,76 €	349,38 €
PSW3.0-4	PSW3.0-4S	4	258,76 €	349,38 €

Dimensions in mm

Worm and wheel set

Bronze wheel

PWG
Module
3,0



- Quality grade 7e25 DIN 3974
- Pressure angle: 20°
- Material: Bronze CA104 (CuAl10Ni5Fe4)
- Tooth thickness conforms to DIN 3967

Options

- Alternative bores (H7)
- Keyway conforming to DIN6885 (J59)
- Tapped hole
- Hole for dowel pin

Info.

- Torque figures are for 100 rpm and are given as a guide only.
- To order, add the number of starts to the part number: e.g. worm PW3,0-4, wheel PWG3,0-15-4

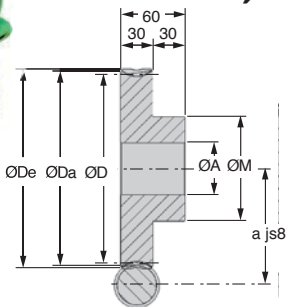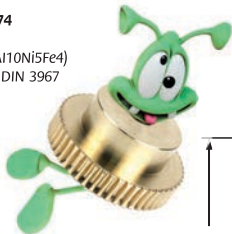

DISCOUNTS

Qty	1+	6+	19+	50+
Disc.	List	-5%	-10%	On request

Part number	No of teeth	a	OD	ODa	ODe	Bore ØA	ØM	Theoretical backlash (mm)		Torque (Nm)	Price each 1 to 5
								Max.	Min.		
PWG3.0-15-1	15	42,50	45	51	54	12	35	0,117	-0,038	33,19	208,60 €
PWG3.0-16-1	16	44,00	48	54	57	12	35	0,117	-0,038	37,27	216,55 €
PWG3.0-17-1	17	45,50	51	57	60	12	35	0,137	-0,048	41,57	230,10 €
PWG3.0-18-1	18	47,00	54	60	63	12	35	0,137	-0,048	46,08	243,60 €
PWG3.0-19-1	19	48,50	57	63	66	12	35	0,137	-0,048	51,73	257,15 €
PWG3.0-20-1	20	50,00	60	66	69	12	35	0,137	-0,048	56,73	263,59 €
PWG3.0-21-1	21	51,50	63	69	72	14	50	0,139	-0,045	63,06	284,24 €
PWG3.0-22-1	22	53,00	66	72	75	14	50	0,139	-0,045	68,57	297,80 €
PWG3.0-23-1	23	54,50	69	75	78	14	50	0,139	-0,045	74,28	307,62 €
PWG3.0-24-1	24	56,00	72	78	81	14	50	0,139	-0,045	81,63	312,00 €
PWG3.0-25-1	25	57,50	75	81	84	14	50	0,139	-0,045	87,85	317,43 €
PWG3.0-26-1	26	59,00	78	84	87	14	50	0,139	-0,045	94,28	362,56 €
PWG3.0-27-1	27	60,50	81	87	90	14	50	0,139	-0,045	101,79	388,59 €
PWG3.0-28-1	28	62,00	84	90	93	14	50	0,139	-0,045	108,68	418,74 €
PWG3.0-29-1	29	63,50	87	93	96	16	65	0,139	-0,045	116,77	438,25 €
PWG3.0-30-1	30	65,00	90	96	99	16	65	0,139	-0,045	124,12	456,95 €
PWG3.0-32-1	32	68,00	96	102	105	16	65	0,139	-0,045	139,41	540,36 €
PWG3.0-35-1	35	72,50	105	111	114	16	65	0,139	-0,045	163,81	622,15 €
PWG3.0-38-1	38	77,00	114	120	123	16	65	0,139	-0,045	196,49	701,85 €
PWG3.0-40-1	40	80,00	120	126	129	16	65	0,139	-0,045	215,50	812,64 €

Wheels available with 15 to 40 teeth

Dimensions in mm

Our other products



MSP23

Masterplate® glueable insert Ø23, Cylindrical Ø23 with threaded s...



GE_ES_2RS

Spherical bushing, Steel / steel with seals



SCA_SS

Stainless steel flat cable clamp, Stainless steel



GLB

Small 6 lobe threaded handle - female, Technopolymer - Brass



HG6-ECO

Eco range Spur gear, Steel C45



PW_PWG05

Worm - precision range, Steel



VELprf

Clip-on base for hook-and-loop strip, Polyamide



BZY

Cylindrical elastomount, Steel



HTD3M_09

HTD Heavy duty timing pulley, HTD3 Aluminium



WJUM20

Drylin® W bearing block, Slide



NK17

Drylin® N miniature guiding system, Width 17 mm



VRSSss

Male swivelling lifting rings stainless steel, Male swivelling - s...

Complementary products



PW_PWG3

Worm - precision range, Steel



PW_PWG3

Worm - precision range, Stainless steel