


For P and PF gearboxes

PX
PDX


- **Optional accessory for adding outputs shafts**
to P and PF gearboxes

Composition


- Single sided shaft kit P-X: Stainless steel 303 shaft, 2 steel keys and 2 steel circlips
- Double sided shaft kit P-dx: Stainless steel 303 shaft, 3 steel keys and 2 steel circlips

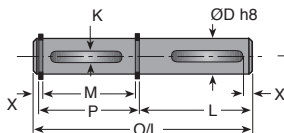


Single sided shaft P-X

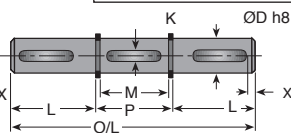

Double sided shaft P-DX

 

Single sided Double sided
Typical applications

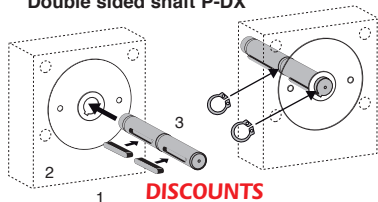


DISCOUNTS

Qty	1+	2+	4+	6+
Disc.	List	-10%	-15%	On request

Part number	For gearbox								Stock*	Price each
	ØD	O/L	M	P	X	L	K			
Single sided										
P20-X	P20-PF20	6	50,80	22	23,60	3,00	25	K2 x 22	✓	39,49 €
P30-X	P30-PF30	8	63,90	28	29,80	3,00	32	K2 x 22	✓	46,41 €
P40-X	P40-PF40	10	76,60	32	34,20	3,50	40	K3 x 20	✓	52,16 €
P45-X	P45-PF45	12	88,10	38	40,20	4,00	45	K4 x 25	-	56,03 €
P55-X	P55-PF55	15	101,10	46	48,20	4,00	50	K5 x 30	-	62,06 €
P60-X	P60-PF60	20	119,80	54	56,60	4,50	60	K6 x 32	-	72,95 €
P70-X	P70-PF70	25	135,80	60	62,60	4,50	70	K8 x 40	-	83,83 €
Double sided										
P20-DX	P20-PF20	6	73,60	22	23,60	1,50	25	K2 x 22	-	52,00 €
P30-DX	P30-PF30	8	93,80	28	29,80	5,45	32	K2 x 22	-	56,52 €
P40-DX	P40-PF40	10	114,20	32	34,20	9,90	40	K3 x 20	-	64,73 €
P45-DX	P45-PF45	12	130,20	38	40,20	4,00	45	K4 x 25	-	70,73 €
P55-DX	P55-PF55	15	148,20	46	48,20	9,90	50	K5 x 30	-	77,07 €
P60-DX	P60-PF60	20	176,60	54	56,60	4,50	60	K6 x 32	-	89,62 €
P70-DX	P70-PF70	25	202,50	60	62,60	4,50	70	K8 x 40	-	102,16 €

Dimensions in mm

 Our other products



RDE-W

Sealing washer
Hygienic Usit®,
Stainless steel - White
EPDM



TOC

Short swivel head,
Short



SRG

Adjustable latch
clamp with strike
plate, Stroke from
77,3mm to 83mm



PRF_BP

Doorstop for
aluminium profile,
Swing door stop



GTC

Belt tensioner, For
standard applications



DOMI120

Connecting kits, XY
linking kit



NSR

Adjustable clamp,
Adjustable



RHTplss

High Temperature
Castor, up to 200kg



AT5M AT10M

AT type timing belt
per metre, AT10 Steel
cored polyurethane



E50

Right angle helical
reducers, from 3 to 41
Nm



RAS

 
90° ball and socket
joints DIN71802, Steel



FBL6000_K19


Brush strip per meter
horsehair fibres Ø0.2,
Black horsehair

Complementary products



P15

 Worm and wheel gear
reducer, up to 3,75
Nm



PF15

Worm and wheel gear
reducer, up to 3,75
Nm