


For P and PF gearboxes

Px
Pdx


- **Optional accessory for adding outputs shafts**
to P and PF gearboxes

Composition


- Single sided shaft kit P-X: Stainless steel 303 shaft, 2 steel keys and 2 steel circlips
- Double sided shaft kit P-dx: Stainless steel 303 shaft, 3 steel keys and 2 steel circlips

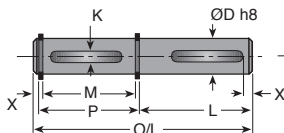


Single sided shaft P-X

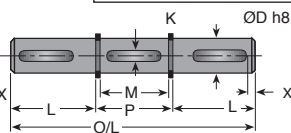

Double sided shaft P-DX

 

Single sided Double sided
Typical applications

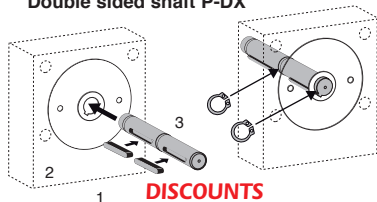

DISCOUNTS

Qty	1+	2+	4+	6+
Disc.	List	-10%	-15%	On request

Part number	For gearbox								Stock*	Price each
	ØD	O/L	M	P	X	L	K			
Single sided										
P20-X	P20-PF20	6	50,80	22	23,60	3,00	25	K2 x 22	✓	39,49 €
P30-X	P30-PF30	8	63,90	28	29,80	3,00	32	K2 x 22	✓	46,41 €
P40-X	P40-PF40	10	76,60	32	34,20	3,50	40	K3 x 20	✓	52,16 €
P45-X	P45-PF45	12	88,10	38	40,20	4,00	45	K4 x 25	-	56,03 €
P55-X	P55-PF55	15	101,10	46	48,20	4,00	50	K5 x 30	-	62,06 €
P60-X	P60-PF60	20	119,80	54	56,60	4,50	60	K6 x 32	-	72,95 €
P70-X	P70-PF70	25	135,80	60	62,60	4,50	70	K8 x 40	-	83,83 €
Double sided										
P20-DX	P20-PF20	6	73,60	22	23,60	1,50	25	K2 x 22	-	52,00 €
P30-DX	P30-PF30	8	93,80	28	29,80	5,45	32	K2 x 22	-	56,52 €
P40-DX	P40-PF40	10	114,20	32	34,20	9,90	40	K3 x 20	-	64,73 €
P45-DX	P45-PF45	12	130,20	38	40,20	4,00	45	K4 x 25	-	70,73 €
P55-DX	P55-PF55	15	148,20	46	48,20	9,90	50	K5 x 30	-	77,07 €
P60-DX	P60-PF60	20	176,60	54	56,60	4,50	60	K6 x 32	-	89,62 €
P70-DX	P70-PF70	25	202,50	60	62,60	4,50	70	K8 x 40	-	102,16 €

Dimensions in mm

Our other products



T10courroie

T type timing belt,
T10 Steel cored
polyurethane



PRF_ECL

Nut for aluminium
profile, Steel square
nut with tab



KBS_UU

Stainless steel closed
precision linear
bearing, Precision -
stainle...



BC3

Panamech, Multi-
Beam stainless steel,
Stainless steel - with
clampin...



SSDB

Stainless steel bevel
gear, 2:1



RAS

90°ball and socket
joints DIN71802,
Stainless steel



BCM_CC

Modular cylindrical
brush, Horsehair
bristles



T2,5-BAR

T type tooth bar
stock, T2.5



PLC_PLT

Magnetic stud with
threaded hole, With
threaded hole



GE

Toggle latches,
Standard



ACL-PL

Joining plate for
aluminium profile,
Joint plate - 176x86
mm



SLBE

Indexing plunger -
Spacer, Spacer for
SLB and SLBS index
bolts

Complementary products



P15

Worm and wheel gear
reducer, up to 3,75
Nm



PF15

Worm and wheel gear
reducer, up to 3,75
Nm