

# Carrying handle

PX  
PO


Steel

## Handle PX399-BR:

- The plate and ring of the handle are not attached
- Plate: 1mm thick formed steel
- Ring: formed wire Ø4.9mm

## Handle PO301-ZB:


- Reduced height saves space
- Ring is secured to plate
- Two part riveted plate, 1.5mm
- 5 fixing holes Ø5.5mm
- Ring: Formed steel wire 8mm
- Plate secured using 4 x light alloy rivets Ø3mm

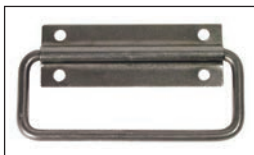


Handle PX399-BR




Handle PO301-ZB

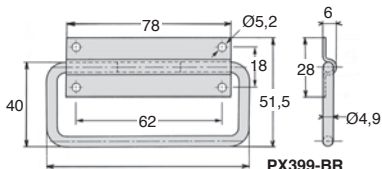

PX399-BR

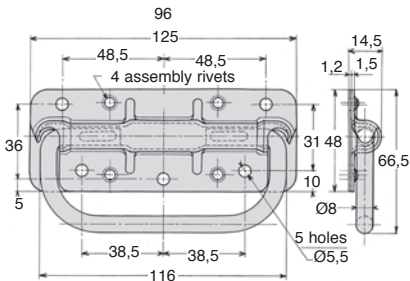

PO301-ZB

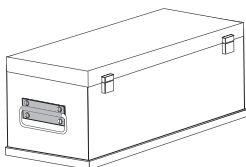

Typical application

## DISCOUNTS

Qty	1+	6+	20+	50+	250+	400+
Disc.	List	-5%	-10%	-15%	-25%	On request

Part number	Finish	Fixing	Max. load per handle (kgf)	Weight (kg)	Stock*	Price each 1 to 5
<b>Ordinary carry handle</b>						
PX399-BR	Unfinished	With hole	-	0,049	✓	1,25 €
<b>Riveted carrying handle</b>						
PO301-ZB	White zinc	With hole	60	0,023	✓	7,84 €

\*Depending on availability - Dimensions in mm

## Our other products



BPLE

Ball transfer unit push fit, Light



PCS62

Chain sprocket - steel, 15.875 (DIN 10B-1)



BOXKK

Boxed set of DIN6885A keys, Boxed set - Steel or stainless steel



PRF\_ER

Joining bar for aluminium profile, Joint bar



RAM35

Manual bevel gearbox, Bevel




M0

Worm and wheel set, Non hardened steel




CAP805

Slat top chain stainless steel, Large range 805

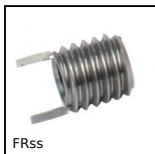

FRss

 Stainless steel thread inserts, Stainless steel



B

Steel bevel gear, 1:1



SH1

Parallel axis helical gear, Machined plastic (delrin)



SSG1


Stainless steel spur gear, Stainless steel 304L



MSP3815

Masterplate® glueable insert rectangular, rectangular with tapped i...

## Complementary products

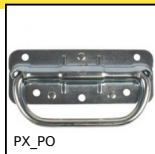

PX\_PO

Carrying handle, back-plated