


# Carrying handle

PX  
PO

Steel

## Handle PX399-BR:

- The plate and ring of the handle are not attached
- Plate: 1mm thick formed steel
- Ring: formed wire Ø4.9mm

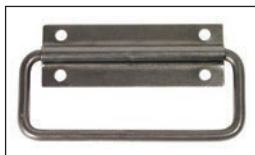


Handle PX399-BR

## Handle PO301-ZB:


- Reduced height saves space
- Ring is secured to plate
- Two part riveted plate, 1.5mm
- 5 fixing holes Ø5.5mm
- Ring: Formed steel wire 8mm
- Plate secured using 4 x light alloy rivets Ø3mm




Handle PO301-ZB

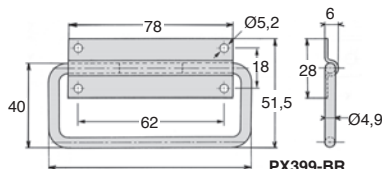

PX399-BR

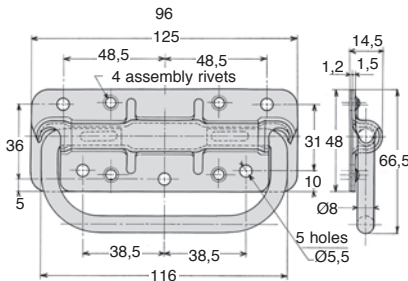

PO301-ZB

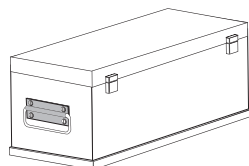

Typical application

## DISCOUNTS

Qty	1+	6+	20+	50+	250+	400+
Disc.	List	-5%	-10%	-15%	-25%	On request

Part number	Finish	Fixing	Max. load per handle (kgf)	Weight (kg)	Stock*	Price each 1 to 5
<b>Ordinary carry handle</b>						
PX399-BR	Unfinished	With hole	-	0,049	✓	1,25 €
<b>Riveted carrying handle</b>						
PO301-ZB	White zinc	With hole	60	0,023	✓	7,84 €

\*Depending on availability - Dimensions in mm

## Our other products



ERF  
Quick fitting threaded cable terminal, Cable terminal with threaded ...



PTA40ssEB  
Articulated foot white sheet metal base Ø40, 3000N



CHAsb28

Roll of hinge without pin, Plastic hinge




HAS

Captive C washer, Slotted flat headed shoulder screw



VDSCB

Sliding lock adjustment system, Blocking wedge for sliding lock for ...

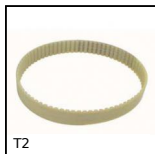

T2

T type timing belt, T2.5 Steel cored polyurethane



CSS

Spherical bushing, Steel / self lubricating steel



MSP3815

Masterplate® glueable insert rectangular, rectangular with nut



BPQ

Quadro linear ball bearing unit, Included ...



WW16

Drylin® W slide, slide assembly



LOQ


Manual lock, Manual latch



NPTR10

Adjustable cross clamp, Adjustable

## Complementary products

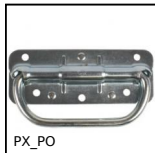

PX\_PO

Carrying handle, back-plated