

Carrying handle

PX
PO


Steel

Handle PX399-BR:

- The plate and ring of the handle are not attached
- Plate: 1mm thick formed steel
- Ring: formed wire Ø4.9mm

Handle PO301-ZB:


- Reduced height saves space
- Ring is secured to plate
- Two part riveted plate, 1.5mm
- 5 fixing holes Ø5.5mm
- Ring: Formed steel wire 8mm
- Plate secured using 4 x light alloy rivets Ø3mm

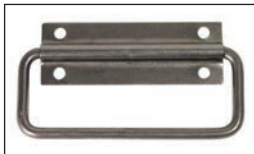


Handle PX399-BR




Handle PO301-ZB

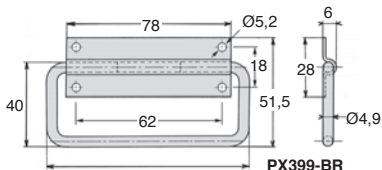

PX399-BR

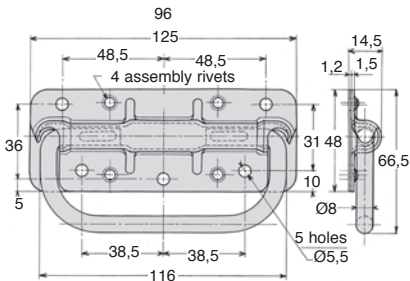

PO301-ZB

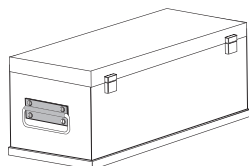

Typical application

DISCOUNTS

Qty	1+	6+	20+	50+	250+	400+
Disc. List	-5%	-10%	-15%	-25%	On request	

Part number	Finish	Fixing	Max. load per handle (kgf)	Weight (kg)	Stock*	Price each 1 to 5
Ordinary carry handle						
PX399-BR	Unfinished	With hole	-	0,049	✓	1,25 €
Riveted carrying handle						
PO301-ZB	White zinc	With hole	60	0,023	✓	7,84 €

*Depending on availability - Dimensions in mm

Our other products



LRR-53

Spring loaded latch,
Spring return latch -
stainless steel



PAT85

Pressed stainless steel
articulating foot
Ø85, Ø 85



UGH25

H Type Guide units,
For Ø25 actuators



DB

Steel bevel gear, 2:1



J65

Spur gear coaxial
gearbox, from 0.80 to
2.95 Nm - Inline




HBM

Adjustment bushing
for half-rail guide,
Adjustment bushing



NCT

Square tube
connector, Fixed
angle

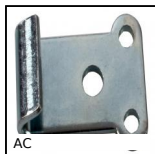

AC

Strike for toggle latch,
15mm



RBNpl

Swivel castor with
plate, Steel - rubber



SLB

Indexing plunger,
steel class 5.8



DIL


Lever operated
locking bolt, lever
clamp



PARF80

Pressed steel base
rigid foot, Swivelling -
Ø80

Complementary products

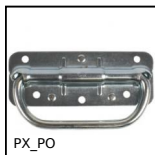

PX_PO

Carrying handle, back-
plated