


Single row cylindrical roller bearings

QNUP

One fixed internal flange and one free internal flange

- The external ring has two fixed flanges whereas the internal ring has one fixed and one free flange.
- The axial movement of the shaft is restricted in both directions.
- Static and dynamic loads are radial loads
- Max working temperature: Polyamide cage: 120°C Steel or brass cage: 150°C
- Materials: Steel flanges and cylinders
P: polyamide cage
M: solid brass cage
J: pressed steel cage

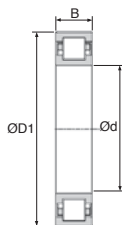

DISCOUNTS

Qty	1+	6+	20+	40+	60+
Disc.	List -10%	-15%	-20%	On request	

Part number	Ød	ØD1	B	Load (kN)		Speed (rpm)		Weight (kg)	Price each 1 to 5
				Dynamic (C)	Static (Co)	lubricant	Oil		
QNUP203-M	17	40	12	17	14	16830	19800	0,073	15.15 €
QNUP2203-P	17	40	16	23	21	16830	19800	0,097	25.36 €
QNUP204-P	20	47	14	25	22	14535	17100	0,12	15.87 €
QNUP205-J	25	52	15	28	26	12240	14400	0,14	17.68 €
QNUP2205-M	25	52	18	33	33	12240	14400	0,17	26.94 €
QNUP206-P	30	62	16	43	36	10710	12600	0,22	21.75 €
QNUP2206-J	30	62	20	54	48	10710	12600	0,27	29.34 €
QNUP207-J	35	72	17	55	47	9180	10800	0,32	23.10 €
QNUP2207-P	35	72	23	68	62	9180	10800	0,42	30.78 €
QNUP307-J	35	80	21	74	62	8415	9900	0,51	29.08 €
QNUP2307-J	35	80	31	104	96	8415	9900	0,75	44.20 €
QNUP208-J	40	80	18	61	52	8415	9900	0,4	29.73 €
QNUP2308-J	40	90	33	126	118	7268	8550	0,98	53.86 €
QNUP209-J	45	85	19	68	63	7268	8550	0,45	31.11 €
QNUP210-P	50	90	20	72	68	6885	8100	0,51	31.80 €
QNUP2310-J	50	110	40	182	182	6120	7200	1,8	75.16 €
QNUP211-J	55	100	21	95	93	6120	7200	0,69	35.37 €
QNUP311-P	55	120	29	153	140	5355	6300	1,55	54.55 €
QNUP212-J	60	110	22	106	100	5738	6750	0,86	41.62 €
QNUP213-M	65	120	23	120	116	5126	6030	1,1	47.86 €

Dimensions in mm


Our other products



BAGtr
Lead screw clamping collar, Aluminium



HSSss
Stainless steel shoulder screw ISO7379, Stainless steel ISO 7379

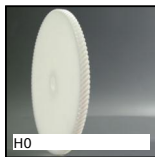

H0
Crossed helical gear crossed axis at 90°, Machined plastic (delrin)



MSP3815
Masterplate® glueable insert rectangular, rectangular with nut



BSB
Ballscrew bearing unit, Support



HS
Hexagonal spacer, Stainless steel 303



EMS
Stainless steel knurled thumb nut, Knurled



 
EMAS
Antistatic knurled nut, Antistatic



BPTRW
Cap for round tube to be welded, To be



EPRC
High helix leadscrew, Cylindrical nut - up to



HBM
Adjustment bushing for half-rail guide,



CHA_GC_9SS
Stainless steel garnet hinge, To be welded

 
Complementary products



Q1
Self-aligning radial ball bearing, Steel



NKX
Combined bearing without inner ring, Needle and ball bearings



KM
Bearing locknut, Locknut KM



EAR
Bearing locknut, Self locking locknut - nylon lock washer