

Clip on Quarter turn latch



QTC

Slot or wing head


- Latch
- 90° rotation
- Suitable for light doors
- Working temp range : -20 to +60°C
- Resists pulling force up to 600N
- Material :
 - Body POM
 - Clip : Polyamide PA6.6

Advantages

- Clip on, tool free assembly
- Low cost

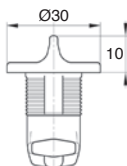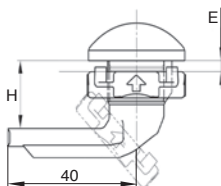

Wing head

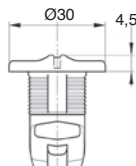

Slotted head

DISCOUNTS

Qty	1+	51+	100+
Disc.	List	-10%	On request

Part number	H	E	Head	Price each 1 to 50
Wing head				
QTC-13/BP	13,5	0 à 4	Wing head	4,35 €
QTC-18/BP	18	0 à 4	Wing head	4,46 €
QTC-25/BP	25	0 à 6	Wing head	4,50 €
Slotted head				
QTC-13/F	13,5	0 à 4	Slot 2x4 mm	4,35 €
QTC-18/F	18	0 à 4	Slot 2x4 mm	4,46 €
QTC-25/F	25	0 à 6	Slot 2x4 mm	4,50 €

Dimensions in mm

Our other products



CLASS
Stainless steel
indexing handle -
female, Stainless steel



AC
Strike for toggle latch,
13mm



DOMI80
Domino 80 adjustable
slide, Slide DOMILINE
80 with counter and
handw...



DER71
Stainless steel AC
asynchronous motor
0.25 à 0.37kW, 0.25
to 0.37kW



ACM_TRI
Manual bonnet
fastener, Black rubber
fastener




PGNT
Thermoplastic T
handle, With threaded
insert



PW_PWG2
Wheel - precision
range, Bronze



 HLC28
Right angle spiro
bevel gearbox, Up to
182Nm



MRS
Stainless steel metric
section rack, Stainless



G2
Steel spur gear, Steel
20NCD2



MAX26
Motor-gearbox 12V
and 24V DC, from



PW_PWG2
Worm - precision
range, Stainless steel

Complementary products



SER69K
Quarter turn latch for
the food industry,
Stainless steel